

STRAIGHT BLADE PLUGS & CONNECTORS

IP67
Suitability


Watertight Plugs, Connectors & Receptacles 2 Pole, 3 Wire Grounding 15 & 20A, 125 & 250V

15W47 & 14W47

Watertight Plugs, Connectors & Receptacles

- A. Rubber body construction** stands up to impacts, oils, chemicals, heat, and weather.
- B. Floating blades** allow self-alignment with contacts for a firm, even electrical connection.
- C. Quick-drive assembly screws** allow for fast installation, saving time and money.
- D. Nickel-plated blades and contacts** for long-lasting, superior corrosion resistance.


NEMA 4, 4X, Watertight. IP65, 66, 67. Rated watertight for 1,500 psi high-pressure hose-down.

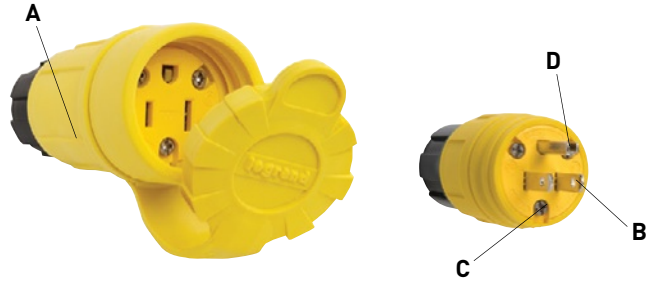

Terminal screws backed-out, ready-to-wire, saving time and money.

Multiple ring seals between plug and connector ensures protection from water and contaminants.

Compression-type cord grip provides watertight seal and 205 lb. pull out strength.

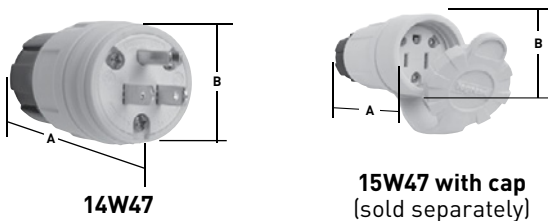

14W47

15W47 with cap
(sold separately)


(INCH)	A	B
WATERTIGHT PLUG		
15A	2.62"	1.85"
20A	2.62"	1.85"
WATERTIGHT CONNECTOR		
15A	4.03"	1.85"
20A	4.03"	1.85"

Cord Grip Range: .250"-.625"



60W33DPLX

CATALOG NUMBER	RATING		DESCRIPTION	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE	
	A.	V.			UL498	C22.2 No. 42M
WATERTIGHT PLUGS, CONNECTORS & RECEPTACLES						
14W47	15	125	Plug, Yellow, NEMA 4X/6P	5-15	•	•
14W47BK	15	125	Plug, Black, NEMA 4X/6P	5-15	•	•
15W47	15	125	Connector, Yellow, NEMA 4X/6P	5-15	•	•
15W47BK	15	125	Connector, Black, NEMA 4X/6P	5-15	•	•
60W47	15	125	Single Receptacle, Yellow, NEMA 4X/6P	5-15	•	•
60W47BK	15	125	Single Receptacle, Black, NEMA 4X/6P	5-15	•	•
60W47DPLX	15	125	Duplex Receptacle, Yellow, NEMA 4X/6P	5-15	•	•
14W33	20	125	Plug, Yellow, NEMA 4X/6P	5-20	•	•
14W33BK	20	125	Plug, Black, NEMA 4X/6P	5-20	•	•
15W33	20	125	Connector, Yellow, NEMA 4X/6P	5-20	•	•
15W33BK	20	125	Connector, Black, NEMA 4X/6P	5-20	•	•
60W33	20	125	Single Receptacle, Yellow, NEMA 4X/6P	5-20	•	•
60W33DPLX	20	125	Duplex Receptacle, Yellow, NEMA 4X/6P	5-20	•	•
14W49	15	250	Plug, Yellow, NEMA 4X/6P	6-15	•	•
14W49BK	15	250	Plug, Black, NEMA 4X/6P	6-15	•	•
15W49	15	250	Connector, Yellow, NEMA 4X/6P	6-15	•	•
15W49BK	15	250	Connector, Black, NEMA 4X/6P	6-15	•	•
60W49	15	250	Single Receptacle, Yellow, NEMA 4X/6P	6-15	•	•
60W49DPLX	15	250	Duplex Receptacle, Yellow, NEMA 4X/6P	6-15	•	•
14W48	20	250	Plug, Yellow, NEMA 4X/6P	6-20	•	•
14W48BK	20	250	Plug, Black, NEMA 4X/6P	6-20	•	•
15W48	20	250	Connector, Yellow, NEMA 4X/6P	6-20	•	•
15W48BK	20	250	Connector, Black, NEMA 4X/6P	6-20	•	•
60W48	20	250	Single Receptacle, Yellow, NEMA 4X/6P	6-20	•	•
60W48DPLX	20	250	Duplex Receptacle, Yellow, NEMA 4X/6P	6-20	•	•
14W07	15/10	125/250	Plug, Yellow, NEMA 4X/6P	NON	•	•
15W07	15/10	125/250	Connector, Yellow, NEMA 4X/6P	NON	•	•
60W07	15/10	125/250	Single Receptacle, Yellow, NEMA 4X/6P	NON	•	•

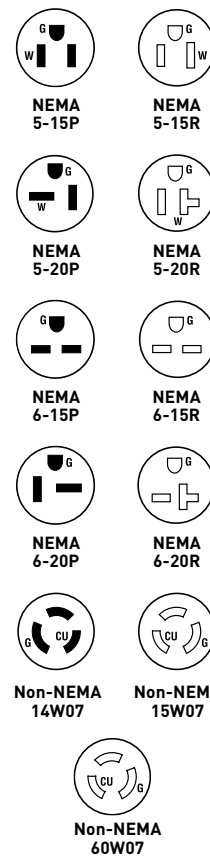

STRAIGHT BLADE PLUGS & CONNECTORS

DEVICES & WALL PLATES

Color Selection Chart

Devices & Plastic Wall Plate Colors



Ivory Light Almond White Green Antique Brass Dark Bronze Nickel



Black Blue Brown Gray Orange Red

See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

Metal Finish



Aluminum Brass (Brushed) Polished Brass Stainless Steel Brushed Bronze Chrome

Custom Metal Wall Plates Paint Finish Colors

Paint Color



Orange Green Gray Yellow Glossy Black Brown White



Primer Red Pink Flat Black Ivory Light Almond Blue

To order custom metal wall plates, see Pages P-40 – P-42.
For additional colors consult factory.