


GFCIs


PlugTail™ Self-Test GFCI Receptacles with SafeLock™ Protection 2 Pole, 3 Wire Grounding 15 & 20A, 125VAC

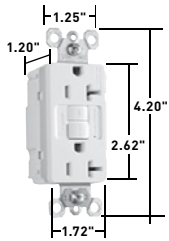

PT2097W



 PTRA65TR




Features

- Faster, more reliable installation.
- No exposed terminals create a finger safe application before, during, and after installation.
- Built-in connector features large brass terminal blades to ensure consistent, reliable electrical connections to PlugTail Connector.
- GFCI works with the existing 3-wire PlugTail Connectors creating a non-feed-thru application for facility owners.
- Conducts an automatic test every three seconds, ensuring it's always ready to protect. If the device fails the test, the indicator light flashes to signal that the GFCI should be replaced. It also has our proven SafeLock Protection feature: if critical components are damaged and protection is lost, power to the receptacle is disconnected.
- Thinner than competitors' GFCI Receptacles: leaves more room for wires in the box.
- Auto-Ground clip assures a positive ground to metal box.
- Meets 2015 UL requirements.
- FSUL Listed (Federal Specification WC596).
- Exceeds UL 943 voltage surge requirements; survives 100x the required UL 3kA/6kV voltage surge test cycles.
- Trip indicator light (red LED).
- 10kA short circuit rating.
- Mounting screws are shipped captive in the device and wall plate for easier installation.
- High-impact-resistant thermoplastic construction.
- Zinc-plated steel mounting strap.
- Button colors match the device face.
- Dual-direction test and reset buttons.
- Class A rated GFCI.
- Supplied with matching TP26 nylon wall plate.
- Tri-drive screws.

Specifications

- Supply Voltage: 125VAC, 60 Hz
- Supply Voltage Range: 102-132 VAC
- Trio Threshold: 5± 1mA
- Trip Time: 0.025 sec., nominal per UL Standard

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	VAC			UL943 C22.2 No. 144	UL498 C22.2 No. 42	FSUL WC596
SPECIFICATION GRADE 15 AMP DUPLEX GFCI							
PT1597I	15	125	Ivory	5-15R	•	•	•
PT1597W	15	125	White	5-15R	•	•	•
PT1597GRY	15	125	Gray	5-15R	•	•	•
PT1597LA	15	125	Light Almond	5-15R	•	•	•
SPECIFICATION GRADE 20 AMP DUPLEX GFCI							
PT2097I	20	125	Ivory	5-20R	•	•	•
PT2097W	20	125	White	5-20R	•	•	•
PT2097	20	125	Brown	5-20R	•	•	•
PT2097GRY	20	125	Gray	5-20R	•	•	•
PT2097BKC	20	125	Black	5-20R	•	•	•
PT2097RED	20	125	Red	5-20R	•	•	•
PT2097LA	20	125	Light Almond	5-20R	•	•	•

 

CATALOG NUMBER	WIRE TYPE	WIRE LENGTH
PLUGTAIL CONNECTORS – RIGHT ANGLE		
PTRA65TR	Stranded	6"
PTRA65SOL	Solid	6"

For additional PlugTail Connectors, see Page B-4.

All PlugTail Connectors are available in any wire length up to 25 inches, consult factory to order.

All devices listed on this page conform to NEMA WD-1 and WD-6.