


# STRAIGHT BLADE RECEPTACLES

## PlugTail™ Specification Grade Receptacles

### PTTR5362W and PT5362SCI PlugTail™ Spec Grade Receptacles

- A. Auto-ground clip** assures positive ground.
- B. .036 inch thick, brass, triple-wipe power contacts** for lasting retention.
- C. Dual mechanical shutter system** to help prevent insertion of foreign objects.
- D. Plated steel wrap strap design** for maximum durability and corrosion resistance.
- E. Built-in connector** features large brass terminal blades to ensure consistent, reliable electrical connections.
- F. Large brass contacts** snugly terminate on device blade terminals. Audible snapping latch assures connection, allows release.
- G. Ultrasonically welded polycarbonate connector housing** secures terminations and conductors in a UL Listed, finger safe housing.
- H. Pre-stripped connector leads** fasten to conductors, easier than standard pigtails.
- I. No exposed terminals** create a finger safe application before, during, and after installation.
- J. Built-in connector** features large brass terminal blades to ensure consistent, reliable electrical connections.
- K. Large brass contacts** snugly terminate on device blade terminals. Audible snapping latch assures connection, allows release.
- L. Exclusive patented feature, circuit label on back** allows permanent circuit identification.
- M. Ultrasonically welded polycarbonate connector housing** secures terminations and conductors in a UL Listed, finger safe housing.
- N. Pre-stripped connector leads** fasten to conductors, easier than standard pigtails.
- O. Auto-ground clip** assures positive ground.
- P. .036 inch thick, brass, triple-wipe power contacts** for lasting retention.
- Q. Plated steel wrap strap design** for maximum durability and corrosion resistance.
- R. Pre-wired with one welded pre-stripped wire lead** to facilitate switched receptacle circuit applications.


**Three drive screws anchor strap** to back body and face.

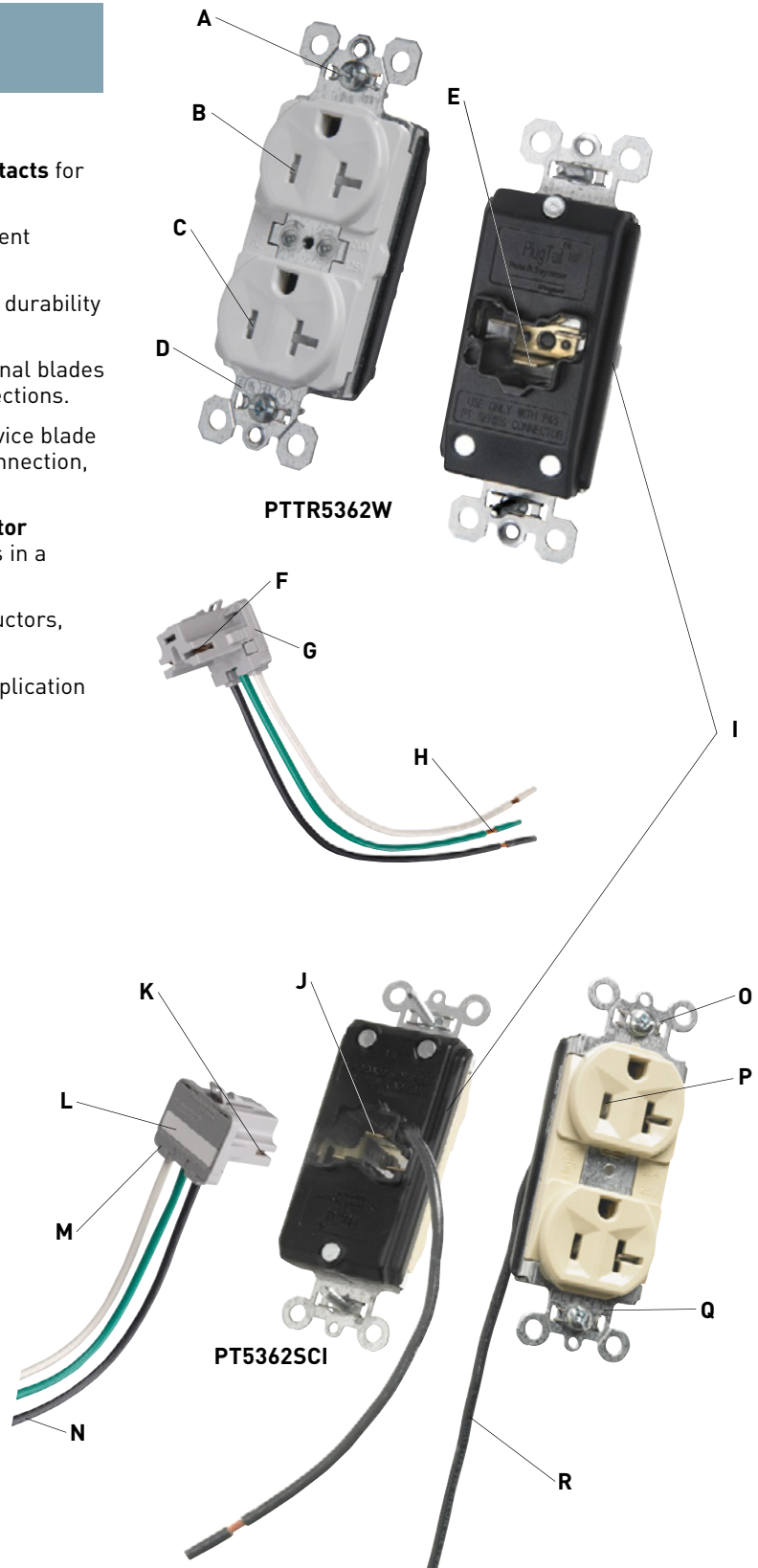



# STRAIGHT BLADE RECEPTACLES

## PlugTail™ Specification Grade Receptacles 15 & 20A, 125V

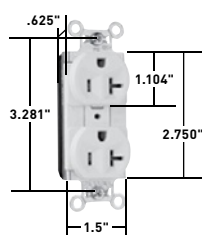

PT5362LA




PTIG5362LA


### Features

- .036 inch thick, brass, triple-wipe power contacts for lasting retention.
- Plated steel wrap-around strap design for maximum durability and corrosion resistance.
- No exposed terminals create a finger safe application before, during, and after installation.
- Built-in connector features large brass terminal blades to ensure consistent, reliable electrical connections.
- Ultrasonically welded polycarbonate connector housing secures terminations and conductors in a UL Listed, finger-safe housing.
- Crimped and welded contacts.
- Large brass contacts snugly terminate on device blade terminals.
- Pre-stripped connector leads fasten to conductors, easier than standard pigtails.
- Auto-ground clip assures positive ground.
- Isolated ground version features a plastic barrier that isolates grounding terminal from mounting strap and metal boxes.

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE	
	A.	V.			 US UL498	FSUL WC596
DUPLEX RECEPTACLES						
PT5262I	15	125	Ivory	5-15R	•	•
PT5262W	15	125	White	5-15R	•	•
PT5262	15	125	Brown	5-15R	•	•
PT5262GRY	15	125	Gray	5-15R	•	•
PT5262BK	15	125	Black	5-15R	•	•
PT5262RED	15	125	Red	5-15R	•	•
PT5262LA	15	125	Light Almond	5-15R	•	•
PT5262BL	15	125	Blue	5-15R	•	•
PT5362I	20	125	Ivory	5-20R	•	•
PT5362W	20	125	White	5-20R	•	•
PT5362	20	125	Brown	5-20R	•	•
PT5362GRY	20	125	Gray	5-20R	•	•
PT5362BK	20	125	Black	5-20R	•	•
PT5362RED	20	125	Red	5-20R	•	•
PT5362LA	20	125	Light Almond	5-20R	•	•
PT5362BL	20	125	Blue	5-20R	•	•

CATALOG NUMBER		RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE	
SPEC GRAD	HOSPITAL GRADE	A.	V.			 UL498	FSUL WC596
ISOLATED GROUND DUPLEX RECEPTACLES							
PTIG5262I	PTIG8200I	15	125	Ivory	5-15R	•	•
PTIG5262W	PTIG8200	15	125	White	5-15R	•	•
PTIG5262		15	125	Orange	5-15R	•	•
PTIG5262GRY		15	125	Gray	5-15R	•	•
PTIG5262RED	PTIG8200RED	15	125	Red	5-15R	•	•
PTIG5262LA		15	125	Light Almond	5-15R	•	•
PTIG5362I	PTIG8300I	20	125	Ivory	5-20R	•	•
PTIG5362W	PTIG8300	20	125	White	5-20R	•	•
PTIG5362		20	125	Orange	5-20R	•	•
PTIG5362GRY		20	125	Gray	5-20R	•	•
PTIG5362RED	PTIG8300RED	20	125	Red	5-20R	•	•
PTIG5362LA	PTIG8300LA	20	125	Light Almond	5-20R	•	•

### 2 Pole, 3 Wire

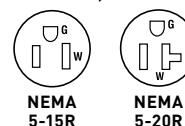


For PlugTail Connectors, see Page B-4.

For Bulk Packaging Solutions consult factory.

# DEVICES & WALL PLATES

## Color Selection Chart

### Devices & Plastic Wall Plate Colors

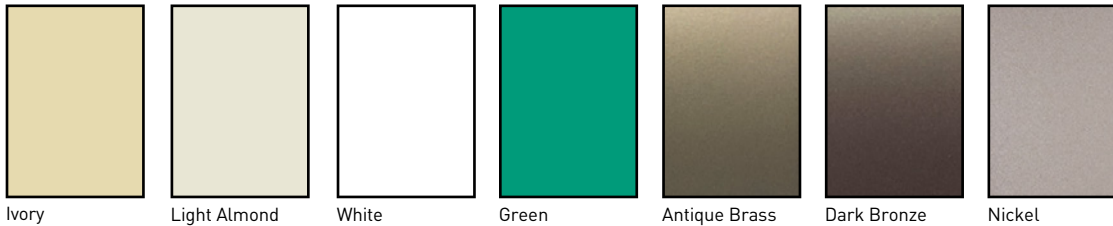

Ivory

Light Almond


White

Green

Antique Brass

Dark Bronze

Nickel

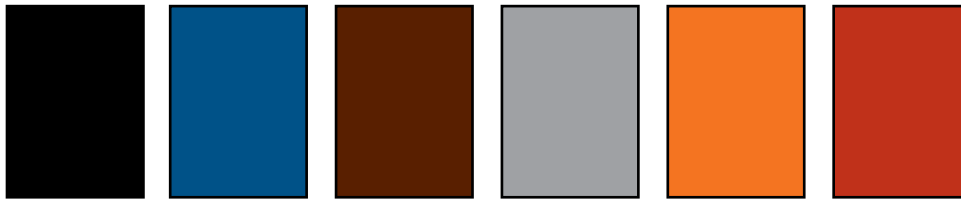

Black

Blue

Brown

Gray


Orange

Red

See specific device and wall plate catalog charts for particular color availabilities.

### Metal Wall Plates

Metal Finish

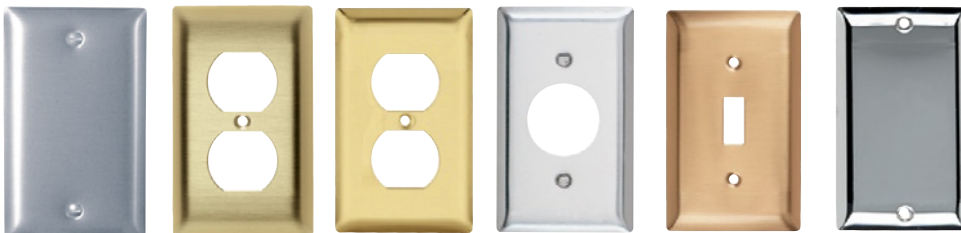

Aluminum

Brass (Brushed)

Polished Brass


Stainless Steel

Brushed Bronze

Chrome

### Custom Metal Wall Plates Paint Finish Colors

Paint Color

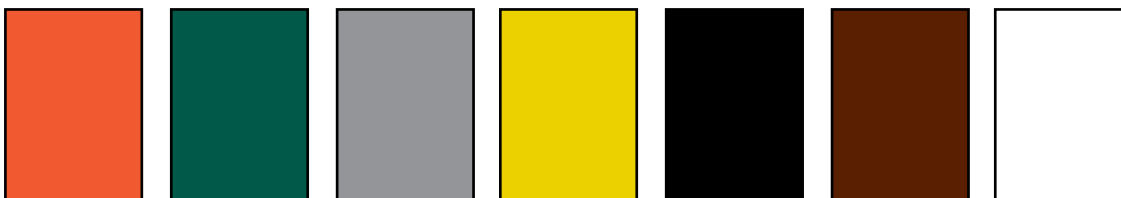

Orange

Green

Gray

Yellow

Glossy Black

Brown

White



Primer

Red

Pink

Flat Black

Ivory

Light Almond

Blue

To order custom metal wall plates, see Pages P-40 – P-44.

**For additional colors consult factory.**