

L7X/L7XR L7XLED T24/ L7XRLED T24



Intended Use

Recessed incandescent housings for 2x8 new construction (L7X and L7XLED T24) or remodel (L7XR and L7XRLED T24) applications. Approved for direct burial in insulation and all ceiling and wiring types.

Features

- Recessed housing rated IC/NON-IC for new construction or remodel applications
- L7X and L7XLED T24: Air-tight, galvanized steel pan with aluminum can and junction box
- L7XR and L7XRLED T24: Air-tight, aluminum housing with heavy-gauge galvanized steel raceway arm utilizing remodel clips for installation in plaster, sheetrock or mechanical ceilings

- Retaining clips are riveted to top of reflector to hold trim inside housing
- Two side-mounted torsion springs on the trim and two receiving brackets in the can ensure a tight fit
- Suitable for ceilings up to 1-1/2" thick
- 120V applications
- Compatible with Acculamp™ LED lamps; see pages 1044-1049 for options

Listings

UL Listed to U.S. and Canadian safety standards.

Featuring
acculamp

**CONTRACTOR
SELECT**

 
 

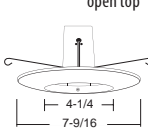
 

ORDERING INFORMATION

 
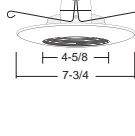
 


 
 
 
 
Specifications subject to change.

Example: L7X 7B2W TOR

Series	Reflector	Options
L7X New construction rough-in	Choose reflector below. Torsion springs will be designated with a TOR in the nomenclature. Riveted clips will have no designation. Housing and reflector may be ordered separately. ²	PHC Poke-home wire connectors
L7XR Remodel rough-in		GSKT Foam gasketing aids in airtight installation
L7XLED T24 New construction rough-in LED base (see p. 469 for 6" LED module options)		
L7XRLED T24 Remodel rough-in LED base (see p. 469 for 6" LED module options)		

IC/NON-IC Rated Full Reflectors: All reflectors are damp location listed. Lensed reflectors are wet location listed. Lamp type and maximum wattages are listed for each trim. White flange standard, except as noted.

Open wide flange		Open narrow flange		Open deep narrow flange		Open top shallow wide flange - economy		Baffle narrow flange		Baffle deep narrow flange	
703 TOR White		702 TOR White		705 White		7X1 MW TOR Matte white open top		7B2 TOR Black, white flange		7B5 Black, white flange	
		702 PF White, white plastic flange		705 PF White, white plastic flange				7B2 TRMW TOR Black, matte white flange		7B5 TRMW TOR Black, matte white flange	
		702MW TOR Matte white		705MW TOR Matte white				7B2MW TOR Matte white		7B5W PF White, white plastic flange	
		702BN TOR Brushed nickel ¹		705A Clear diffuse, white plastic flange				7B2W TOR White		7B5W White	
		702ORB TOR Oil-rubbed bronze ¹		705AZ Clear specular, white plastic flange				7B2W PF TOR White, white plastic flange		7B5MW TOR Matte white	
		702A R24 Clear diffuse, white plastic flange						7B2BN TOR Brushed nickel ¹			
		702AZ Clear specular, white plastic flange						7B2ORB TOR Oil-rubbed bronze ¹			
		702A PFMW TOR Clear diffuse, matte white plastic flange									
IC		IC		NON-IC		IC		IC		NON-IC	
75 PAR30		65 BR30		120 PAR38		75 PAR30 (short neck)		65 BR30		120 BR40	
65 BR30		75 PAR30		120 BR40		65 BR30		75 PAR30		120 PAR38	

Baffle wide flange		Baffle open top shallow wide flange - economy		Eyelid wallwash		Eyeball		Shielded wallwash		Shielded pinhole		Polycarbonate lens		WETlite™		Glass lens	
7B3 TOR Black, white flange		7XB1MW TOR Matte white baffle open top		7W1 White		25° Vertical tilt		7W1 White		7W1 Matte white		7LD1 Drop opal ¹		6H20 TOR White		6LD3 Drop opal	
7B3W TOR White				7W1MW Matte white		7E1 TOR White				CS1 White				6H20BN TOR Brushed nickel ¹		6LF3 Flat white	
						7E1MW TOR Matte white								6H20ORB TOR Oil-rubbed bronze ¹		6L4 Fresnel	
						7E1BN TOR Brushed nickel ¹										6LDB3 Drop opal baffle	
						7E1ORB TOR Oil-rubbed bronze ¹										6LFB3 Flat white baffle	
																6LBA Fresnel baffle	
IC		IC		IC		IC		IC		IC		IC		IC		IC	
75 PAR30		75 PAR30 (short neck)		40 A19		65 BR30		40 A19		40 A19		40 A19		75 PAR30		75 A19	
65 BR30		65 BR30				75 PAR30				50 R20				75 PAR38			

ADDITIONAL INFORMATION

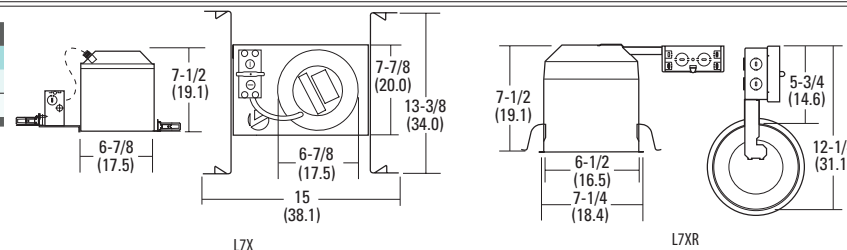
For additional product information, visit www.lithonia.com.

ACCESSORIES

ORDER SEPARATELY

CTR6	6" goof ring, white
ATK6	6" air-tight trim kit

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches (centimeters) unless otherwise noted.



Notes

- Flange matches trim finish.
 - 6 and C series trims also compatible trim options.
- Please consult www.lithonia.com for a full listing of Contractor Select products.