

Lighting and Accessories



T8 Fluorescent Light Kits

- Available in 18", 24" and 48" lengths.
- Operating voltage 115 AC 60Hz
- Manual operated switch with 115 volt convenience outlet
- Metal housing finish in white, durable plastic lens with 6' power cord (without plug)
- Can mount to available light bracket (see below) or magnet strip
- Low profile 1.75" high x 4.5" deep
- Use standard 18", 24" or 48" T8 Fluorescent bulb (not included)

Part Number	Description
FLK18T8	18" Fluorescent Light Kit
FLK24T8	24" Fluorescent Light Kit
FLK48T8	48" Fluorescent Light Kit
FLK18MM	Magnet mount for 18" and 24" light
FLK48MM	Magnet mount for 48" light



LED Light Kits

- Available in 9", 17.5", 26", 34.5" and 38.5" lengths
- Operating voltage 100/240V AC 50/60Hz Operating temperature -20 C to + 50 C
- Long lamp life 60,000 hours in warm white color temperature
- No remote power supplies as unit comes with its own integral LED drivers
- Hard wired via multiple knockouts in light weight extruded Aluminum frame finished white with manual operated switch
- Hinged glass diffuser allows easy access to replaceable LED module


Part Number	Description	Number LED Modules	Energy Use
FLK5LED	9" LED Light Kit	1	4.4 w
FLK7LED	17.5" LED Light Kit	2	7.2 w
FLK10LED	26" LED Light Kit	3	9.8 w
FLK15LED	34.5" LED Light Kit	4	15.0 w
FLK17LED	38.5" LED Light Kit	5	17.0 w



Light Kit Brackets

- Designed for mounting to HME frame assembly
- Brackets accept either Fluorescent or LED light kits
- Clear coat plated finish

Part Number	Description
FLMTGBRK	Light kit mounting bracket 1.5" x 9" qty 2

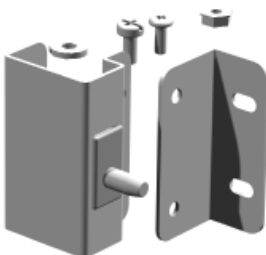

Door switch

- Designed for mounting to HME frame assembly
- NO/NC switch rated 10A 115/230 volt

Part Number	Description
FDS1	Door Switch HME