

OMNIBOX™ SERIES FLOOR BOXES



OmniBox Series™ Floor Boxes provide an excellent activation solution when multiple services are required in open space areas to meet the workstation needs of today's applications.

CODE REFERENCE

cULus Listed
Metallic Outlet Boxes:
 File E2961 Guide QCIT.
 Meets Article 314.27(C) of NEC.

COLOR OPTIONS



OmniBox Series™ Flanges Cover Plates are available in the these colors as indicated in the part number descriptions.


Custom color options are also available. Consult the factory for more information.

OMNIBOX™ SERIES FLOOR BOXES

Omnibox Series Powder-Coated Aluminum Cover Plates Ordering Information

828R-TCAL

Powder-Coated Aluminum Duplex Cover Plate

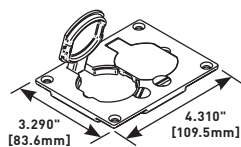


828R-TCAL-BK, 828R-TCAL-GY, 828R-TCAL-BS, 828R-TCAL-NK, 828R-TCAL-BZ

Flip lids. Can also be used with a 106 type communication adapter.

829CKAL-3/4

Powder-Coated Aluminum Cover Plate

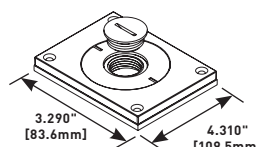


829CKAL-3/4BK, 829CKAL-3/4GY, 829CKAL-3/4BS, 829CKAL-3/4NK, 829CKAL-3/4BZ

Power or communication plate with 2" [51mm] and 3/4" [19.1mm] plugs. Covers are available in five decorative colors: black, gray, brass, nickel and bronze.

NOTE: Acceptable for use with threaded conduit when passing through power cables.

828GFITCAL


Powder-Coated Aluminum Rectangular Cover Plate

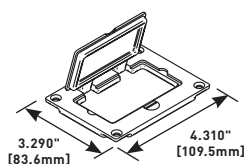

828GFITCAL-BK, 828GFITCAL-GY, 828GFITCAL-BS, 828GFITCAL-NK, 828GFITCAL-BZ


Allows for mounting of a duplex receptacle (Duplex or GFCI style) with a rectangular flip cover.

828MAAP AV Adapter Plate

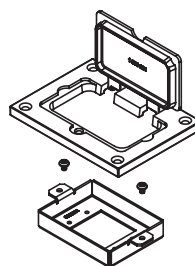

Sheet metal adapter plate that accepts two (2) Legrand AVIP or Extron® Electronics MAAP style device plates (sold separately). For use with 828GFITC or 828GFITCAL cover plates (sold separately).

829CKAL-1 Powder-Coated Aluminum Cover Plate

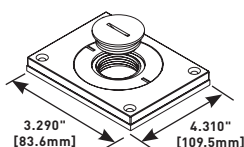


829CKAL-1BK, 829CKAL-1GY, 829CKAL-1BS, 829CKAL-1NK, 829CKAL-1BZ

Power or communication plate with 2" [51mm] and 1" [25mm] plugs. Covers are available in five decorative colors: black, gray, brass, nickel and bronze.

NOTE: Acceptable for use with threaded conduit when passing through power cables.

Omnibox Series Nonmetallic Cover Plate Flanges Ordering Information


817PCC 1-Gang Nonmetallic Carpet Flange

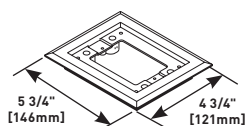

817PCC-BLK, 817PCC-BRN

For Ortronics® connectivity use with 829PFLRT Cover. For Activate™ connectivity use with 829PFL Cover. Accepts Ortronics® MAB6TJ TracJack and MAB3S2 Series II adapters and Wiremold CM Series inserts, sold separately.

827PCC 2-Gang Nonmetallic Carpet Flange

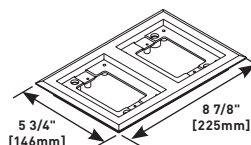

827PCC-BLK, 827PCC-BRN

For Ortronics® connectivity use with 829PFLRT Cover. For Activate™ connectivity use with 829PFL Cover. Accepts Ortronics® MAB6TJ TracJack and MAB3S2 Series II adapters and Wiremold CM Series inserts, sold separately.

NOTE: UL Listed for tile, terrazzo, and carpet floors. Brass covers and flanges are not interchangeable with aluminum or nonmetallic covers and flanges. Nonmetallic covers are interchangeable with aluminum flanges.

WALKERDUCT® UNDERFLOOR DUCT SYSTEMS

Walkerduct Underfloor Duct Systems Service Fitting Compatibility

PRODUCT FAMILY	CATALOG NUMBER	ACTIVATION LOCATION		SERVICE CAPACITY			SERVICE COMPATIBILITY			MATERIAL/COLORS				
		Flush	Pedestal	Single Service	Dual Service	Triple Service	Power	Communication	Audio/Visual	Polycarbonate	Aluminum	Brass	Gray	Black
	817B	•		•			•	•				•		
	827B	•			•		•	•			•			
	837B	•				•	•	•			•			
	817PCC	•		•			•	•		•				•
	827PCC	•			•		•	•		•				•
	837PCC	•				•	•	•		•				•
	818TCAL	•		•			•	•			•			
	828TCAL	•			•		•	•			•			
	838TCAL	•				•	•	•			•			
	S165B	•		•			•					•		
	S165BLK/BRN	•		•						•				•
	S166B	•		•				•				•		
	S166BLK/BRN	•		•				•		•				•
	S175BLK/BRN	•		•			•			•				•
	PSRC9TC	•		•			•				•	•	•	•
	PSRC9AMDTC	•		•				•			•	•	•	•
	PSRC9FFTC	•		•				•			•	•	•	•
	1204BF		•	•				•				•		
	1204AL		•	•				•			•			
	1223BF		•	•			•					•		
	1223AL		•	•			•				•			
	MP4		•	•			•	•	•		•			
	MP8		•		•		•	•	•		•			
	MP8-1		•		•		•	•	•		•			
	525A		•	•				•	•		•			
	525B		•	•				•	•		•			
	525C		•	•				•	•		•			
	525D		•	•				•	•		•			
	525F		•	•			•				•			
	25G		•	•			•				•			
	525H		•	•			•				•			
	525I		•	•			•				•			
	525J		•	•			•	•	•		•			
	525RT		•	•				•			•			
525ACT		•	•				•			•				