

# JB Conduit Outlet Boxes, Covers and Hangers

UNILET® for use with Threaded Rigid Metal Conduit and IMC. Furnished with Internal Ground Screw.

## Applications

- Serve as pulling fittings.
- Provide openings for splicing.
- Make straight connections and 90° bends in conduit runs.
- Permit access to conductors for maintenance.

## Features

- Raintight when enclosed and gasketed with hub or blank covers.
- Furnished with internal ground screw.
- Blind cover screw holes prevent conductor damage during installation, provide water-tightness.
- Available in three inside depths: 1-5/16", 2-1/16", and 3-1/8".
- Order with or without mounting lugs.
- Furnished with four tapped holes and two close-up plugs.
- Cushion fixture hangers are enclosed and gasketed.

## Standard Materials






- JB conduit outlet boxes and covers and JB fixture hangers: malleable iron
- JB-A boxes and covers: copperfree (4/10 of 1% max.) aluminum
- Gaskets: neoprene

## Standard Finishes

- Malleable iron conduit outlet boxes, and hub covers: triple-coat — (1) zinc electroplate, (2) chromate and (3) epoxy powder coat
- Fixture hangers, JB 1/2" hub and blank covers: triple-coat — (1) zinc electroplate, (2) chromate and (3) epoxy powder coat
- Aluminum JB conduit outlet boxes: epoxy powder coat

 
 



## NEC Certifications and Compliances

- UL Standard: 514A
- UL Listed: E2527
- NEMA Standard: FB-1


Description	Hub Size (Inches)	Catalog Number	
		Malleable Iron	Aluminum
JBX — 1-5/16" Inside Depth — Furnished with four tapped openings and two close-up plugs			
 Less mounting lugs	1/2	JBX-50	—
	3/4	JBX-75	—
	1	JBX-100	—
 With mounting lugs	1/2	JBX-50L	JBX50L-A
	3/4	JBX-75L	JBX75L-A
	1	JBX-100L	—
JBDX — 2-1/16" Inside Depth — Furnished with four tapped openings and two close-up plugs			
 Less mounting lugs	1/2	JBDX-50	—
	3/4	JBDX-75	—
	1	JBDX-100	—
 With mounting lugs	1/2	JBDX-50L	—
	3/4	JBDX-75L	—
	1	JBDX-100L	—
JBLX — 3-1/8" Inside Depth — Furnished with four tapped openings and two close-up plugs			
 With removable mounting lugs	1/2	JBLX-50L	JBLX-50L-A
	3/4	JBLX-75L	JBLX-75L-A
	1	JBLX-100L	JBLX-100L-A

# JB Conduit Outlet Boxes, Covers and Hangers


UNILET® for use with Threaded Rigid Metal Conduit and IMC.

		Hub Size (Inches)	Depth in Millimeters (Inches) (A)	Catalog Number	
Description				Malleable Iron	Aluminum
Cast Covers — Furnished with screws — When used with gasket provides raintight fit, supports 113.4 kg (250 lb)					
	Hub Covers	1/2	20.0 (0.75)	<b>JBK-50</b>	<b>JBK-50-A</b>
		3/4	23.9 (0.94)	<b>JBK-75</b>	<b>JBK-75-A</b>
	Cover	Blank	4.8 (0.19)	<b>JBK-B</b>	<b>JBK-1B-CA</b>
Gasket — Neoprene					
		—	—	<b>JB-GK-N</b>	<b>JB-GK-N</b>
Flexible Fixture Hangers — Furnished with gasket and screws					
	Ball Type — 15° swing in all directions, support 113.4 kg (250 lb)	1/2	65.0 (2.56)	<b>JBK-50-BS</b>	—
		3/4	65.0 (2.56)	<b>JBK-75-BS</b>	—
	Cushion type, enclosed and gasketed — 8° swing in all directions. Cushions 18.1 kg (40 lb), supports 113.4 kg (250 lb)	1/2	41.4 (1.63)	<b>JBK-50-CS</b>	—
		3/4	41.4 (1.63)	<b>JBK-75-CS</b>	—

## Dimensions in Millimeters (Inches)

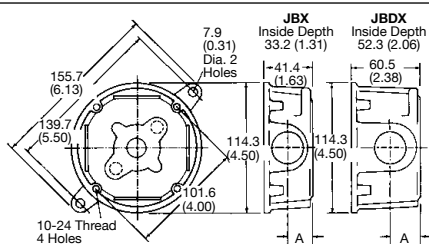

JBX, JBDX

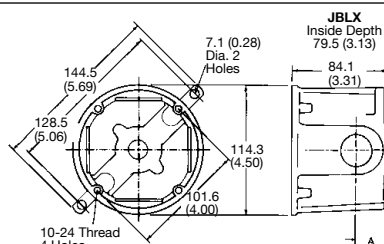

JBLX

Hub Size (Inches)	Dimension "A" in Millimeters (Inches)		
	JBX	JBDX	JBLX
1/2	19.1 (0.75)	19.1 (0.75)	19.1 (0.75)
3/4	22.4 (0.88)	22.4 (0.88)	22.4 (0.88)
1	20.6 (0.81)	26.9 (1.06)	26.9 (1.06)

## Wiring Capacity ①

Hub Size (Inches)	JBX	dm <sup>3</sup> (in <sup>3</sup> ) JBDX	JBLX
1/2	15.50 (0.25)	23.00 (0.38)	33.00 (0.54)
3/4	15.50 (0.25)	23.00 (0.38)	33.00 (0.54)
1	15.50 (0.25)	23.00 (0.38)	33.00 (0.54)

① JB covers add no additional cubic inch capacity.