


Device Boxes

Armoured and Nonmetallic Sheathed Cable Clamps




CI2104-LLEA

Holding prongs and prepositioned depth tabs.

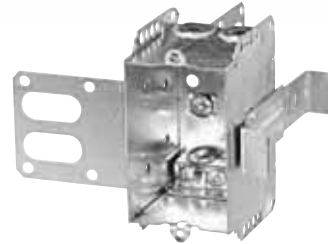


CI2104-LSSAX

"Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.

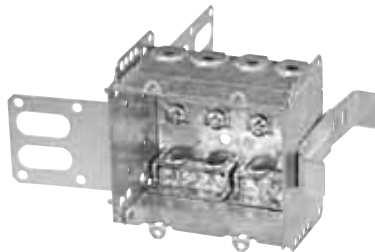

CI2104-LSSA-2X

2 gang. "Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.

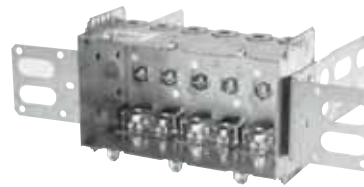

CI2104-LSSA-3X


3 gang. "Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.




Cat. No.	Width (in.)	Volume (Cu. in.)	Features		Pryouts ends
			Ears	Bracket	
2-1/2 in. Deep — Non-Gangable — 3 in. High					
CI2104-LLEA	2	12.5	-	P. Tabs	4
CI2104-LSSAX	2	12.5	-	P. Tabs	4
CI2104-LSSA-2X	4	25	-	"SSX"	8
CI2104-LSSA-3X	6	37.5	-	"SSX"	12

Steel Stud Boxes

Device Boxes

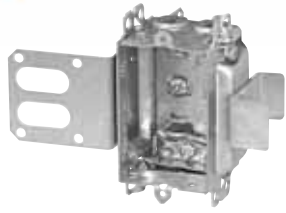


CI3102-LSSAX

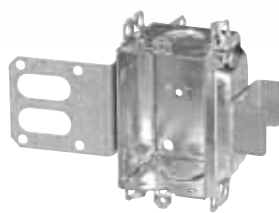


CI3102-SSX




CI1204-3/4-SSX-HV

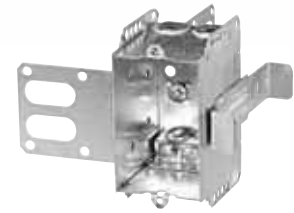


CI2104-LSSAX

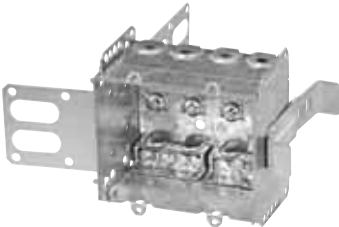


CI2104-LSSA-2X

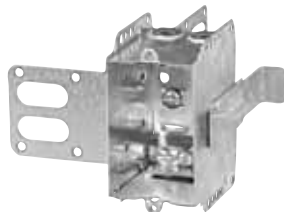


CI2104-LSSX

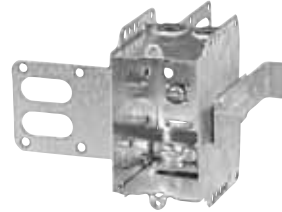


CI2104-LSS1X-1

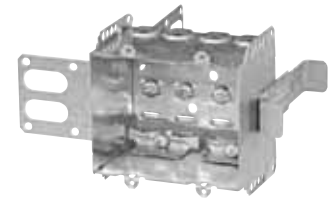


CI2104-LSS2X-1

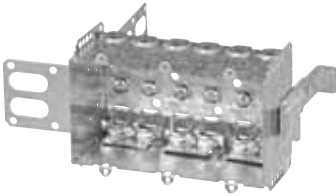

CI2104-LSS3X-1

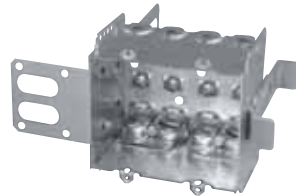

CI2104-LSS-2X

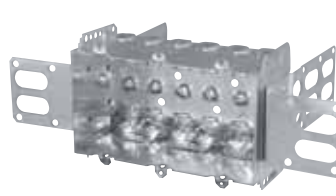

CI2104-LSS-3X



CISSX-6



Cat. No.	Volume (Cu. in.)	Width (in.)	Features	Knockouts			Pryouts
			Clamps	1/2 in. ends	1/2 in. bottom	3/4 in. ends	ends
Device Boxes — 2 in. Deep — Gangable — 3 in. High							
CI3102-LSSAX	12.0	2	loomex/BX	-	-	-	4
CI3102-SSX	12.0	2	-	2	-	-	-
Device Boxes — 2-1/2 in. Deep — Pre-Ganged — 3 in. High							
CI1204-3/4-SSX-HV	16.0	2	-	-	-	2	-
CI2104-LSSAX	12.5	2	loomex/BX	-	-	-	4
CI2104-LSSA-2X	25.0	3-3/4	loomex/BX	-	-	-	8
CI2104-LSSA-3X	37.5	5-1/2	loomex/BX	-	-	-	12
CI2104-LSSX	12.5	2	loomex/BX	-	-	-	4
CI2104-LSS1X-1	12.5	2	loomex/BX	-	-	-	4
CI2104-LSS2X-1	25.0	3-3/4	loomex/BX	-	-	-	8
CI2104-LSS3X-1	37.5	5-1/2	loomex/BX	-	-	-	12
CI2104-LSS2X	25.0	3-3/4	loomex/BX	-	-	-	8
CI2104-LSS3X	37.5	5-1/2	loomex/BX	-	-	-	12

Cat. No.	Description
Support Brackets	
CISSX-6	Support bracket extension for 6 in. metal stud