

FH and FHSN Series Flexible Fixture Hangers

Hook and Loop

UNILETS® for Use with Threaded Rigid Metal Conduit and IMC.

CEC:

Listed for Ordinary (Unclassified) Locations

Applications

- Designed for suspension of HID, fluorescent and incandescent lighting fixtures.

Features

- Protect fixture against wind and vibration damage.
- Cushion type for added protection where lighting fixtures are subjected to vibration.
- Malleable iron for strength and safety.
- Hook and loop combination permits quick disconnect and removal of fixture for maintenance.
- Offer inexpensive means of pendant flexible suspension of lighting fixtures.
- Permit free swing in any direction.
- EF and FHSN jaw openings can be completely closed for added safety.

Standard Materials

- Malleable iron

Standard Finishes

- Zinc electroplate and clear chromate

CEC Certifications and Compliances

- CSA Certified: 065180



FHLM



FHHM



FHSN

Illustrated Features

GHPHT Feed-Thru
Receptacle Hanger

FHLF
Female Loop



Baymaster High Bay HID
Lighting Fixture

POLES/HANGERS: NEC/CEC ORDINARY LOCATION FLEXIBLE FIXTURE HANGERS

Appleton®





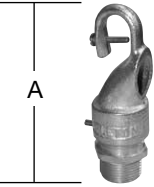
 
FH and FHSN Series Flexible Fixture Hangers

Hook and Loop

UNILETS® for Use with Threaded Rigid Metal Conduit and IMC.

CEC:
Listed for Ordinary (Unclassified) Locations

POLES/HANGERS: NEC/CEC ORDINARY LOCATION FLEXIBLE FIXTURE HANGERS

	Size (Inches)	Length A (mm) in	Support Weight kg (lbs)	Catalog Number		
FH – Hanger Loops – With 5/8" diameter wireway						
 <p>FHLM</p>	FHLM – Male		157.5 (350)	FHLM-50		
	1/2	98.6 (3.88)				
	3/4	104.9 (4.13)		FHLM-75		
	FHLF – Female					
 <p>FHLF</p>	1/2	82.6 (3.25)	157.5 (350)	FHLF-50		
	3/4	82.6 (3.25)		FHLF-75		
	FH – Hanger Hooks – With 5/8" diameter wireway, 3/8" jaw opening					
	 <p>FHHM</p>	FHHM – Male		90.0 (200)	FHHM-50	
1/2		98.6 (3.88)				
3/4		104.9 (4.13)	FHHM-75			
FHHF – Female						
 <p>FHHF</p>	1/2	82.6 (3.25)	90.0 (200)	FHHF-50		
	3/4	82.6 (3.25)		FHHF-75		
	FHHCG – Gasketed Fixture Hanger Hook – With 5/8" wire opening, 3/8" jaw opening, safety screw – As FHHM's above, with internal grommet to prevent moisture and dirt entry					
		FHHCG – Male		34.0 (75)	FHHCG-3750-SS	
1/2		108.0 (4.25)				
3/4		108.0 (4.25)	FHHCG-3775-SS			
FHSN – Conduit Suspension Hanger – With safety strap—clamps around rigid conduit or IMC –Has 3/8" jaw opening						
	1/2	79.5 (3.13)	67.5 (150)	FHSN-50		
	3/4	82.6 (3.25)		FHSN-75		
	1	85.9 (3.38)		FHSN-100		