


In-Wall 3-Way Switch

LC2203

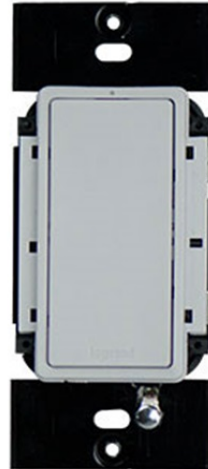

This in-wall 3-Way switch provides convenient control from multiple access points when used in conjunction with any wireless switch. In the radiant style, the LC2203 shares the collection's fit and finish for consistent color and clean, low-profile design. Legrand's RF Lighting Control switches and dimmers integrate with Intuity Home Intelligence, for superior and unified home control of your lights, security, audio, comfort, and more.

features & benefits

- Patented Top Dog™ RF communication protocol; 900MHz radio. Avoids interference with other 900MHz devices, such as cordless phones and baby monitors.
- Patented overload and short circuit protection.
- Legrand patented RF communication protocol for reduced interference
- Patented overload and short circuit protection
- Provides convenient control from multiple access points
- Allows homeowners to change their environment at the push of a button
- Integrates with Legrand's Intuity Home Intelligence
- Frequency-agile Radio Frequency (RF) wireless communications technology
- Available in three colors: light almond, nickel, and white

specifications

General Info

Size: Unit Package: 4.8" x 3.03" x 2.48", Master Carton (Qty 20): 35" x 17" x 25"

Typical Applications: Incandescent, Halogen, MLV, Fluorescent, ELV, CFL, and LED bulbs

Type: In-wall 3-way switch, Universal Lighting Control, radiant style

Housing Material: High Impact Plastic

Special Features: Remote dimmer, RH, multiple access points, Intuity Home Intelligence

Dimensions

Height Metric: 121.92mm

Height U S: 4.8"
Length U S: 2.48"
Length Metric: 62.99mm

Technical Information

AC Voltage Input: 120 VAC
Frequency: Frequency Rating: 900 MHz
Humidity: Up to 90% Relative Humidity (non-condensing)
Load: 1500 W max
Mounting: Mounts in a standard electrical box
Operating Temperature Celsius: 0° ~ 43°C
Operating Temperature Fahrenheit: 32° ~ 104°F
Power Consumption: Varies based on load
Regulatory Approvals: UL, FCC, cULus, RoHS