

# FIRE CLASSIFIED FLOOR BOXES



Wiremold® Fire Classified Floor Boxes meet or exceed the UL Fire Classification requirements for floor boxes eliminating the need for additional spraying or fireproofing.

## CODE REFERENCE


**cULus Listed**  
**Metallic Outlet Boxes:**  
 File E2961 Guide QCIT.  
 Meets Article 314.27(C) of NEC.

## Shallow Depth Steel Floor Boxes Ordering Information

### 880S1FC

#### 1-Gang Fire Classified Shallow Depth Steel Floor Box


Adjustment range over deck of 4 1/2" [114mm] minimum to 5" [127mm] maximum. Use in normal weight concrete 4 1/2" [114mm] minimum pour over deck. One 1 1/4" [32mm] conduit feed opening. Box Capacity – 53 cubic inches.

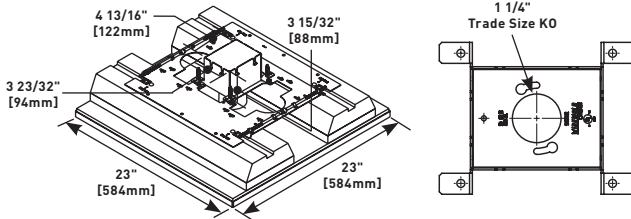

### 880S3FC

#### 3-Gang Shallow Depth Steel Floor Box


Adjustment range over deck of 4 1/2" [114mm] minimum to 5" [127mm] maximum. Use in normal weight concrete 4 1/2" [114mm] minimum pour over deck. Three 1 1/4" [32mm] conduit feed openings. Inside Gang Capacity – 67.5 cubic inches. Outside Gang Capacity – 54 cubic inches each gang.

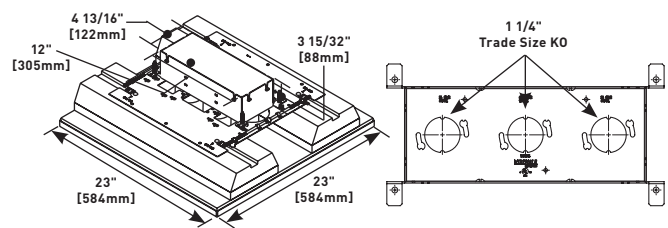

### 880S2FC

#### 2-Gang Fire Classified Shallow Depth Steel Floor Box

Adjustment range over deck of 4 1/2" [114mm] minimum to 5" [127mm] maximum. Use in normal weight concrete 4 1/2" [114mm] minimum pour over deck. Two 1 1/4" [32mm] conduit feed openings. Box Capacity – 58.5 cubic inches per gang.

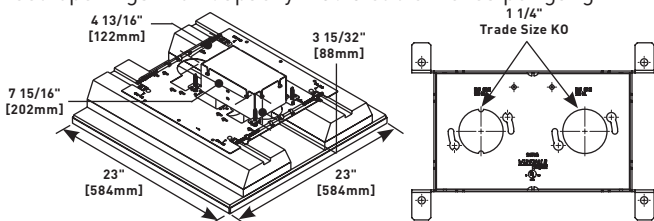

**NOTE:** Floor Box spacing 2' on center and one for every 4 square feet in a span. Four (4) #12 AWG Type THHN Power Conductors or 48 #23 AWG (6 Cat. 6) Tele Data Conductors per gang.

## COLOR OPTIONS




Cover Plates and Flanges for Fire Classified OmniBox Series™ Floor Boxes are available in the colors shown as indicated in the part number descriptions.

**Custom color options are also available. Consult the factory for more information.**

# FIRE CLASSIFIED FLOOR BOXES


RFB Series Floor Boxes

## Fire Classified RFB4 Series Multiservice Shallow Steel Floor Box Compartment Capacities, Knockout Locations & Sizes

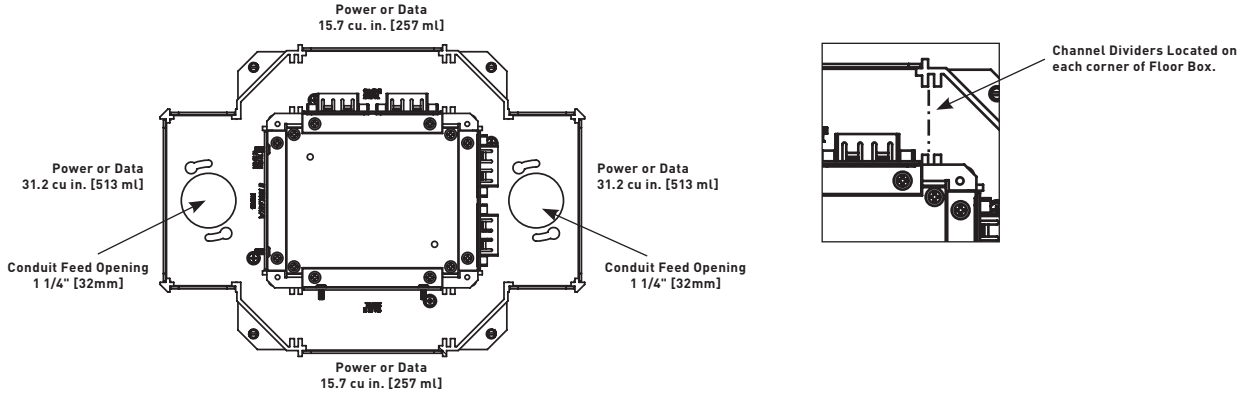


## Fire Classified RFB4 Series Multiservice Shallow Steel Floor Box Accessories Ordering Information

### RFB-B-SS Internal Blank Bracket

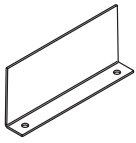


Used to close off unused gangs.

### RFB-2-SSRT Communication Bracket

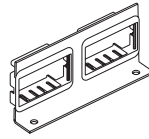


Ortronics® AB2TJ TracJack and ABS2 Series II adapters included.

### RFB-RB-SS Internal Duplex Receptacle Bracket

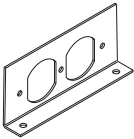

Accepts standard 15 Amp and 20 Amp duplex receptacles.


### RFB-4TKO-SS Internal Bracket

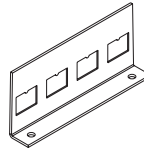

Four RJ Keystone opening knockouts. Use as blank plate or for up to four RJ openings.


**NOTE:** Opening dimension is 9/16" x 3/4" [14.3mm x 19.1mm].

### RFB-GFI-SS Internal GFI Receptacle Bracket

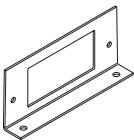


Accepts standard GFCI and Decorator style receptacles, communications or Audio/Video Devices.

### RFB4-SS-AAP Internal Audio Video Bracket

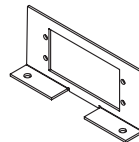


Accepts two (2) Extron® Electronics AAP Series devices (Sold separately).

### RFB-2AB-SS Internal Bracket

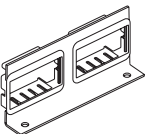

Two Pass & Seymour® Activate adapters included. Wiremold CM Series Open System adapters (sold separately).

### RFB4-SS-MAAP Internal Audio Video Bracket

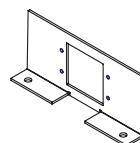

Accepts two (2) Legrand AVIP or Extron® Electronics MAAP Series devices (Sold separately).

Additional configurations available. Please consult your Wiremold Field Sales Representative for more information.