

# Color-Keyed®

## Long Barrel Copper Lug T&B Catalog Number:




58926BEBS  
78621087579  
Active

**UPC Number:**  
**Status:**  
**Description:**

Copper One-Hole Lug - Straight Long Belled End Barrel - max 35KV, 900 kcmil Wire, 5/8" Bolt Size, Tin Plated Blind End, Yellow 115

### General

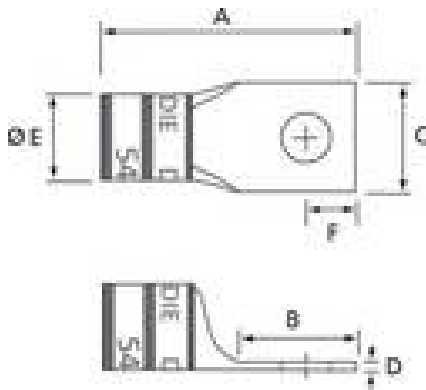

Material	Copper
Finish	Tin Plated
Wire Size	900 kcmil
Number of Studs	1
Stud Size	5/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Yellow
Die Code	115

### Specifications

Voltage Rating	600V to 35KV
----------------	--------------

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	3
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	120.4 lbs. per 100

### Application Support

Overview	Available on Website
----------	----------------------

### Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

### Certifications



File Nbr:  
E9809

For further technical assistance, please contact us...