


Fork Terminals

- Fork terminals enable easy installation because the mounting screw does not have to be completely removed
- Brazed-seam barrel is serrated for high pull-out value. Terminal is high-conductivity electrolytic copper, electro-tin plated.
- Insulation is color coded
- Vinyl-insulated fork terminals have extra-long PVC insulation sleeve for protection and stress relief at wire's flex point
- Suffix "X" indicates an expanded insulation support, meaning a wider wire entry to accommodate heavy wall insulation

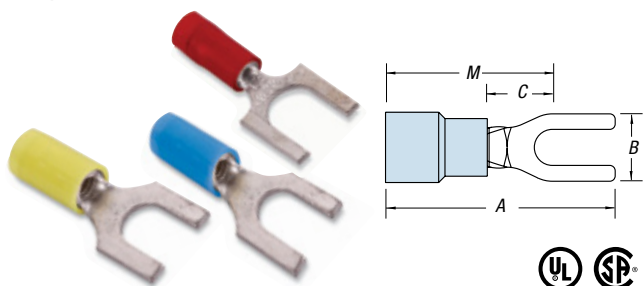


Nylon-Insulated Forks



CAT. NO.	PKG. QTY.	WIRE RANGE	MAX. INS.	BOLT HOLE	REC. TOOL	DIMENSIONS				STOCK THICK.		
						A	B	C	M			
RA18-6F	100	22-16	.136	#6	ERG4001	.83	.25	.25	.71	.02		
RA1103	1,000	22-16	.136	#6		.83	.25	.25	.71			
RA18-8F	100	22-16	.136	#8		.86	.31	.25	.71			
RA1123	1,000	22-16	.136	#8		.86	.31	.25	.71			
RA18-10F	100	22-16	.136	#10		.86	.31	.25	.71			
RA1153	1,000	22-16	.136	#10		.86	.31	.25	.71			
RA18-14F	100	22-16	.136	1/4"		.95	.44	.31	.70			
RA1163	1,000	22-16	.136	1/4"		.95	.44	.31	.70			
RB14-6F	100	18-14	.162	#6		ERG4001	.87	.31	.25		.71	.03
RB1113	1,000	18-14	.162	#6			.87	.31	.25		.71	
RB14-8F	100	18-14	.162	#8	.87		.31	.25	.71			
RB1123	1,000	18-14	.162	#8	.87		.31	.25	.71			
RB14-10F	100	18-14	.162	#10	.87		.38	.25	.71			
RB1153	1,000	18-14	.162	#10	.87		.38	.25	.71			
RB14-14F	100	18-14	.162	1/4"	.95		.44	.28	.74			
RB1163	1,000	18-14	.162	1/4"	.95		.44	.28	.74			
RB1103	1,000	18-14	.162	#6	.74		.28	.16	.60			
RB1124	1,000	18-14	.190	#8	.95		.31	.25	.79			
RB1154	1,000	18-14	.190	#10	.95	.31	.25	.79				
RC10-6F	50	12-10	.210	#6		.97	.31	.27	.81	.04		
RC1113	500	12-10	.210	#6		.97	.31	.27	.81			
RC10-8F	50	12-10	.210	#8		1.00	.37	.27	.81			
RC1123	500	12-10	.210	#8		1.00	.37	.27	.81			
RC10-10F	50	12-10	.210	#10		1.00	.37	.27	.81			
RC1153	500	12-10	.210	#10		1.00	.37	.27	.81			
RC10-14F	50	12-10	.210	1/4"		1.12	.50	.27	.86			
RC1163	500	12-10	.210	1/4"		1.12	.50	.27	.86			
RC1124	1,000	12-10	.250	#8		1.10	.37	.27	.91			
RC1154	1,000	12-10	.250	#10		1.10	.37	.27	.91			


Nylon-Insulated Locking Forks

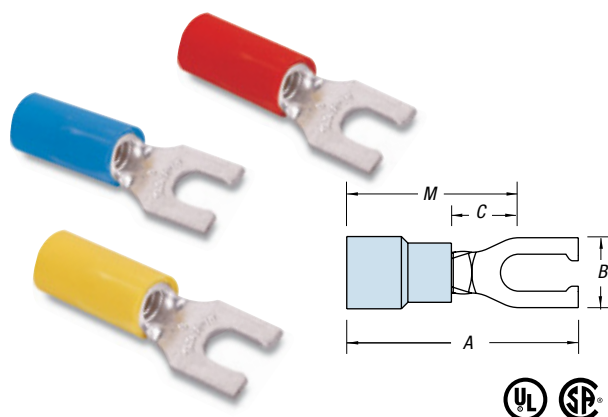

CAT. NO.	PKG. QTY.	WIRE RANGE	MAX. INS.	BOLT HOLE	REC. TOOL	DIMENSIONS				STOCK THICK.		
						A	B	C	M			
RA18-6FL	100	22-16	.136	#6	ERG4001	.86	.25	.25	.71	.02		
RA2213	1,000	22-16	.136	#6		.86	.25	.25	.71			
RA18-8FL	100	22-16	.136	#8		.86	.29	.25	.71			
RA2243	1,000	22-16	.136	#8		.86	.29	.25	.71			
RA18-10FL	100	22-16	.136	#10		.86	.29	.25	.71			
RA2253	1,000	22-16	.136	#10		.86	.29	.25	.71			
RB14-6FL	100	18-14	.162	#6		ERG4001	.87	.25	.25		.71	.03
RB2213	1,000	18-14	.162	#6			.87	.25	.25		.71	
RB2214	1,000	18-14	.190	#6			.95	.25	.25		.79	
RB14-8FL	100	18-14	.162	#8			.87	.29	.25		.71	
RB2233	1,000	18-14	.162	#8	.87		.29	.25	.71			
RB14-10FL	100	18-14	.162	#10	.87		.29	.25	.71			
RB2253	1,000	18-14	.162	#10	.87		.29	.25	.71			
RB2254	1,000	18-14	.190	#10	.95		.29	.25	.71			
RC10-6FL	50	12-10	.210	#6			.97	.31	.27	.81	.04	
RC2203	500	12-10	.210	#6			.97	.31	.27	.81		
RC2204	1,000	12-10	.250	#6		1.07	.31	.27	.91			
RC10-8FL	50	12-10	.210	#8		1.00	.37	.27	.81			
RC2213	500	12-10	.210	#8		1.00	.37	.27	.81			
RC10-10FL	50	12-10	.210	#10		1.00	.37	.27	.81			
RC2223	500	12-10	.210	#10		1.00	.37	.27	.81			
RC2224	1,000	12-10	.250	#10		1.10	.37	.27	.91			
RC10-14FL	50	12-10	.210	1/4"		1.12	.50	.32	.86			
RC2233	500	12-10	.210	1/4"		1.12	.50	.32	.86			

Fork Terminals


Vinyl-Insulation Forks — Expanded Insulation

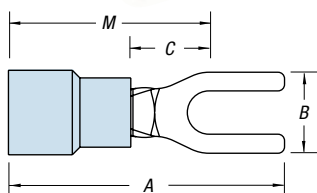

CAT. NO.	PKG. QTY.	WIRE RANGE	MAX. INS.	BOLT HOLE	REC. TOOL	DIMENSIONS				STOCK THICK.	
						A	B	C	M		
18RA-6FX	100	22-16	.170	#6	ERG4001	.94	.25	.27	.81	.02	
RA1167-170	1,000	22-16	.170	#6		.94	.25	.27	.81		
18RA-8FX	100	22-16	.170	#8		.97	.31	.27	.81		
RA1147-170	1,000	22-16	.170	#8		.97	.31	.27	.81		
18RA-10FX	100	22-16	.170	#10		.97	.31	.27	.81		
RA1157-170	1,000	22-16	.170	#10		.97	.31	.27	.81		
14RB-6FX	100	18-14	.200	#6		.97	.31	.27	.81		.03
RB647-200	1,000	18-14	.200	#6		.97	.31	.27	.81		
14RB-8FX	100	18-14	.200	#8		.97	.31	.27	.81		
RB657-200	1,000	18-14	.200	#8		.97	.31	.27	.81		
14RB-10FX	100	18-14	.200	#10	.97	.31	.27	.81			
RB1157-200	1,000	18-14	.200	#10	.97	.31	.27	.81			
10RC-8FX	50	12-10	.250	#8		1.11	.38	.27	.90	.04	
RC1147-250	500	12-10	.250	#8		1.11	.38	.27	.90		
10RC-10FX	50	12-10	.250	#10		1.11	.38	.27	.90		
RC1157-250	500	12-10	.250	#10		1.11	.38	.27	.90		
10RC-14FX	50	12-10	.250	¼"		1.17	.50	.37	.90		

For multiple wire combinations per UL File E9609, see page G-8.

Vinyl-Insulated Locking Forks

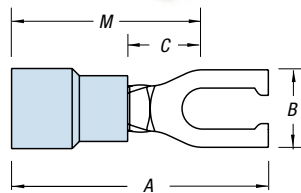

CAT. NO.	PKG. QTY.	WIRE RANGE	MAX. INS.	BOLT HOLE	REC. TOOL	DIMENSIONS				STOCK THICK.	
						A	B	C	M		
18RA-6FL	100	22-16	.150	#6	ERG4001	.97	.25	.25	.81	.02	
RA2217	1,000	22-16	.150	#6		.97	.25	.25	.81		
RA2227	1,000	22-16	.155	#6		.97	.29	—	.81		
18RA-8FL	100	22-16	.150	#8		.97	.29	.25	.81		
RA2247	1,000	22-16	.150	#8		.97	.29	.25	.81		
18RA-10FL	100	22-16	.150	#10		.97	.29	.25	.81		
RA2257	1,000	22-16	.150	#10		.97	.29	.25	.81		
14RB-6FL	100	18-14	.170	#6		.97	.25	.27	.81		.03
RB2207	1,000	18-14	.170	#6		.97	.25	.27	.81		
RB2217	1,000	18-14	.170	#6		.97	.29	.27	.81		
14RB-8FL	100	18-14	.170	#8	.97	.29	.27	.81			
RB2237	1,000	18-14	.170	#8	.97	.29	.27	.81			
14RB-10FL	100	18-14	.170	#10	.97	.29	.27	.81	.04		
RB2257	1,000	18-14	.170	#10	.97	.29	.27	.81			
10RC-6FL	50	12-10	.220	#6	1.09	.31	.27	.90			
RC2207	500	12-10	.220	#6	1.09	.31	.27	.90			
10RC-8FL	50	12-10	.220	#8	1.09	.37	.27	.90			
RC2217	500	12-10	.220	#8	1.09	.37	.27	.90			
10RC-10FL	50	12-10	.220	#10	1.09	.37	.27	.90			
RC2227	500	12-10	.220	#10	1.09	.37	.27	.90			
10RC-14FL	50	12-10	.220	¼"	1.09	.49	.27	.90			
RC2237	500	12-10	.220	¼"	1.09	.49	.27	.90			

For multiple wire combinations per UL File E9609, see page G-8.