

RS-WPRB Series

Dimensions

RS10-WPRB:

4⁵/₈" (11.8 cm) L x 7³/₈" (18.6 cm) H x 4¹/₈" (10.5 cm) D

RS20-WPRB:

12⁵/₈" (32.1 cm) L x 5⁵/₈" (14.3 cm) H x 4¹/₈" (10.5 cm) D

Canopy:

4¹/₄" (10.7 cm) Diameter



Ordering Information

EXAMPLE:

RS	10	SBWPRB6V9W	
Series	# of Heads	Lamp Wattage/Type	Options
RS = par 36	10 = single head 20 = double head 30T = triple head	SBWPRB6V __ W = 6V - 9, 12, 18 or 25 watts, tungsten, sealed beam SBWPRB12V __ W = 12V - 12, 18 or 25 watts, tungsten, sealed beam QSBWPRB6V __ W = 6V - 8, 12 or 20 watts, halogen, quartz sealed beam QSBWPRB12V __ W = 12V - 8, 12 or 37 watts, halogen, quartz sealed beam	TC = teflon coated lens
*NOTE: "__" = insert wattage required			

MT-W4T Series


Dimensions

MT1-W4T:

5.0" (12.8 cm) L x 5.0" (12.8 cm) H x 4.0" (10.2 cm) D

MT2-W4T:

7.0" (17.8 cm) L x 5.0" (12.8 cm) H x 4.0" (10.2 cm) D

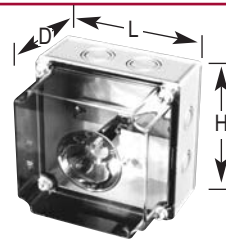

Ordering Information

EXAMPLE:

MQ	1W4T	12V12W	
Series	# of Heads	Lamp Wattage/Type	
MT = tungsten MQ = halogen	1W4T = single head 2W4T = double head	6V9W = 6V - 9 watts, tungsten, wedge base 12V __ W = 12V - 9 or 18 watts, tungsten, wedge base 24V __ W = 24V - 9 or 18 watts, tungsten, wedge base 6V __ W = 6V - 8, 12, or 20 watts, halogen, quartz bi-pin 12V __ W = 12V - 8, 12, or 20 watts, halogen, quartz bi-pin 24V20W = 24V - 20 watts, halogen, quartz bi-pin	
*NOTE: "__" = insert wattage required			

