

## Industrial specification grade device covers


### Product description

Metal and nylon covers

### Weatherproof covers for 30A, 50A & 60A straight blade receptacles

#### Features

- UL Listed for wet locations (cover closed) and damp locations (cover open or closed)
- Meets 2014 NEC® 406.9 (A) and 406.9 (B)(2)
- Self-closing spring door assures full protection
- Gasketing material provides excellent resistance to weather

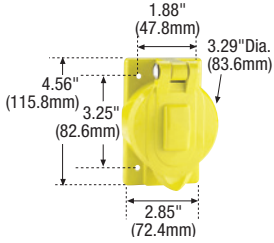

7788CR

### Diecast aluminum receptacle covers

Description	Catalog no.
Weatherproof lift lid cover for 4.69" (119.1.0mm) flush box, use box 2.125" (53.96mm) deep or larger	□ 5741NS*
Weatherproof lift lid cover for FS/FD boxes, use box 2.125" (53.96mm) deep or larger	□ 7420C

\* Not UL Listed

### Weatherproof covers for 50A locking devices in FS/FD boxes

#### Features

- UL Listed for wet locations (cover closed) and damp locations (cover open or closed)
- Meets 2014 NEC® 406.9 (A) and 406.9 (B)(2)
- Self-closing spring door assures full protection
- Gasketing material provides excellent resistance to weather



20416N

### Diecast aluminum & glass-filled nylon covers

Description	Color	Catalog no.
Diecast aluminum lift lid cover	Diecast aluminum	□ 7770*
Glass-filled nylon lift lid cover	Y	□ 7788CR
Glass-filled nylon lift lid cover	BK	□ 7788BK
Glass-filled nylon lift lid cover	GY	□ 7788GY

\* Not cULus listed, UL Listed only

### Weatherproof covers for power-lock devices in FS/FD boxes

#### Features

- UL Listed for wet locations (cover closed) and damp locations (cover open or closed)
- Meets 2014 NEC® 406.9 (A) and 406.9 (B)(2)
- Self-closing spring door assures full protection
- Gasketing material provides excellent resistance to weather

### Diecast aluminum & glass-filled nylon covers

Description	Color	Catalog no.
Glass-filled nylon lift lid cover for 4-wire 30A receptacles	RD	□ 20446N*
Glass-filled nylon lift lid cover for 4-wire 30A receptacles	GY	□ 20416N
Lift lid cover for 4-wire 30A receptacles	Diecast aluminum	□ 20416D

\* Not CSA certified

### Color information:

BK (Black), GY (Gray), RD (Red), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.