

Wireforms®

Juno's timeless, patented Wireform design encircles line and low voltage halogen lamps in a light, technically appealing frame.



Catalog

T430WH
T430BL

Finish


White
Black

Lamp

12V, 50W max. MR16

T537 or T538 transformer required. Must order separately.
See Low Voltage Transformers section for detailed information.

Dimensions

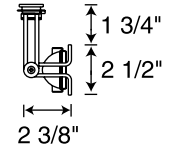


Accessories

For Fixture:	T430
Color Filters	T551-6
Dichroic Filters	T5501-18
Diffusion Lens	T5520
Uniformity Lens	T5521
UV Filter	T5522
Prismatic Spread Lens	T557
Linear Spread Lens	T559
Hexcell Louver	T5559BL
Black Barn Doors	T74BL

12V Transformers

T537, T537U (LED-compatible) and **T538** are available in white, black or silver finishes. See Low Voltage Transformers section for a full description, or Monopoints section for Monopoint Transformers.

 T537, T537U



T538

