

Color-Keyed®

Long Barrel Copper Lug T&B Catalog Number:




UPC Number:
Status:
Description:

54922BEBS
78621087442
Active

Copper One-Hole Lug - Straight Long Belled End Barrel - max 35KV, 750 kcmil Wire, 1/2" Bolt Size, Tin Plated Blind End, Black 106

General

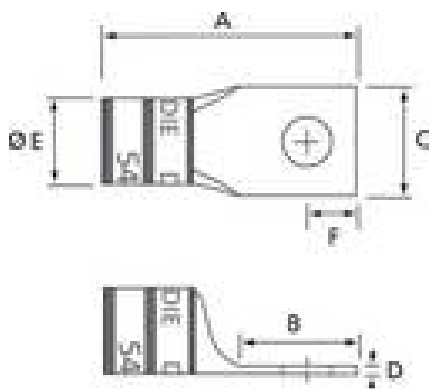

Material	Copper
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	106

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	2
T&B Inner Pack	2
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	90.3 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809