

STRAIGHT BLADE RECEPTACLES


PlugTail™ Extra Heavy-Duty Specification Grade Receptacles


PT5362AW
 Duplex Receptacles

- A. Auto-ground clip** ensures positive ground.
- B. Exclusive patented feature, circuit label on face** allows permanent circuit identification.
- C. .036 inch thick, brass, triple-wipe power contacts** for lasting retention.
- D. Strap tabs wrap around and lock down on face** to prevent strap from separating from face and back body.
- E. No exposed terminals** create a finger-safe application before, during, and after installation.
- F. Built-in connector** features large brass terminal blades to ensure consistent, reliable electrical connections.
- G. Large crimped and welded brass contacts** snugly terminate on device blade terminals.
- H. Ultrasonically welded polycarbonate connector housing** secures terminations and conductors in a UL Listed, finger safe housing. Audible snapping latch assures connection, allows release.
- I. Exclusive patented feature, circuit label on back** allows permanent circuit identification.
- J. Pre-stripped connector leads** fasten to conductors, easier than standard pigtailed.


Two drive screws anchor strap to back body and face.

Tamper-resistant version features dual mechanical shutter system to help prevent insertion of foreign objects.

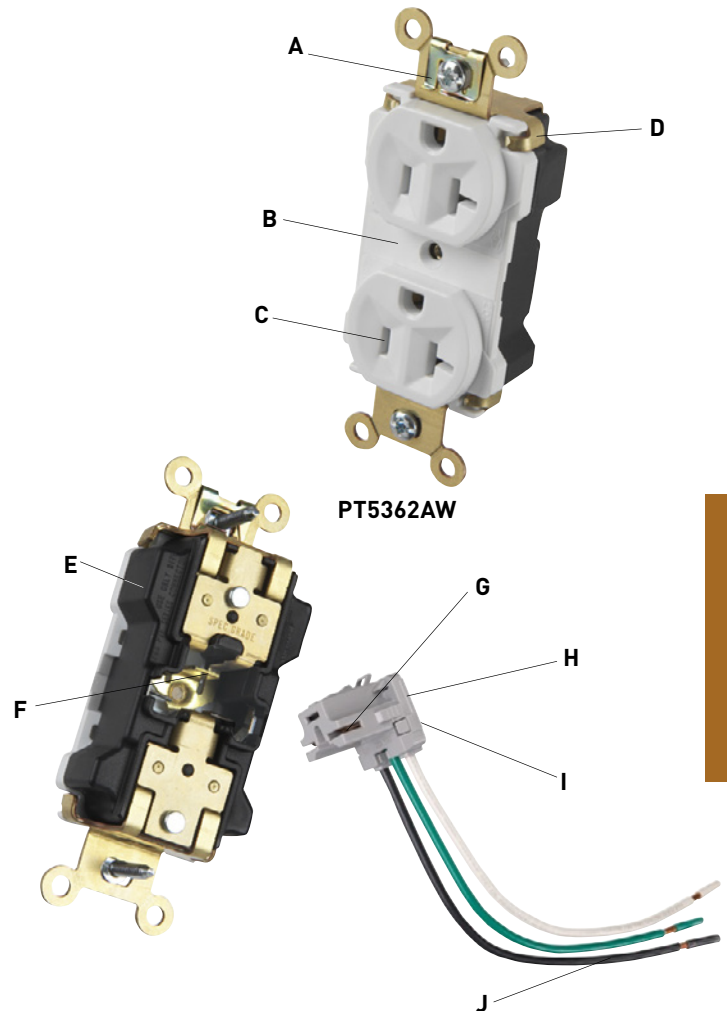


STRAIGHT BLADE RECEPTACLES

PlugTail™ Extra Heavy-Duty Specification Grade Receptacles 15 & 20A, 125V

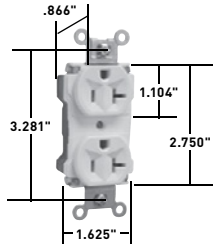

PT5362AW

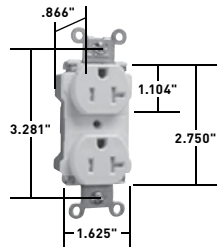

PTTR63W



PTR63STR



PTR63STRBP



PTR63STRG

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE	
	A.	V.			cULus UL498	FSUL WC596
DUPLEX RECEPTACLES						
PT5262AI	15	125	Ivory	5-15R	•	•
PT5262AW	15	125	White	5-15R	•	•
PT5262A	15	125	Brown	5-15R	•	•
PT5262AGRY	15	125	Gray	5-15R	•	•
PT5262ABK	15	125	Black	5-15R	•	•
PT5262ARED	15	125	Red	5-15R	•	•
PT5262ALA	15	125	Light Almond	5-15R	•	•
PT5262ABL	15	125	Blue	5-15R	•	•
PT5362AI	20	125	Ivory	5-20R	•	•
PT5362AW	20	125	White	5-20R	•	•
PT5362A	20	125	Brown	5-20R	•	•
PT5362AGRY	20	125	Gray	5-20R	•	•
PT5362ABK	20	125	Black	5-20R	•	•
PT5362ARED	20	125	Red	5-20R	•	•
PT5362ALA	20	125	Light Almond	5-20R	•	•
PT5362ABL	20	125	Blue	5-20R	•	•
TAMPER-RESISTANT DUPLEX RECEPTACLES						
PTTR62I	15	125	Ivory	5-15R	•	•
PTTR62W	15	125	White	5-15R	•	•
PTTR62	15	125	Brown	5-15R	•	•
PTTR62GRY	15	125	Gray	5-15R	•	•
PTTR62BK	15	125	Black	5-15R	•	•
PTTR62RED	15	125	Red	5-15R	•	•
PTTR62LA	15	125	Light Almond	5-15R	•	•
PTTR62BL	15	125	Blue	5-15R	•	•
PTTR63I	20	125	Ivory	5-20R	•	•
PTTR63W	20	125	White	5-20R	•	•
PTTR63	20	125	Brown	5-20R	•	•
PTTR63GRY	20	125	Gray	5-20R	•	•
PTTR63BK	20	125	Black	5-20R	•	•
PTTR63RED	20	125	Red	5-20R	•	•
PTTR63LA	20	125	Light Almond	5-20R	•	•
PTTR63BL	20	125	Blue	5-20R	•	•

2 Pole, 3 Wire



NEMA 5-15R



NEMA 5-20R

CATALOG NUMBER	WIRE TYPE	CONNECTOR HEAD	WIRE LENGTH
PLUGTAIL CONNECTORS – RIGHT ANGLE			
PTRA650L	Solid		6"
PTRA65STR	Stranded		6"
PTRA650LB25	Solid		25"
PTRA65STRB25	Stranded		25"
NAFTA-COMPLIANT PLUGTAIL CONNECTORS – RIGHT ANGLE			
PTRA650LNA	Solid		6"
PTRA65STRNABL	Stranded	Blue	6"
PTRA65STRNAOR	Stranded	Orange	6"
PTRA65STRNARE	Stranded	Red	6"

CATALOG NUMBER	WIRE TYPE	WIRE LENGTH
PLUGTAIL CONNECTORS – RIGHT ANGLE WITH WAGO CONNECTORS		
PTRA650LBP	Solid	6"
PTRA65STRBP	Stranded	6"
PLUGTAIL CONNECTORS – RIGHT ANGLE WITH GROUND SCREW		
PTRA650LGG	Solid	6"
PTRA65STRG	Stranded	6"

For Bulk Packaging Solutions consult factory.

NAFTA-Compliant PlugTail Connectors are ideal for use on projects subject to the provisions of the Buy American Act.

All devices listed on this page conform to NEMA WD-1 and WD-6.