


TYPE GPL

Made from high copper content alloy. Furnished with silicon bronze bolt, nuts and lockwashers.

Universal parallel or 90° cable connection to rod or pipe

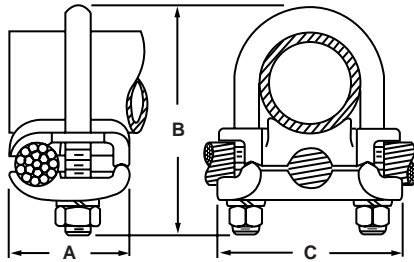

Catalog Number	Accommodates		Conductor Range	Wire Diameter Range	Approximate Dimensions						
	Rod	IPS			A		B		C		Bolt Dia.†
					in	mm	in	mm	in	mm	
GPL-1 *	1/2	1/4	8 Sol.-4 Str.	.128- .232	1 3/8	34	2 1/2	64	1 7/8	47	3/8
GPL-2 *	1/2	1/4	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	2 1/2	64	1 7/8	47	3/8
GPL-3 *	1/2	1/4	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	2 1/2	64	1 7/8	47	3/8
GPL-4	5/8 or 3/4	3/8	8 Sol.-4 Str.	.128- .232	1 3/8	34	2 3/4	70	2	51	3/8
GPL-5	5/8 or 3/4	3/8	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	2 3/4	70	2	51	3/8
GPL-6	5/8 or 3/4	3/8	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	2 3/4	70	2	51	3/8
GPL-7 •	5/8 or 1	3/8 or 3/4	300-500 MCM	.634- .815	2 1/4	57	3 1/2	89	2 3/8	60	1/2
GPL-8	7/8 or 1	1/2 or 3/4	8 Sol.-4 Str.	.128- .232	1 3/8	34	2 5/8	67	2 3/8	60	3/8
GPL-9	7/8 or 1	1/2 or 3/4	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	2 5/8	67	2 3/8	60	3/8
GPL-10	7/8 or 1	1/2 or 3/4	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	3	76	2 3/8	60	3/8
GPL-12 •	7/8 or 1	1/2 or 3/4	500-750 MCM	.815- .999	2 5/8	67	3 3/4	95	2 3/4	70	1/2
GPL-13 •	7/8 or 1	1/2 or 3/4	750-1000 MCM	.999-1.153	3	76	4	102	3 1/2	89	1/2
GPL-14	—	1	8 Sol.-4 Str.	.128- .232	1 3/8	34	2 3/4	70	2 5/8	67	3/8
GPL-15	—	1	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	2 3/4	70	2 5/8	67	3/8
GPL-16	—	1	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	3 1/4	82	2 5/8	67	3/8
GPL-17 •	—	1	300-500 MCM	.634- .815	2 3/8	60	4 1/2	115	3	76	1/2
GPL-18 •	—	1	500-750 MCM	.815- .999	2 5/8	67	4 1/2	115	3	76	1/2
GPL-19 •	—	1	750-1000 MCM	.999-1.153	3	76	4 3/4	121	3 1/2	89	1/2
GPL-20	—	1 1/4	8 Sol.-4 Str.	.128- .232	1 3/8	34	3 1/2	89	3	76	3/8
GPL-21	—	1 1/4	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	3 1/2	89	3	76	3/8
GPL-22	—	1 1/4	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	3 1/2	89	3	76	3/8
GPL-23 •	—	1 1/4	300-500 MCM	.634- .815	2 3/8	60	4 1/4	108	3 3/8	85	1/2
GPL-24 •	—	1 1/4	500-750 MCM	.815- .999	2 3/4	70	5	127	3 3/4	95	1/2
GPL-25 •	—	1 1/4	750-1000 MCM	.999-1.153	3	76	5 1/2	140	4 1/4	108	1/2
GPL-26	—	1 1/2	8 Sol.-4 Str.	.128- .232	1 3/8	34	4	102	3 1/4	82	3/8
GPL-27	—	1 1/2	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	4	102	3 1/4	82	3/8
GPL-28	—	1 1/2	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	4	102	3 1/4	82	3/8
GPL-29 •	—	1 1/2	300-500 MCM	.634- .815	2 3/8	60	4 5/8	118	3 5/8	92	1/2
GPL-30 •	—	1 1/2	500-750 MCM	.815- .999	2 3/4	70	5 1/4	133	4	102	1/2
GPL-31 •	—	1 1/2	750-1000 MCM	.999-1.153	3	76	5 3/4	146	4 1/2	115	1/2
GPL-32	—	2	8 Sol.-4 Str.	.128- .232	1 3/8	34	4 1/4	108	3 3/4	95	3/8
GPL-33	—	2	4 Sol.-2/0 Str.	.204- .419	1 5/8	41	4 1/4	108	3 3/4	95	3/8
GPL-34	—	2	2/0 Sol.-250 MCM	.365- .575	1 7/8	47	4 1/4	108	3 3/4	95	3/8
GPL-35 •	—	2	300-500 MCM	.634- .815	2 3/8	60	5 1/4	133	4	102	1/2
GPL-36 •	—	2	500-750 MCM	.815- .999	2 3/4	70	5 1/2	140	4 1/2	115	1/2
GPL-37 •	—	2	750-1000 MCM	.999-1.153	3	76	6	152	5	127	1/2

Chart continued next page

*UL listing is limited to a maximum wire size of 250 MCM.

*Not UL listed for 1/4" Pipe.

†3/8" U-Bolt threaded as shown above, add suffix "FT" for full thread. 1/2" U-Bolt standard is full thread.