

# ★ LED Step Lights PROGRESS LED

5W LED WITH THE LUMEN OUTPUT COMPARABLE TO A 7W CFL OR 25W INCANDESCENT.  
2700K COLOR TEMPERATURE WITH 80+ CRI AND A 120° BEAM SPREAD. CRI: 80+



**P6827-09** Brushed Nickel  
**P6827-30** White  
LED step/wall lights are available in a vertical or horizontal configuration for mounting into a single-gang wallbox  
Size: 5-1/4" W. , 3-1/2" ht.  
Lamp: 5w LED (included).



**P6828-09** Brushed Nickel  
**P6828-30** White  
Step/wall lights are available in a vertical or horizontal configuration for mounting into a single-gang wallbox  
Size: 3-1/2" W. , 5-1/4" ht.  
Lamp: 5w LED (included).



**P6829-09** Brushed Nickel  
**P6829-20** Antique Bronze  
**P6829-30** White  
**P6829-31** Black  
Mini decorative vertical step/wall light. Wet location listed.  
Dimensions: 2-7/8" W., 4-1/2" ht.  
Lamp: 5w LED (included).




**P6832-09** Brushed Nickel  
**P6832-20** Antique Bronze  
**P6832-30** White  
**P6832-31** Black  
Mini decorative vertical step/wall light. Wet location listed.  
Dimensions: 2-7/8" ht., 4-1/2" W.  
Lamp: 5w LED (included).


# ★ Step Lights




**P6802-31** Black P6802-31, P6803-31  
Cast aluminum housing with black aluminum louver. For wood, brick, masonry, and poured concrete installations. IC Rated.  
Size: Refer to diagram.  
Lamp: One 7w 2-pin twin compact fluorescent lamp.

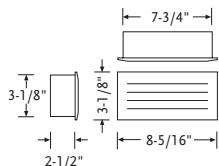


**P6803-31** Black P6803-31, P6803-30  
**P6803-30** White  
Cast aluminum housing with metal louver. For wood, brick, masonry, and poured concrete installations. With Therma-Gard protection.  
Size: Refer to diagram.  
Lamp: One 25w 120V T6-1/2, intermediate base.

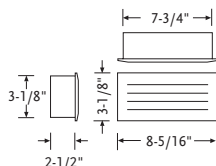

**P6817-16** Satin Aluminum P6817-16  
**P6817-31** Black  
Cast aluminum, tempered glass with louver faceplate. Two 1/2" I.P. for conduit entry. For poured concrete and masonry installations.  
Size: Refer to diagram.  
Lamp: One medium base; 25w max.

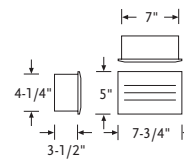

**P6819-16** Satin Aluminum P6819-16  
Cast aluminum, tempered glass with louver faceplate. Two 1/2" I.P. for conduit entry. For poured concrete and masonry installations.  
Size: Refer to diagram.  
Lamp: One medium base; 75w max.

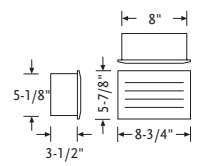

# Steps, Corridors and Walls

## Brick Lights – Outdoor & Indoor



### Lighting for safety in traffic areas, indoors and outdoors.


Cast aluminum housing with black metal louver. Three 1/2" I.P. conduit entries. Measures 7-3/4" x 2-1/2" x 3-1/8". For brick, masonry, and poured concrete installations. UL listed for wet locations.

**P6802-31** Black .  
Lamp: One 7w compact fluorescent lamp.



**P6803-30** White  
**P6803-31** Black  
Therma-Gard protection.  
Lamp: One 120V T6-1/2 25w intermediate base.

**P6805-31** Black  
Lamp: One 120v 13w 2pin twin CFL GX23 base.

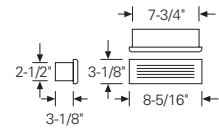

## Indoor & Protected Outdoor



Spring-held white louver faceplate. Metal housing has 1/2" I.P. conduit entry. For indoor and protected outdoor use. UL listed for damp locations. Sheet rock or dry wall installations.


**P6820-30TG\*** White  
Therma-Gard protection. Porcelain socket. Lamp: One 60w A19

**P6820-31TG\*** Black  
Therma-Gard protection. Porcelain socket. Lamp: One 60w A19

**P6821-30\*** White  
Standard 120V NPF ballast.  
Lamp: One 7w or 9w twin CFL lamp.



**P6826-30\*** White  
Compact fluorescent.  
Same as P6821-30 except with a shatter-resistant white acrylic faceplate.  
Lamp: One 7w or 9w twin CFL lamp.

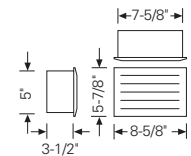

## Thru-Wall Double Face




One metal housing with two shatter-resistant white acrylic faceplates for both sides of a stud wall, 3-1/2" to 4-1/2" thick. White trim. Reduces costs by illuminating two areas with one fluorescent light. For indoor and protected outdoor use. UL listed for damp locations. Sheet rock or dry wall installations.

**P6824-30\*** White  
Compact fluorescent.  
Lamp: One 7w or 9w twin CFL lamp.



**P6825-30\*** White  
Same as P6824-30 except with two louver faceplates.  
Lamp: One 7w or 9w twin CFL lamp.

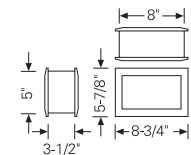

## Indoor & Outdoor



P6816-16



P6818-16

Cast aluminum, porcelain socket, reflector, tempered glass. Two 1/2" I.P. for conduit entry. For poured concrete and masonry installations only. UL listed for wet locations.

**P6816-16** Satin Aluminum  
White glass face.  
Lamp: One 25w A-19.


**P6818-16** Satin Aluminum  
White glass face.  
Lamp: One 75w A-19.

**P6817-16** Satin Aluminum  
Louver faceplate over glass.  
Lamp: One 25w A-19.


**P6817-31** Black  
Louver faceplate over glass.  
Lamp: One 25w A-19.

**P6819-16** Satin Aluminum  
Louver faceplate over glass.  
Lamp: One 75w A-19.

**P6816-16 & P6817-16,31**

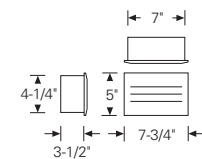

**P6818-16 & P6819-16**

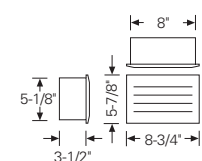

P6817-31



P6819-16

\* Requires accessory bar hanger kit, P8716-01 for installation to wood studs.