

METER SOCKET ACCESSORIES

Fifth Jaw Assemblies




	CATALOGUE NUMBER	R3	BA3	BE1	BQ2 / BS2
Standard capacity 9 o'clock position	C205	✓	✓	✓	✓
Full capacity 9 o'clock position	Z105*	✓	✓	✓	
	Z205*				✓
Full capacity 6 o'clock position	CM-B106*			✓	✓
	B206*				Units with "R" bridges only
	B306*† (mono block application)				✓

* CSA not applicable

† For mono blocks only

Pole Mount Bracket Kit

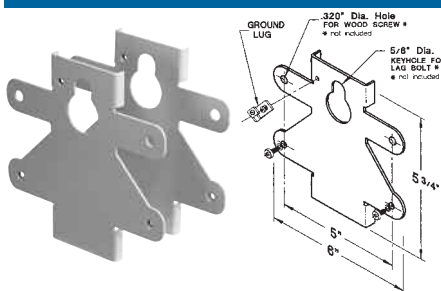


PMB200


- Secures Microelectric meter socket to a wooden pole via:
Option 1 - Use a lag bolt through 5/8" center keyhole
Option 2 - Use the two side bracket mounting holes (0.320" dia.) to wrap around the pole
- Attach meter socket using one or two bracket(s). PMB200 kit comes complete with 2 brackets, 1 ground connector. Conductor range: 14-2 AWG. Includes assembly hardware

Note: Suitable for any Microelectric meter socket with mounting holes 5" apart. Use with model series: BA3, BE1, BQ2, CL, C01, C02, CT, M02, PL17, PL27, VT.


Pole Line Hardware

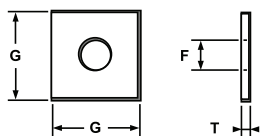

CATALOGUE NUMBER	DESCRIPTION	BOLT SIZE (in.)	G SIZE (in.)	T THICK. (in.)	WEIGHT (100 PCS)		STD. PKG
					lb.	kg	
RC729	Square washer	5/8	2	3/16	22	10.0	400

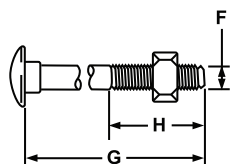

CATALOGUE NUMBER	DESCRIPTION	F DIA. (in.)	G LENGTH (in.)	H MIN. (in.)	WEIGHT (100 PCS)		STD. PKG
					lb.	kg	
BC301L	Carriage bolt	3/8	1-1/2	1-1/2	11	5.0	50

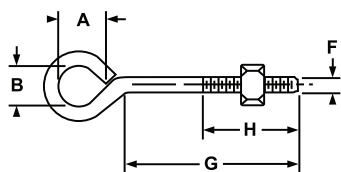

CATALOGUE NUMBER	DESCRIPTION	F DIA. (in.)	G LENGTH (in.)	H MIN. (in.)	WEIGHT (100 PCS)		STD. PKG
					lb.	kg	
B0506	Oval eye bolt	5/8	6	3	122	55.4	50
B0508	Oval eye bolt	5/8	8	4	136	61.8	50
B0510	Oval eye bolt	5/8	10	4	150	68.1	50
B0512	Oval eye bolt	5/8	12	4	168	76.3	50