

# COMMERCIAL DIMMERS & FAN SPEED CONTROLS

## Titan® Series



**A complete solution for easy, economical multi-gang installations.**

The P&S Titan® Series dimmers have key features designed to increase installer productivity. Each comes with all the screwless wall plate components necessary for single gang or multi-gang installations. No need to order any additional components such as long-lead time custom wall plates to finish the job. Complete the installation with everything right out of the box, increasing productivity by finishing up in one visit instead of several.

### CD703PW

#### Titan Commercial Dimmers

- A. Exclusive labeling system** has a built-in label holder enabling instant circuit identification; looks clean and professional.
- B. Included end-caps and spacers** screw directly to heat sinks; center plate snaps easily on and off.
- C. Enclosed slider** helps prevent dust and dirt contamination.
- D. Exclusive adjustable limit control in incandescent dimmers** saves energy and extends bulb life — reduces maximum output by up to 10 percent.
- E. Air-gap switch**
- F. Improved heat management** enables superior load ratings.


**Included screwless wall plate components** make it easy to assemble a custom multi-gang wall plate in any configuration — saving money and time.

**Preset models** feature large ON/OFF button and single pole/three-way functionality.

**High-reliability design** with built-in surge and static protection plus oversize output devices to stand up to abuse.

**Power-failure memory** retains presets through power outages.

**Widest choice of amperage ratings** with minimal or no de-rating for faster job planning.

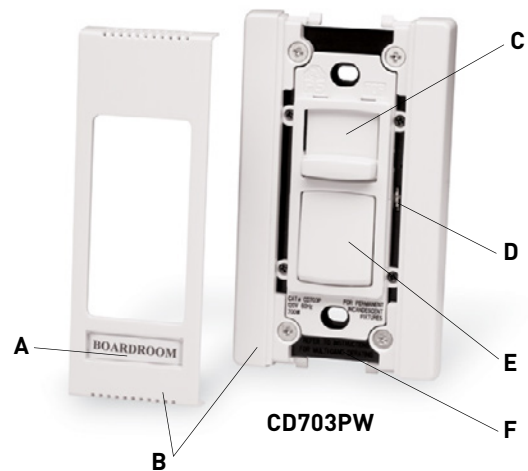


**CDADAPTORKITW**




**Adaptor kit enables matching installation of standard P&S Decorator Devices** — outlets, switches, GFCIs and more.

## COMMERCIAL DIMMERS &amp; FAN SPEED CONTROLS

## Titan® Series Magnetic Low-Voltage Dimmers &amp; Adaptor Kit

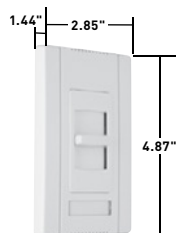

CDLV700W - Narrow

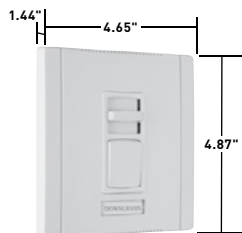


CDLV1103PW - Wide

CATALOG NUMBER	DESCRIPTION	RATINGS	NARROW OR WIDE	COLOR
<b>MAGNETIC LOW-VOLTAGE</b>				
CDLV700I CDLV700W CDLV700 CDLV700GRY CDLV700BK CDLV700LA	Single Pole, Slide-to-OFF	120V, 700W	Narrow	Ivory White Brown Gray Black Light Almond
CDLV703PI CDLV703PW CDLV703P CDLV703PGRY CDLV703PBK CDLV703PLA	Single Pole/3-Way, Preset	120V, 700W	Narrow	Ivory White Brown Gray Black Light Almond
CDLV1100I CDLV1100W CDLV1100 CDLV1100GRY CDLV1100BK CDLV1100LA	Single Pole, Slide-to-OFF	120V, 1100W	Narrow	Ivory White Brown Gray Black Light Almond
CDLV1103PI CDLV1103PW CDLV1103P CDLV1103PGRY CDLV1103PBK CDLV1103PLA	Single Pole/3-Way, Preset	120V, 1100W	Narrow	Ivory White Brown Gray Black Light Almond
CDLV1600I CDLV1600W CDLV1600 CDLV1600GRY CDLV1600BK CDLV1600LA	Single Pole, Slide-to-OFF	120V, 1600W	Wide	Ivory White Brown Gray Black Light Almond
CDLV1603PI CDLV1603PW CDLV1603P CDLV1603PGRY CDLV1603PBK CDLV1603PLA	Single Pole/3-Way, Preset	120V, 1600W	Wide	Ivory White Brown Gray Black Light Almond
<b>ADAPTOR KIT</b>				
CDADAPTORKITI CDADAPTORKITW CDADAPTORKIT CDADAPTORKITGRY CDADAPTORKITBK CDADAPTORKITLA	Decorator Device Adaptor Kit		Narrow	Ivory White Brown Gray Black Light Almond

## Features

- Field configurable wall plate system.
- Labeling system.
- Adjustable low end output voltage.
- Shipped with protective film.
- Rugged construction.
- Superior ratings with a minimum of de-rating when ganged.
- Simple to plan the rough-in.
- Available in single pole slide-to-OFF and single pole/3-way preset models.
- Attractive European styling.
- Eye-catching packaging.
- Exclusive adaptor kit to install other Decorator opening devices under the Titan® wall plate system.
- Blank center plate included.

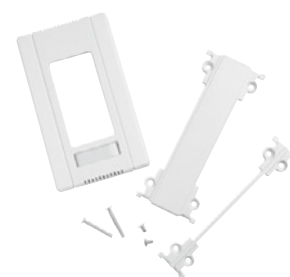


CDADAPTORKITW

Adaptor kit enables matching installation of standard P&S Decorator Devices – outlets, switches, GFCIs and more. See Page L-23.

# DEVICES & WALL PLATES

## Color Selection Chart

### Devices & Plastic Wall Plate Colors

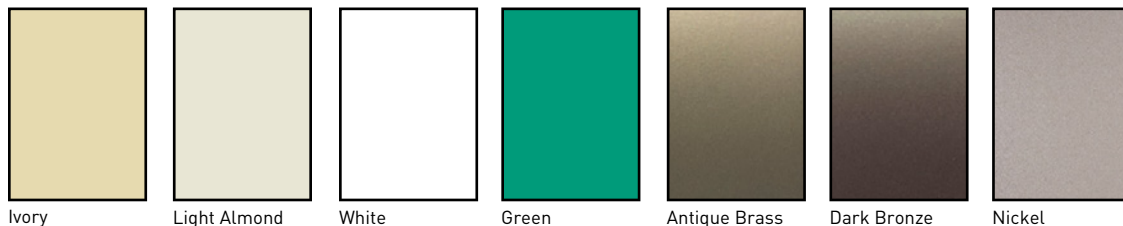

Ivory

Light Almond


White

Green

Antique Brass

Dark Bronze

Nickel

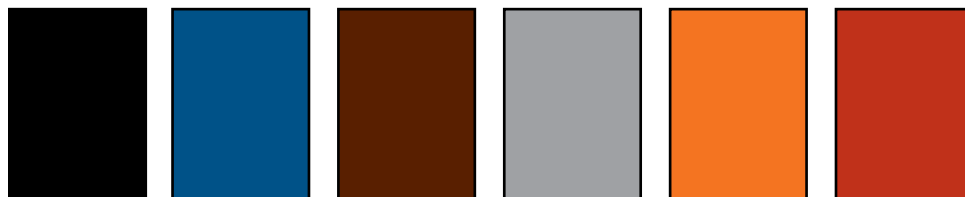

Black

Blue

Brown

Gray


Orange

Red

See specific device and wall plate catalog charts for particular color availabilities.

### Metal Wall Plates

#### Metal Finish

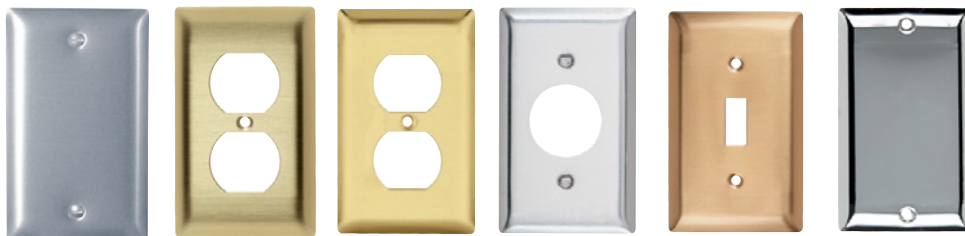

Aluminum

Brass (Brushed)

Polished Brass


Stainless Steel

Brushed Bronze

Chrome

### Custom Metal Wall Plates Paint Finish Colors

#### Paint Color

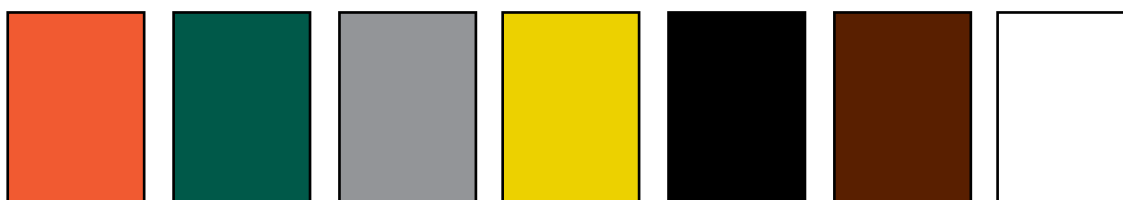

Orange

Green

Gray

Yellow

Glossy Black

Brown

White



Primer

Red

Pink

Flat Black

Ivory

Light Almond

Blue

To order custom metal wall plates, see Pages P-40 – P-42.

**For additional colors consult factory.**