

Ordering information

Accessories

OXS6X_
S01026A




Shafts

The type and ordering numbers are for one piece

OX6X_
S04118



OSP6X_
S00050A

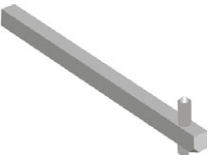

Shaft length [mm]	H [mm]	Suitable for switches	Type	Order number	Delivery batch [pcs]	Weight/unit [kg]
For selector type handles, shaft diameter 6 mm						
85	See dimension drawings	OT16...125F, OTDC16...32F	OXS6X85	1SCA101647R1001	10	0.02
105		OT16...125F, OTDC16...32F	OXS6X105	1SCA108043R1001	10	0.02
120		OT16...125F, OTDC16...32F	OXS6X120	1SCA101654R1001	10	0.03
130		OT16...125F, OTDC16...32F	OXS6X130	1SCA101655R1001	10	0.03
160		OT16...125F, OTDC16...32F	OXS6X160	1SCA101656R1001	10	0.04
180		OT16...125F	OXS6X180	1SCA101659R1001	10	0.04
250		OT16...125F	OXS6X250	1SCA101660R1001	10	0.05
330		OT16...125F	OXS6X330	1SCA101661R1001	10	0.05
For round padlockable type handles, shaft diameter 6 mm						
60	See dimension drawings	OT16...125F	OX6X60	1SCA111459R1001	10	0.02
85		OT16...125F	OX6X85	1SCA111274R1001	10	0.02
105		OT16...125F	OX6X105	1SCA111930R1001	10	0.02
115		OT16...125F	OX6X115	1SCA111931R1001	10	0.03
130		OT16...125F	OX6X130	1SCA111460R1001	10	0.03
155		OT16...125F	OX6X155	1SCA111275R1001	10	0.04
200		OT16...125F	OX6X200	1SCA111932R1001	10	0.04
300		OT16...125F	OX6X300	1SCA111933R1001	10	0.05
For pistol type handles, shaft diameter 6 mm.						
150	See dimension drawings	OT16...125F	OSP6X150	1SCA022295R5600	10	0.05
170		OT16...125F	OSP6X170	1SCA108224R1001	10	0.05
265		OT16...125F	OSP6X265	1SCA108225R1001	10	0.08
400		OT16...125F	OSP6X400	1SCA108226R1001	10	0.12
Shaft diameter 6 mm ¹⁾						
130	109...174	OT160EV...250	OSP6X130	1SCA022057R0570	10	0.04
150	129...194	OT160EV...250	OSP6X150	1SCA022295R5600	10	0.05
161	140...205	OT160EV...250	OSP6X161	1SCA022067R1760	10	0.05
210	189...254	OT160EV...250	OSP6X210	1SCA022295R6080	10	0.06
290	269...334	OT160EV...250	OSP6X290	1SCA022042R6370	10	0.08

¹⁾ Longer shafts on request