

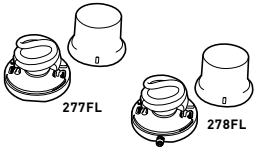
ELECTRICAL ACCESSORIES

Incandescent Lampholders

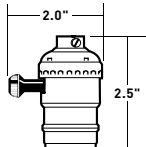
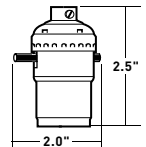
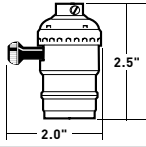
 
MEDIUM BASE LAMP HOLDERS

	CATALOG NUMBER	RATING		DESCRIPTION	COLOR	cULus	UL	CSA
 272WH	272	660W	250V	Medium base, porcelain, one piece keyless, 2 terminals with tri-drive screws, fits 3-1/4" and 4" boxes, with cage neck.	White		•	•
	272WH6	660W	250V	Same with 6" leads.	White		•	•
	274	660W	250V	Medium base, porcelain, one piece keyless, 4 terminals with tri-drive screws, fits 3-1/4" and 4" boxes.	White		•	•
	276WH	660W	250V	Medium base, phenolic, one-piece keyless, 4 terminals with tri-drive screws, fits 3-1/4" and 4" boxes, with cage neck.	White		•	•
	276WH6	660W	250V	Same with 6" leads.	White		•	•
 282WH	282	250W	250V	Medium base, porcelain, pullchain, 2 terminals with tri-drive screws, fits 3-1/4" and 4" boxes, with cage neck.	White		•	•
	284	250W	250V	Medium base, porcelain, pullchain, 4 terminals with tri-drive screws, fits 3-1/4" and 4" boxes, with cage neck.	White		•	•
	280WH	250W	250V	Medium base, phenolic, pullchain, 4 terminals with tri-drive screws, fits 3-1/4" and 4" boxes, with cage neck.	White		•	•
	280WH6	250W	250V	Same with 6" leads.	White		•	•
 298	29816C2	250W	250V	Medium base, porcelain, pullchain, 2 terminals with tri-drive screws, 6" leads, fits 3-1/4" and 4" boxes with cage neck.	White		•	•
	288	250W	125V	Medium base, porcelain, pullchain, 2 terminals with tri-drive screws, 15A 125V grounding receptacle, fits 3-1/4" and 4" boxes, with cage neck.	White		•	•

CFL LAMP HOLDERS

 277FL	277FL	13W	120V, 60Hz	Compact Fluorescent Lampholder, includes GU24 lamp, Energy Star qualified	White	•		
	278FL	13W	120V, 60Hz	Compact Fluorescent Lampholder with pull chain, includes GU24 lamp, Energy Star qualified	White	•		

METAL SHELL LAMP HOLDERS

 7070PG, 7090PG	7070PG	250W	250V	Medium base, metal shell, removable turn knob, electrolier, 2 lamp controls, 3 terminals, 1st ON, 2nd ON, both ON, OFF sequence.			•	•
	7090PG	250W	250V	Medium base, metal shell, removable turn knob, electrolier, 3-way LO-MED-HIGH.			•	
	7090M			Interior only for 7090-PG.			•	
	7090MH			Interior only with hickey for 7090-PG.			•	
 6098PG	6098PG	660W	250V	Medium base, push through, metal shell, electrolier, single circuit.			•	•
 1008316	1008316	250W	250V	Medium base, metal shell, removable turn knob, single circuit, electrolier, 1/8" IPS tapped bushing with set screw.			•	
	10083M			Interior only for 10083-16.			•	
 19980PG	19980PG	660W	250V	Medium base, metal shell, pull chain, electrolier, single circuit, 1/8" IPS bushing with set screw.			•	•
	8002M			Interior only for 19980.			•	