


T&B Conduit Fittings

Armoured Cable and Flexible Metal Conduit Fittings




Combination Coupling

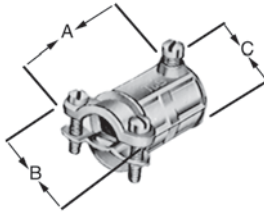

Cat. No.	Size Flex to EMT	Dimension (in.)		
		A	B	C
449C	3/8" - 1/2"	1-21/32	1-11/32	15/16

Cable opening: max. .656, min. .250

A one piece fitting that couples 3/8" flexible metal conduit to 1/2" electrical metallic tubing (EMT)

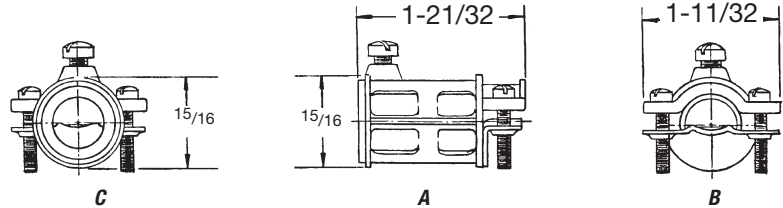

Anti-short bushings are made of smooth plastic, and designed to protect conductor insulation from rough edges of armoured cable and flexible metal conduit.

Anti-Short Bushing

Cat. No.	Size
390	14-2, 14-3, 12-2
391	14-4, 12-3, 6-1, and 4-1
392	12-4, 10-2, 10-3 and 2-1
393	10-4, 8-2, 8-3, and 1-1
394	8-4, 6-2, 6-3, 4-2, 4-3, and 6-4

Colorized
Temperature Rating: 240°F
U.L. not applicable.



Strap



Cat. No.	Bolt Hole Dia.	Size
65C	.265"	3/8" Flex