

# Voice/Data/Video

## Modular/Coax Connectors and Accessories

### Klein Tools' Universal Compression Connector


Installs up to 5x faster!



Compact ferrule

Patented universal sleeve design provides excellent holding power and signal strength.

### Standard Compression Connector

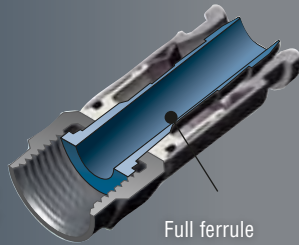

Full ferrule

### Modular Connector



Klein's data and telephone plugs are professional-grade and deliver consistent, reliable performance. They feature thick 50 micro-inch gold plating on the contact plates, three-pronged solid and stranded wire contacts, and durable connector housings.

## Universal Compression Connectors

- Fit all manufacturers' diameter variations within a cable series.

### F • RG6-RG6Q



VDV812-612

### BNC • RG6-RG6Q



VDV813-613

### RCA • RG6-RG6Q



VDV813-614

### F • RG59



VDV812-615

### BNC • RG59



VDV813-619

### RCA • RG59



VDV813-620

Cat. No.	Connector Type	Cable Type	Pack Qty.
VDV812-618	F-Connector	RG59	50
VDV812-612	F-Connector	RG6 - RG6Q	50
VDV813-619	BNC Connector	RG59	35
VDV813-613	BNC Connector	RG6 - RG6Q	35
VDV813-620	RCA Connector	RG59	35
VDV813-614	RCA Connector	RG6 - RG6Q	35

## Compression Connectors

- Full ferrule design.



VDV812-623

Cat. No.	Connector Type	Cable Type	Pack Qty.
VDV812-623	F-Connector	RG6	10
VDV812-624	F-Connector	RG6	50



## RJ45 Modular Data/RJ11 Telephone Plugs

- Three-pronged contacts for more reliable connections.



VDV826-628



VDV826-600



VDV826-604  
(26-22 AWG)



VDV826-605  
(26-19 AWG)

Cat. No.	Connector Type	Cable Type	Position & Contacts	Pack Qty.
VDV826-628	RJ45	CAT 5 / CAT 5e	8C8P	10
VDV826-602	RJ45	CAT 5 / CAT 5e	8C8P	50
VDV826-611	RJ45	CAT 5 / CAT 5e	8C8P	100
VDV826-603	RJ45	CAT 6	8C8P	25
VDV826-601	RJ11	CAT 4	6P4C	25
VDV826-600	RJ11	CAT 4	6P6C	25
VDV826-604	UY	twisted pair	2P2C	25
VDV826-605	UR	twisted pair	3P3C	25



# Reference Guide

Cat. No.	UPC # 0-92644+	Description
<b>FISH TAPES AND ACCESSORIES</b>		
56055	56055-2	100' Multi-Groove Fiberglass Fish Tape – 7" leader
56056	56056-9	200' Multi-Groove Fiberglass Fish – 7" leader
56057	56057-6	50' Non-Conductive Multi-Groove Fiberglass Fish Tape
56058	56058-3	100' Non-Conductive Multi-Groove Fiberglass
56059	56059-0	200' Non-Conductive Multi-Groove Fiberglass
56000	56000-2	25' Steel Fish Tape
56001	56001-9	50' Steel Fish Tape
56002	56002-6	65' Steel Fish Tape
56003	56003-3	125' Steel Fish Tape
56004	56004-0	240' Steel Fish Tape
56005	56005-7	25' Steel Fish Tape
56006	56006-4	100' Steel Fish Tape
56007	56007-1	125' Stainless Steel Fish Tape
56008	56008-8	240' Stainless Steel Fish Tape
56013	56013-2	50' Spiral Steel Fish Tape
56065	56065-1	65' Steel Replacement Fish Tape
56125	56125-2	125' Steel Replacement Fish Tape
56240	56240-2	240' Steel Replacement Fish Tape
<b>Pull Line</b>		
56108	56108-5	500' Poly Pull Line
56110	56110-8	6500' Poly Pull Line
<b>Lubricants</b>		
51100	51100-4	Foam Wire Pulling Lubricant - 19 oz. can
<b>Splinter-Guard™ Fish and Glow Rods</b>		
56326	56326-3	Deluxe Fish Rod Kit
56304	56304-1	4' Lo-Flex Fish Rod
56306	56306-5	6' Lo-Flex Fish Rod
56312	56312-6	12' Lo-Flex Fish Rod Set
56324	56324-9	24' Lo-Flex Fish Rod Set
56325	56325-6	25' Fish and Glow Rod Set
56405	56405-5	5' Mid-Flex Glow Rod
56406	56406-2	6' Hi-Flex Glow Rod
56409	56409-3	9' Mid-Flex Glow Rod Set
56415	56415-4	15' Mid-Flex Glow Rod Set
56418	56418-5	18' Hi-Flex Glow Rod Set
56119	56119-1	Illuminated Fish Rod Tip
<b>Conduit Benders</b>		
56203	56203-7	Iron Bender w/ Handle – 1/2" EMT
56204	56204-4	Iron Bender w/ Handle – 3/4" EMT
56205	56205-1	Iron Bender w/ Handle – 1" EMT
56206	56206-8	Aluminum Bender w/ Handle – 1/2" EMT
56207	56207-5	Aluminum Bender w/ Handle – 3/4" EMT
56208	56208-2	1/2" Iron Conduit Bender Head
56209	56209-9	3/4" Iron Bender Head
56210	56210-5	1" Iron Bender Head
56211	56211-2	1-1/4" Iron Bender Head
51427	51427-2	Handle for 1/2" & 3/4" EMT Benders
51428	51428-9	Handle for 1" EMT Benders
51429	51429-6	Handle for 1-1/4" EMT Benders
<b>VOICE/DATA/VIDEO TEST AND MEASUREMENT</b>		
VDV501-828	58211-0	VDV Commander™ Test Kit
VDV501-829	58212-7	VDV Commander™ Test and Tone Kit
VDV501-815	58187-8	VDV Ranger™ TDR Kit
VDV501-823	58196-0	VDV Scout® Pro 2 Tester Kit
VDV501-824	58197-7	VDV Scout® Pro 2 Tester & Test-n-Map™ Remote Kit
VDV501-825	58198-4	VDV Scout® Pro 2 LT Tester & Remote Kit
VDV501-826	58199-1	VDV Scout® Pro 2 LT Tester & Test-n-Map™ Remote Kit
VDV770-827	58200-4	VDV Scout® Pro 2 Test-n-Map™ Remote Kit
<b>VDV ProTech™ Kits</b>		
VDV026-831	58248-6	ProTech™ Data Kit
VDV011-832	58249-3	ProTech™ Coaxial Kit
VDV001-833	58250-9	ProTech™ Data & Coaxial Kit

Cat. No.	UPC #0-92644+	Description
<b>VDV Connectors</b>		
VDV812-612	58148-9	Universal F Connector – RG6/6Q (50-Pack)
VDV812-618	58158-8	Universal F Connector – RG59 (50-Pack)
VDV813-613	58149-6	Universal BNC Connector – RG6/6Q (35-Pk)
VDV813-614	58150-2	Universal RCA Connector – RG6/6Q (35-Pk)
VDV813-619	58159-5	Universal BNC Connector – RG59 (35-Pk)
VDV813-620	58160-1	Universal RCA Connector – RG59 (35-Pk)
VDV812-624	58164-9	Standard F Connector – RG6 (50-Pk)
VDV826-600	58136-6	Telephone Plug – RJ11 – 6P6C (25-Pk)
VDV826-601	58137-3	Telephone Plug – RJ11 – 6P4C (25-Pk)
VDV826-602	58138-0	Modular Data Plug – RJ45 – CAT5e (50-Pk)
VDV826-603	58139-7	Modular Data Plug – RJ45 – CAT6 (25-Pk)
VDV826-604	58140-3	UY IDC Connector – UY 22-26 AWG (25-Pk)
VDV826-605	58141-0	UR IDC Connector – UR 19-26 AWG (25-Pk)
VDV826-611	58147-2	Modular Data Plug – RJ45 – CAT5e (100-Pk)
VDV826-628	58168-7	Modular Data – RJ45 – CAT5e (10-Pk)
<b>ELECTRICAL TEST AND MEASUREMENT</b>		
MM1300	69154-6	Electrician's/HVAC Multimeter
MM1300N	69654-1	Electrician's/HVAC Multimeter w/ NIST Cert.
MM2300	69155-3	Electrician's/HVAC TRMS Multimeter
MM2300N	69655-8	Electrician's/HVAC TRMS Multimeter w/ NIST Cert.
MM500	69158-4	Auto Ranging Multimeter
MM5000	69156-0	Electrician's TRMS Multimeter
MM5000N	69656-5	Electrician's TRMS Multimeter w/ NIST Cert.
MM6000	69157-7	Electrician's / HVAC TRMS Multimeter
MM6000N	69657-2	Electrician's / HVAC TRMS Multimeter w/ NIST Cert.
CL1200	69212-3	600A AC Clamp Meter
CL1200N	69712-8	600A AC Clamp Meter w/ NIST Cert.
CL2200	69214-7	600A AC/DC True RMS Clamp Meter
CL2200N	69714-2	600A AC/DC True RMS Clamp Meter w/ NIST Cert.
CL2300	69215-4	600A AC/DC TRMS Clamp Meter w/ Temp.
CL2300N	69715-9	600A AC/DC TRMS Clamp Meter w/ Temp.w/ NIST Cert.
CL2500	69207-9	1000A AC/DC TRMS Clamp Meter
CL2500N	69707-4	1000A AC/DC TRMS Clamp Meter w/ NIST Cert.
CL3200	69208-6	200A AC Fork Tester
CL3200N	69708-1	200A AC Fork Tester w/ NIST Cert.
IR2000A	69309-0	Infrared Thermometer
NCVT-2	69002-0	Dual Range Non-Contact Voltage Tester
69416	69416-5	Silicone Test Leads
<b>PERSONAL PROTECTIVE EQUIPMENT</b>		
<b>Protective Eyewear</b>		
60046	60046-3	Standard Eyewear – Dark Gray Lens
60047	60047-0	Standard Eyewear – SCT Gray Lens
60049	60049-4	Standard Eyewear – Amber Lens
60053	60053-1	Standard Eyewear – Clear
60054	60054-8	Standard Eyewear – Clear
60055	60055-5	Standard Eyewear – Espresso
60056	60056-2	Frameless Eyewear – Clear
60057	60057-9	Frameless Eyewear – Espresso
<b>Hard Hats and Accessories</b>		
60009	60009-8	Standard Hard Cap, White
60010	60010-4	Standard Hard Cap, Yellow
60011	60011-1	Standard Hard Cap, Blue
60025	60025-8	Advance® Hard Cap, White
60027	60027-2	Advance® Hard Cap, Blue
60028	60028-9	V-Gard® Hard Hat, White
60030	60030-2	V-Gard® Hard Hat, Blue
60031	60031-9	V-Gard® Hard Hat, White
60060	60060-9	Full Face Shield
<b>Lockouts, Barricade Tape and Cleaners</b>		
45200	45200-0	Lockouts w/Interlocking Tabs
45201	45201-7	Lockouts w/Interlocking Tabs
58000	58000-0	200' CAUTION Tape
58001	58001-7	1000' CAUTION Tape
58002	58002-4	200' CAUTION/BURIED ELECTRIC LINE Tape