

Weatherproof Metallic Covers

Single-Gang Device Covers



CCD

CAT. NO.	COLOR	DESCRIPTION
Duplex Receptacle Cover, Horizontal		
CCD	Silver	Device Mount
CCD-L	Silver	Device Mount with Lock Option
CCD-FS	Silver	Box Mount
WR81-CN	Natural	Cover, Stay-Open Lid
WRH80-C	Gray	Cover, Self-Closing Lids

D-PAK®

DCCD-P	Silver	Non-Metallic Device Mount
DCCD	Silver	Device Mount
DCCD-BR	Bronze	Device Mount
DCCD-WH	White	Device Mount
DCCDSO	Silver	Device Mount, Stay Open
DCCDSO-BR	Bronze	Device Mount, Stay Open
DCCDSO-WH	White	Device Mount, Stay Open

Duplex Receptacle Cover, Vertical

CCDV	Silver	Device Mount
CCDV-L	Silver	Device Mount with Lock Option

D-PAK®

DCCDV	Silver	Device Mount
DCCDV-BR	Bronze	Device Mount
DCCDV-WH	White	Device Mount

GFCI Receptacle Cover, Horizontal

CCG	Silver	Device Mount
CCG-FS	Silver	Box Mount

D-PAK®

DCCG	Silver	Device Mount
DCCG-BR	Bronze	Device Mount
DCCG-WH	White	Device Mount

GFCI Receptacle Cover, Vertical

CCGV	Silver	Device Mount
CCGV-L	Silver	Device Mount with Lock Option

D-PAK®

DCCGV	Silver	Device Mount
DCCGV-BR	Bronze	Device Mount
DCCGV-WH	White	Device Mount



CCDV



CCG



CCGV



CCS



CCSV



CCSV-TL



CCMB



CCT-1

CAT. NO.	COLOR	DESCRIPTION
Single Receptacle Cover, Horizontal — 1.485" Diameter Opening		
CCS	Silver	Device Mount

Single Receptacle Cover, Vertical — 1.59"/2.156" Diameter Opening

CCSV	Silver	Device Mount
CCSV-L	Silver	Device Mount with Lock Option
CCPO	Silver	Power Outlet Cover with 2.156" Diameter Opening, Box Mount
CCPO-L	Silver	Box Mount with Lock Option

Single Receptacle Cover, Vertical — 1.59" Opening

CCSV-TL	Silver	Device Mount Integral Locking Hasp
---------	--------	------------------------------------

Motor Base Plug and Cover, Horizontal

CCMB	Silver	Device Mount 15A, 125V Motor Base Plug
------	--------	--

Switch Cover Only

CCT	Silver	Device Mount Switch Cover Only, Packed with Spacers and Screws
-----	--------	--

Switch Cover with Switch

CCT-1	Silver	Single-Pole 15A, 125V
CCT-1-20	Silver	Single-Pole 20A, 120-277V
CCT-3	Silver	3-Way Switch 15A, 125V

Note: Raintight when used with appropriate Red•Dot® boxes.

SW1	Silver	One-Gang Cover with 10A, 125V Single-Pole Switch
-----	--------	--

SW2	Silver	One-Gang Cover with 10A, 125V Double-Pole Switch
-----	--------	--

SW20-1/710	Silver	One-Gang Cover with 20A, 102/277V Single-Pole Switch (special oil- and gas-resistant gasket)
------------	--------	--


SW20-2	Silver	One-Gang Cover with 20A, 102/277V Double-Pole Switch
--------	--------	--

SW20-2/710	Silver	One-Gang Cover with 20A, 102/277V Double-Pole Switch (special oil- and gas-resistant gasket)
------------	--------	--

UL Listed E-18407.

CSA Certified LR-18685.

Note: All covers packed with gasket and screws.

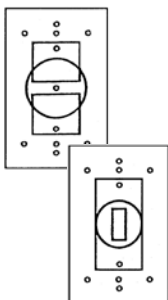

Single-Gang Gaskets

CAT. NO.	COLOR	DESCRIPTION
CCK	Black	Neoprene
CCSK	Black	Neoprene