

Oil & dust tight free standing single door enclosure

Quick Features :


- Poured gasket
- Seamless welding
- 3-point handle
- Drip shield
- Superior hinging
- 180° door opening
- 12 GA steel
- Side panels available
- Powder coated

The 9500 oil & dust tight enclosures are used indoors for protection against dust, dirt or oil splashing. The 9500 are made from quality 12 GA steel, with corner seams continuously welded. The opening has a curled lip around all sides to prevent dripping water from entering the enclosure when the door is open, it also increases rigidity. A high quality robotically poured-in-

place seamless gasket ensures a complete and durable oil & dust tight seal. The pins of the concealed hinges can be pulled out to remove the door. An automotive locking handle ensures smooth, secure 3-point latching. Optional back panels can be mounted at any depth, using the three sets of rails welded on the sides of the cabinet. Side panels can also be ordered separately.

A print pocket is provided. Double door enclosures have stiffeners welded to the back. Enclosures and panels are finished with heat fused polyester powder, electrostatically applied on a phosphatized base. Box is ANSI/ASA 61 gray, panel is white (other colors available).

CSA Certified / UL Listed
NEMA 12-13 / IP65

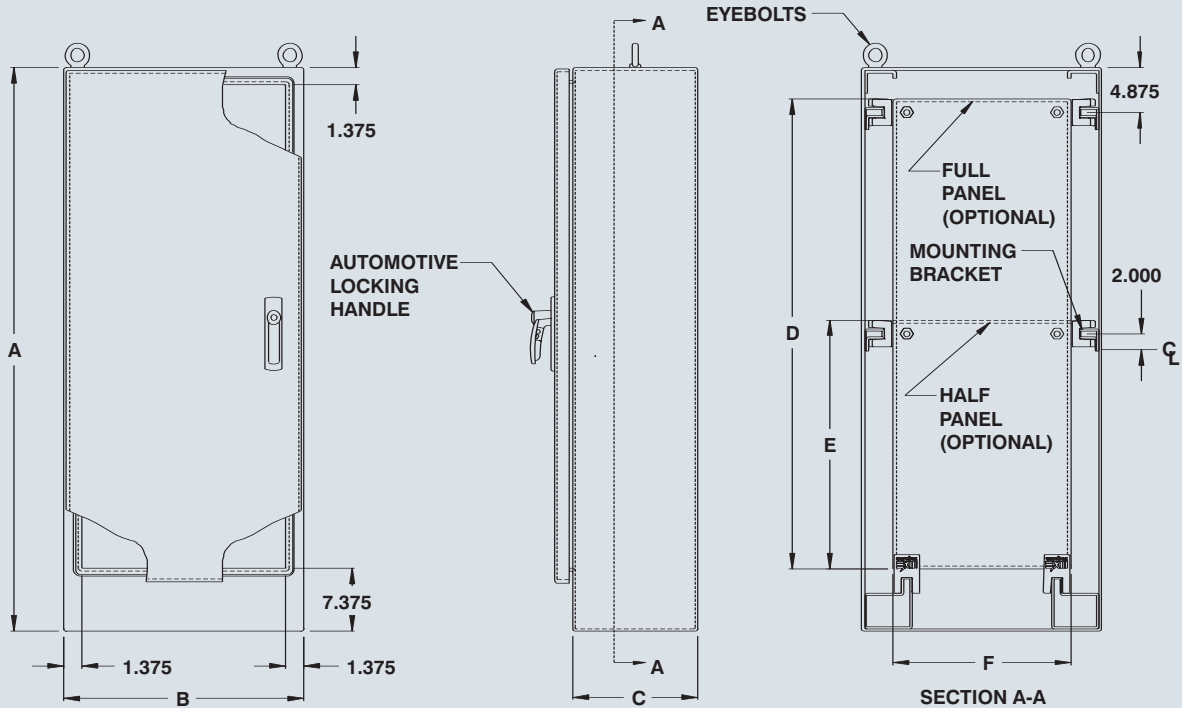

CATALOG NUMBER	DIMENSIONS						EQUIPMENT PANEL		SHIP WGT LBS.
	A	B	C	D	E	F	FULL	HALF	
9500 602418	60	24	18	48	24.875	20	889 FP6024	889 HP6024	250
9500 722418	72	24	18	60	30.875	20	889 FP7224	889 HP7224	280
9500 723018	72	30	18	60	30.875	26	889 FP7230	889 HP7230	300
9500 723618	72	36	18	60	30.875	32	889 FP7236	889 HP7236	330
9500 902420	90	24	20	78	39.875	20	889 FP9024	889 HP9024	405
9500 903620	90	36	20	78	39.875	32	889 FP9036	889 HP9036	440
9500 603624	60	36	24	48	24.875	32	889 FP6036	889 HP6036	300
9500 722424	72	24	24	60	30.875	20	889 FP7224	889 HP7224	300
9500 723024	72	30	24	60	30.875	26	889 FP7230	889 HP7230	340
9500 723624	72	36	24	60	30.875	32	889 FP7236	889 HP7236	375
9500 903624	90	36	24	78	39.875	32	889 FP9036	889 HP9036	445
9500 722430	72	24	30	60	30.875	20	889 FP7224	889 HP7224	358
9500 723630	72	36	30	60	30.875	32	889 FP7236	889 HP7236	420
9500 722436	72	24	36	60	30.875	20	889 FP7224	889 HP7224	400
9500 723636	72	36	36	60	30.875	32	889 FP7236	889 HP7236	470
9500 903636	90	36	36	78	39.875	32	889 FP9036	889 HP9036	500

Visit www.eurobex.com for details.

Call us toll free 1-800-363-2423

Data subject to change without notice.

Suggested Accessories



p.359



p.365



p.366



p.360



p.364



p.384



p.368