


Cushion-Grip Screwdrivers

Square-Recess Tip Screwdrivers – Round-Shanks

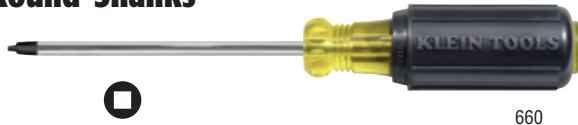

Additional Features:

- Color-coded handle ends for quick and easy identification.
- Round shank with Robertson® tip for square-recess screws.
- Chrome plated shank for corrosion resistance.

Cat. No.	Point Size	Color Code	Shank Length	Overall Length	Weight (lbs.)
660	No. 0	yellow	4" (102 mm)	7-3/4" (197 mm)	.20
661	No. 1	green	4" (102 mm)	7-3/4" (197 mm)	.20
662	No. 2	red	4" (102 mm)	8-1/4" (210 mm)	.30
663	No. 3	black	4" (102 mm)	8-1/4" (210 mm)	.30
665	No. 1	green	8" (203 mm)	11-3/4" (298 mm)	.30
666	No. 2	red	8" (203 mm)	12-1/4" (311 mm)	.40
667	No. 3	black	8" (203 mm)	12-1/4" (311 mm)	.40

Refer to the insulated section for insulated screwdrivers.
Robertson® is a trademark of Robertson Inc.

TORX® Screwdrivers – Round-Shanks



Additional Features:

- Color-coded handle ends for quick and easy identification.
- TORX® tip drive cuts slippage, saves fasteners, transmits more torque to the work.
- Chrome plated shank for corrosion resistance.

Cat. No.	TORX® Size	Color Code	Shank Length	Overall Length	Weight (lbs.)
19542	T15	yellow	4" (102 mm)	8-5/16" (211 mm)	.20
19543	T20	green	4" (102 mm)	8-5/16" (211 mm)	.25
19544	T25	blue	4" (102 mm)	8-5/16" (211 mm)	.25
19545	T27	brown	4" (102 mm)	8-5/16" (211 mm)	.25
19546	T30	red	4" (102 mm)	8-5/16" (211 mm)	.25

TORX® is a registered trademark of Acument Intellectual Properties, LLC.

Conduit-Fitting Screwdriver

Additional Feature:

- Hooded-blade design keeps tip from slipping out of screws, especially when tightening hard-to-reach screws in conduit fittings.

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
19360	3/8" (10 mm)	1" (25 mm)	5-11/32" (144 mm)	.30



Conduit-Fitting and Reaming Screwdriver

Additional Features:

- Hooded-blade design keeps tip from slipping out of screws, especially when tightening hard-to-reach conduit fittings. Thicker hood is designed for rugged use.
- Reams and smooths 1/2" (13 mm), 3/4" (19 mm), and 1" (25 mm) thin-wall conduit ends to protect wire and permit correct installation of fittings.
- Reams both the inside and outside of the conduit at the same time.
- Longer Cushion-Grip handle provides comfort and more torque for reaming.
- Replaceable reaming blade is now held in place with a 1/16" set screw.



Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
85191	5/16" (8 mm)	2-1/2" (64 mm)	7-1/2" (191 mm)	.50
19353	conduit reamer replacement blade kit			.01

Conduit Reamer

- Locks onto screwdrivers; reams and smooths thin-wall conduit.
- Reams ID and OD at the same time.
- Two set-screws for round- and square-shank screwdrivers.
- Fits up to 3/8" (10 mm) keystone-tip screwdrivers.
- NOT for use on power tools.

Cat. No.	Conduit Capacity	Weight (lbs.)
19352	1/2", 3/4", 1"	.20
19353	conduit reamer replacement blade kit for 19352	.01
19351	conduit reamer replacement blade for 19350	.01



All dimensions are in inches and (millimeters).

⚠WARNING: Always wear approved eye protection.

⚠WARNING: NOT insulated. Will NOT protect against electrical shock.

⚠WARNING: Do NOT use to pry or chisel.

