


Conduit and Cable

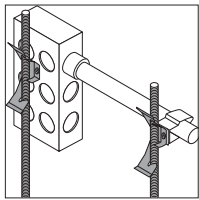

Features

FROM DROP WIRE OR FLANGE

- Attaches to #12 wire through 3/8 in. rod.
- Fits 1/8 in. to 3/8 in. flanges
- Provides attachment of conduit and boxes.
- Supports #10-24 and 1/4 in.-20 threaded bridle rings
- Assembles to support 1/2 in., 3/4 in. and 1 in. EMT and rigid conduit
- Also attaches to 1/4 in. and 3/8 in. threaded rod

 


Fig. 1

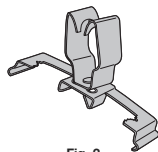


Fig. 2

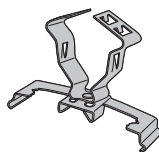


Fig. 3

| Cat. No. | Fig. No. | Description | Static Load Limit | Qty. Per Box |
|---|----------|--|-------------------|--------------|
| Multi-Function Utility Clip from Drop Wire or Flange | | | | |
| SSF-CUC | 1 | Multi-function utility clip | 50 | 100 |
| SSF-CUC-S1/2 | 2 | Utility clip to 1/2 in. conduit | 15 | 25 |
| SSF-CUC-S3/4 | 2 | Utility clip to 3/4 in. conduit | 15 | 25 |
| SSF-CUC-S1 | 2 | Utility clip to 1 in. conduit | 15 | 25 |
| SSF-CUC-C1/2 3/4 | 3 | Utility clip to 1/2 in. or 3/4 in. conduit | 25 | 25 |
| SSF-CUC-C1 | 3 | Utility clip to 1 in. conduit | 25 | 25 |


Features

- Exclusive slot keeps drop wire centered
- Will not bend or deform drop wire
- Delivers faster installation
- Supports MC/AC, 14-2 through 12-3 cable and 1/2 in. EMT (0.433 in.-0.706 in. O.D.) from #8-#12 wire and 1/4 in. plain and threaded rod
- Eliminates the need to trap cable against drop wire
- Supports 25 lb. static load limit
- No tools required

New finger friendly design and exclusive center slot keeps drop wire centered.



Fig. 1

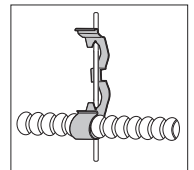

| Cat. No. | Fig. No. | Description | Static Load Limit | Qty. Per Box |
|-------------------------------------|----------|------------------------------|-------------------|--------------|
| Cable from Drop Wire Support | | | | |
| SSF-CB706 | 1 | Cable from drop wire support | 25 | 100 |