

CASTOR WHEELS, EYEBOLTS, PAINT

Visit
www.eurobex.com
for details.


 
 
Call us
toll free
1-800-363-2423

Castor wheels - Series 880 C


The **880 C** castor wheels can be mounted on a rack base. They are available with top plate (880 C100) or with threaded stem (880

C200). Castor wheels are available with or without brake and have a load capacity of 250lbs.

CATALOG NUMBER	BRAKE ?	SHIP WGT LBS.
880 C100	No	1
880 CB100	Yes	1
880 C200	No	1
880 CB200	Yes	1

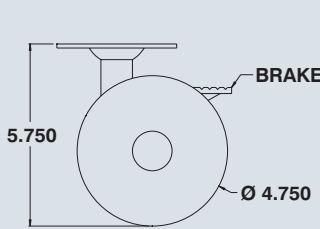

TOP PLATE

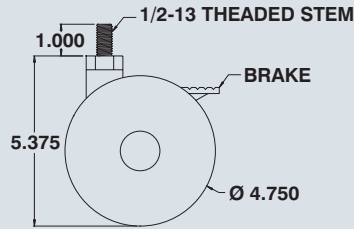

THREADED STEM




Lifting eyebolts - Series 880 EB

The **880 EB** are cast lifting eyebolts used to facilitate cabinet handling.

The **880 EBxSS** are made of stainless steel.

The eyebolts come complete with washers and nuts

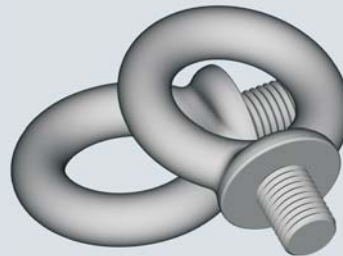

CATALOG NUMBER	THREAD	PIECES	SHIP WGT LBS.
880 EB14	M14	2	1
880 EB14SS	M14	2	1
880 EB12	M12	2	1
880 EB12SS	M12	2	1

Touch up paint - Series 880 P

The **880 P** touch up spray paint cans are exact color match enamel paints in 12 oz. spray cans.



CATALOG NUMBER	COLOR	SHIP WGT LBS.
880 PE	White	1
880 PTE	Textured white	1
880 PG	ANSI/ASA 61 Grey	1
880 PG2	ANSI/ASA 70 Grey	1
880 PTG	Textured grey	1
880 PR	Texture fire red	1
880 PY	Yellow	1
880 PO	Matadore orange	1
880 PV	Egg shell green	1
880 PTB	Textured blue	1
880 PTC	Beige (RAL7032)	1
880 PSC	Sandtex beige	1
880 PSG	Sandtex grey	1
880 PTD	Textured dark blue	1
880 PTK	Textured black	1
880 PGL	Mtrx grey (RAL7035)	1