

## Tripod insulator (7.2 kV)




CATALOGUE NUMBER	HEIGHT (in.)	OVERALL DIAMETER (in.)	WEIGHT (100 pcs)		STD PKG
			lb	kg	
<b>IB400</b>	3-1/2	3-1/4	125	56.8	25

## Insulators (100-200 Amp)



CATALOGUE NUMBER	HEIGHT (in.)	DIAMETER (in.)	HOLE DIA.(IN.)	WEIGHT (100 pcs)		STD PKG
				lb	kg	
<b>IB134 (100 A)</b>	2	2-1/4	9/16	40	18.1	100
<b>IB135 (200 A)</b>	3	3	13/16	115	52.2	50


## Screw type insulator (7.2 kV)

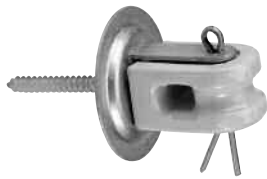

CATALOGUE NUMBER	INSULATOR LENGTH (in.)	PULL OUT STRENGTH	WEIGHT (100 pcs)		STD PKG
			lb	kg	
<b>IB900</b>	3	1500 lb	87	39.5	25

Porcelain insulator securely held in the hot galvanized steel clevis by a cotter pin.


## Clevis (100 Amp)

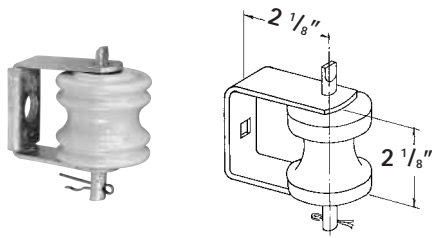

CATALOGUE NUMBER	MOUNTING HOLE	WEIGHT (100 pcs)		STD PKG
		lb	kg	
<b>AN422</b>	11/16" round	90	40.9	25
<b>AN422KIT</b>	11/16" round c/w bolts and washers			1
<b>AN423</b>	9/16" x 9/16" square	90	40.9	25
ADD SUFFIX " <b>NI</b> " IF INSULATOR IS NOT REQUIRED				

Constructed of 1/8" x 1" flat mild steel, has 3/8" diam. pin and C/W No. IB134 insulator, mounting hole as per table above. All ferrous parts are hot dip galvanized.

## Clevis (200 Amp)

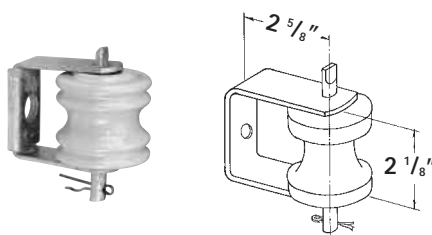

CATALOGUE NUMBER	WEIGHT (100 pcs)		STD PKG
	lb	kg	
<b>AN424</b>	100	45.4	25
ADD SUFFIX " <b>NI</b> " IF INSULATOR IS NOT REQUIRED			

Constructed of 1/8" x 1-1/4" flat mild steel, has 3/8" diam. pin and C/W No. IB134 insulator, 3/8" round mounting hole. All ferrous parts are hot dip galvanized.