

# WORKSTATION POWER SOLUTIONS



Work Station Power Solutions are point-of-use, plug-in outlet centers available with and without surge suppression.

## CODE REFERENCE

**cULus Listed:** File E66421  
Guide XYBS, XUHT, VZCA

## Surge Suppression Specifications

### Sentrex® High Performance Surge Specifications

Surge Protection Circuitry	3 Element, 3-Stage Hybrid Circuit
Maximum Surge Current	56,000 Amps [32,000 Amps L-N, 12,000 Amps L-G, 12,000 Amps N-G]
Noise Reduction	+50dB
Response Time	Less than 1 nanosecond

**NOTE:** See the Joule explanation located on the Cabinet Power Solutions page 626.

### Perma-Power® Computer Grade Surge Specifications

Surge Protection Circuitry	Single Stage
Maximum Surge Current	36,000 Amps [12,000 Amps L-N, 12,000 Amps L-G, 12,000 Amps N-G]
Noise Reduction	+35dB
Response Time	Less than 1 nanosecond


## Mounting Information

### MOUNTING TYPES

Each Plug-In Outlet Center unit has one of three different mounting types. Each mounting method has been designed to optimize the performance of the product. Complete mounting hardware and installation instructions are included with every unit.


#### Snap-On/Slide-Off

Mount unit in any position. Catalog No. 8004 includes two aluminum mounting clips that snap onto mounting rails on the back of the unit. Screws also included. Used for all units with 2" [51mm] aluminum housing.

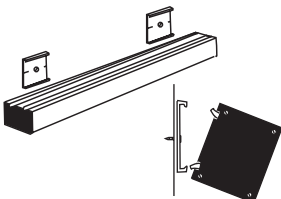


#### Keyhole Mounting

Mount unit in almost any position. Screws not included. Available on all plastic units and units with 3 1/2" [89mm] aluminum housing.

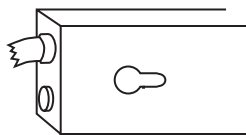


#### Spring Clip Mounting

Mount unit in any position. Catalog No. 8002 includes two spring steel mounting clips that snap onto the unit. Screws also included. Used for all units with 1 1/2" [38mm] narrow aluminum housing.

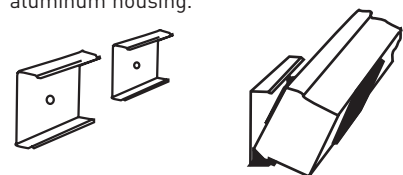

## COLOR OPTIONS

 

Workstation Power Solutions Plug-In Outlet Center Units Part Number descriptions indicate available color options.

# WORKSTATION POWER SOLUTIONS

Ordering Information

## Work Station Power Solutions – Power Only Plug-In Outlet Center Units Ordering Information (continued)

### NM20-C5 Plug-In Outlet Center Units




Ten (5 duplex) outlets, nonmetallic housing with ivory finish. 6' [1.8m] cord, Length 60" [1.5m]. Receptacle center-to-center 12" [305mm].

### NM20-C6 Plug-In Outlet Center Units




Twelve (6 duplex) outlets, nonmetallic housing with ivory finish. 6' [1.8m] cord. Length 72" [1.8m]. Receptacle center-to-center 12" [305mm].

### UL100BC, UL100BD Plug-In Outlet Center Units

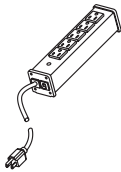


Five outlets, rugged gray aluminum housing, 15A. 6' [1.8m] (UL100BC) or 15' [4.6m] (UL100BD) 14/3 SJT black cord with NEMA5-15 plug. Length 9 1/4" [235mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.

### UL101BC, UL101BD Plug-In Outlet Center Units

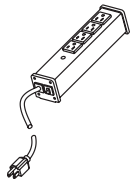


Four outlets, rugged gray aluminum housing, 15A. 6' (UL101BC) or 15' (UL101BD) [1.8m or 4.6m] 14/3 SJT black cord with NEMA5-15 plug. Length 9 1/4" [235mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.

### UL104BC, UL104BD Plug-In Outlet Center Units

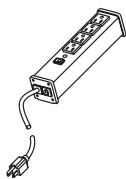


Four outlets, rugged gray aluminum housing, 15A, lighted switch. 6' [1.8m] (UL104BC) or 15' [4.6m] (UL104BD) 14/3 SJT black cord with NEMA5-15 plug. Length 9 1/4" [235mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.

### UL204BC, UL204BD Plug-In Outlet Center Units

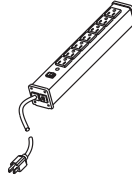


Seven outlets, rugged gray aluminum housing, 15A, lighted switch. 6' [1.8m] (UL204BC) or 15' [4.6m] (UL204BD) 14/3 SJT black cord with NEMA5-15 plug. Length 13" [330mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.

### UL205BC, UL205BD Plug-In Outlet Center Units

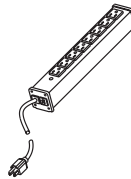


Eight outlets, rugged gray aluminum housing, 15A. 6' [1.8m] (UL205BC) or 15' [4.6m] (UL205BD) 14/3 SJT black cord with NEMA5-15 plug. Length 13" [330mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.

### UL206BC, UL206BD Plug-In Outlet Center Units

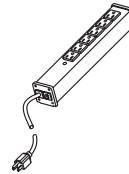

Six outlets, rugged gray aluminum housing, 15A. 6' [1.8m] (UL206BC) or 15' [4.6m] (UL206BD) 14/3 SJT black cord with NEMA5-15 plug. Length 12 1/4" [311mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.

### UL207BC, UL207BD Plug-In Outlet Center Units

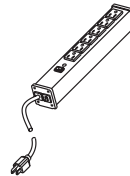

Six outlets, rugged gray aluminum housing, 15A, lighted switch. 6' [1.8m] (UL207BC) or 15' [4.6m] (UL207BD) 14/3 SJT black cord with NEMA5-15 plug. Length 12 1/4" [311mm]. Receptacle center-to-center 1 1/4" [32mm]. Snap-on, slide-off mounting.