



RESIDENTIAL & LIGHT COMMERCIAL FAN SPEED CONTROLS

LS TradeMaster® Series Fan Speed Controls

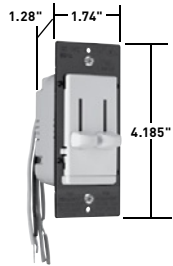

LSDC16LAV

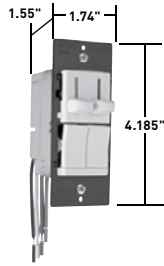

LSDC163PLAV



TM8LMCC

CATALOG NUMBER	DESCRIPTION	RATINGS	COLOR						
DECORATOR SLIDE FAN SPEED CONTROLS*									
LSSC5I LSSC5W LSSC5 LSSC5BK LSSC5LA	Non-Preset, Single Pole, Adjustable Trim	120V 5A	Ivory White Brown Black Light Almond						
LSSC5PI LSSC5PW LSSC5P LSSC5PBK LSSC5PLA			120V 5A	Ivory White Brown Black Light Almond					
DECORATOR SLIDE DE-HUMMER CONTROLS**									
LSDH16IV LSDH16WV LSDH16V LSDH16BKV LSDH16LAV				Non-Preset, 4-Speed Fan Control	120V 1.6A	Ivory White Brown Black Light Almond			
DUAL CONTROL DECORATOR SLIDES**									
LSDC16IV LSDC16WV LSDC16V LSDC16BKV LSDC16LAV	Non-Preset, 3-Speed De-Hummer Fan Control With Single Pole Dimmer	120V 1.6A/300W				Ivory White Brown Black Light Almond			
LSDC163PIV LSDC163PWV LSDC163PV LSDC163PBKV LSDC163PLAV			Preset, 3-Speed De-Hummer Fan Control With Single Pole 3-Way Dimmer			120V 1.6A/300W	Ivory White Brown Black Light Almond		
LSDV25IV LSDV25WV LSDV25V LSDV25BKV LSDV25LAV							Non-Preset, Variable Speed Fan Control With Single Pole Dimmer	120V 2.5A/300W	Ivory White Brown Black Light Almond
SINGLE POLE /3-WAY PRESET DIMMER WITH SINGLE POLE/3-WAY 3-SPEED DE-HUMMER FAN CONTROL									
LSCLDC163PBK LSCLDC163P LSCLDC163PI LSCLDC163PLA LSCLDC163PW				Single Pole/3-Way Preset CFL/LED Dimmer With Single Pole/3-Way 3-Speed De-Hummer Fan Control	1.6A, 300W (Fan Control); 120VAC, 60Hz, 450W (Dimmer)				Black Brown Ivory Light Almond White

CATALOG NUMBER	DESCRIPTION	COLOR	
ACCESSORIES FOR LS SERIES			
LRKIV LRKWV LRKVV LRKBKV LRKLAV	Replacement Knobs for Decorator Dual Slides	Ivory White Brown Black Light Almond	
LLRKIV LLRKWV LLRKVV LLRKBKV LLRKLAV		Large Replacement Knobs for Decorator Single Slides	Ivory White Brown Black Light Almond

* Available in VisionPak™ packaging, add "V" to Catalog Number. Example: LSSC5IV.

**Available in VisionPak™ only.

Feature specially designed capacitive circuitry to virtually eliminate fan motor "hum."

CATALOG NUMBER	RATING		COLOR
	A.	VAC	
SNAP-IN LIGHT MODULE			
TM8LMCC	15	120/125	Clear


For additional LS Series products and information, see Pages L-12 – L-15.

All devices listed on this page conform to NEMA WD-1 and WD-6. UL Listed and CSA Certified.


DEVICES & WALL PLATES

Color Selection Chart

Devices & Plastic Wall Plate Colors

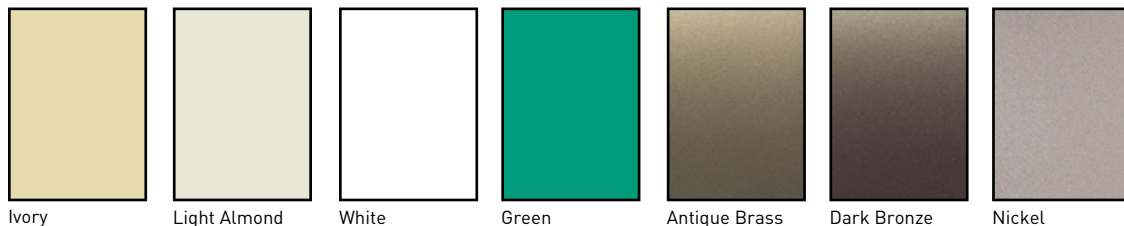

Ivory Light Almond White Green Antique Brass Dark Bronze Nickel

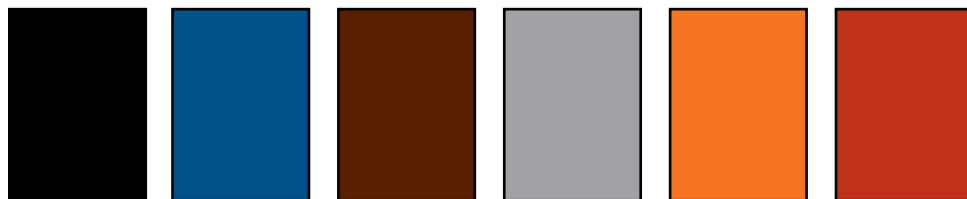


Black Blue Brown Gray Orange Red

See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates


Metal Finish

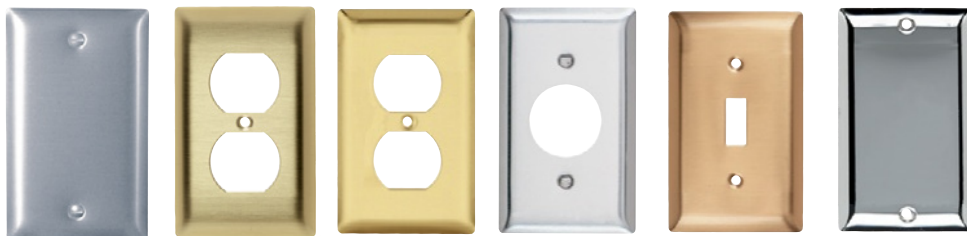

Aluminum Brass (Brushed) Polished Brass Stainless Steel Brushed Bronze Chrome

Custom Metal Wall Plates Paint Finish Colors

Paint Color

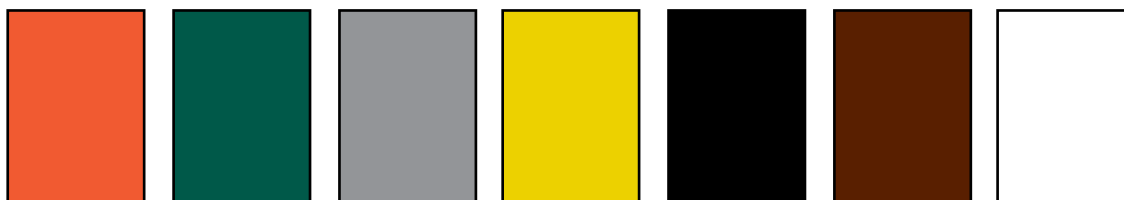

Orange Green Gray Yellow Glossy Black Brown White



Primer Red Pink Flat Black Ivory Light Almond Blue

To order custom metal wall plates, see Pages P-40 – P-42.
For additional colors consult factory.

WALL PLATES