

## Cushion-Grip Screwdriver Sets

### 2-Piece Stubby Screwdriver Set

Additional Feature:

- Double wings inside handle provide solid, twist-resistant blade anchor.



85071


Cat. No.	Set Contains	Weight (lbs.)
85071		.30

Cat. No.	Description	Shank Length	Overall Length
600-1	round-shank, keystone-tip	1-1/2" (38 mm)	3-7/16" (87 mm)
603-1	round-shank, Phillips-tip	1-1/2" (38 mm)	3-7/16" (87 mm)

### Stubby Square-Recess Tip Cushion-Grip Screwdrivers

Additional Features:

- Double wings inside handle provide solid, twist-resistant blade anchor.
- Works on most combination head receptacle and switch screws.
- Color-coded handle ends for quick and easy identification.

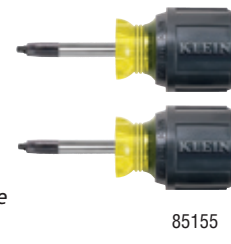

85155

Cat. No.	Description	Color Code	Shank Length	Overall Length	Weight (lbs.)
668	round-shank, No. 1 square-recess tip	green	1-1/2" (38 mm)	3-7/16" (87 mm)	.15
669	round-shank, No. 2 square-recess tip	red	1-1/2" (38 mm)	3-7/16" (87 mm)	.15

#### Stubby Square-Recess Cushion-Grip Screwdriver Set

Cat. No.	Description	Color Code	Shank Length	Overall Length	Weight (lbs.)
85155	2-piece stubby square-recess cushion-grip screwdriver set	green (Cat. No. 668), red (Cat. No. 669)	1-1/2" (38 mm)	3-7/16" (87 mm)	.30

## Cushion-Grip Screwdrivers

### Keystone-Tip Screwdrivers – Heavy-Duty Square-Shanks

Additional Features:

- Heavy-duty square shank for wrench-assisted turning.
- Bolster reinforces shank for hard use.
- Designed for the most demanding uses.



600-4

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
600-4	1/4" (6 mm)	4" (102 mm)	8-11/32" (212 mm)	.25
600-6	5/16" (8 mm)	6" (152 mm)	10-15/16" (278 mm)	.40
600-8	3/8" (10 mm)	8" (203 mm)	13-7/16" (341 mm)	.65
600-12	1/2" (13 mm)	12" (305 mm)	17-7/16" (443 mm)	.80

### Keystone-Tip Screwdrivers – Heavy-Duty Round-Shanks

Additional Features:

- Built to handle the tough jobs with ease.
- Hex bolster reinforces shank for hard use and allows wrench assisted turning.



602-6

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
600-1*	1/4" (6 mm)	1-1/2" (38 mm)	3-7/16" (87 mm)	.10
602-3	7/32" (6 mm)	3" (76 mm)	6-3/4" (171 mm)	.15
602-4	1/4" (6 mm)	4" (102 mm)	8-11/32" (212 mm)	.25
602-6	5/16" (8 mm)	6" (152 mm)	10-15/16" (278 mm)	.35
602-8	3/8" (10 mm)	8" (203 mm)	13-7/16" (341 mm)	.55
602-10	3/8" (10 mm)	10" (254 mm)	15-7/16" (392 mm)	.60
602-12	3/8" (10 mm)	12" (305 mm)	17-7/16" (443 mm)	.65

\* Bolster not available on 600-1.  
Refer to the insulated section for insulated screwdrivers.

All dimensions are in inches and (millimeters).

**WARNING:** NOT insulated. Will NOT protect against electrical shock.

**WARNING:** Always wear approved eye protection.

**WARNING:** Do NOT use to pry or chisel.

