

Heavy-Duty Ratchet Cable Cutters




- Extra thick blades, ground flat to reduce potential for breakage.
- Ratchet action for heavy-duty cutting.
- Two cutting actions – fast scissor cutting for small cable and insulation; converts automatically to ratchet mode.
- Anti-slip mechanism for positive ratchet action.
- Rubber boot protects ratchet mechanism.

SPECIFICATIONS

	COPPER	ALUMINUM
Maximum Capacity	1500 kcmil (MCM) (800 mm ²)	1500 kcmil (MCM) (800 mm ²)
Frequent Use Capacity	1000 kcmil (MCM) (500 mm ²)	1000 kcmil (MCM) (500 mm ²)
Length	27-1/2" (698 mm) long	
Jaw opening	2" (51 mm)	
Weight	11.41 lbs. (5.17 kg)	

CAT. NO.	UPC NO.	DESCRIPTION
756	34081	Heavy-Duty Ratchet Cable Cutter with rubber boot.
R 34188	34188	Cutter Head Unit (Includes 2 Blades)

Two-Hand Ratchet Cable Cutter

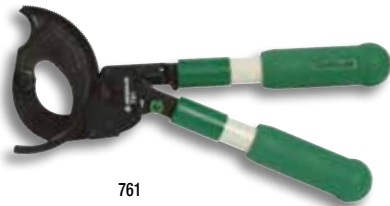

761

- Two-handed operation provides more leverage and makes cutting large cables easier.
- Short fiberglass handles make it easy to use in tight places and to store in tool boxes.
- Single-speed ratchet mechanism.
- Blade release allows blades to be opened in mid-cut.
- Heavy-duty forged steel blades provide long life.

SPECIFICATIONS

Cutting Capacity*	Copper: 1000 kcmil (MCM) (500 mm ²) Aluminum: 1000 kcmil (MCM) (500 mm ²) Communications Cable: 1-1/8" dia. (28 mm ²)
Length	10-3/4" (273 mm)
Weight	3.6 lbs. (1.6 kg)

CAT. NO.	UPC NO.	DESCRIPTION
761	11761	Two-Hand Ratchet Cable Cutter
R 11768	11768	Movable Blade (761)

High Performance Ratchet Cable Cutters



773

- Two-speed mechanism saves cutting time by closing the blades rapidly and shifting to normal speed to perform the cut.
- No more pushing on stubborn release buttons—the blades open automatically when the cut is complete.
- Completely new ratchet mechanism improves durability.
- Narrow profile permits use in deep boxes, against walls or on floors.
- Durable, lightweight fiberglass handles.
- U.S. Patent #6,766,581

SPECIFICATIONS

Maximum Capacity*	773 Copper: 500 kcmil (MCM) (240 mm ²) Aluminum: 795 kcmil (MCM) (400 mm ²) Communications Cable: 1-3/16" dia.
Frequent Use Capacity*	Copper: 350 kcmil (MCM) (150 mm ²) Aluminum: 750 kcmil (MCM) (400 mm ²) Communications Cable: -
Length	5-1/2" (394 mm)
Weight	5.3 lbs. (2.4 kg)



774

Maximum Capacity*	774 Copper: 750 kcmil (MCM) (400 mm ²) Aluminum: 795 kcmil (MCM) (400 mm ²) Communications Cable: 1-3/16" dia.
Frequent Use Capacity*	Copper: 500 kcmil (MCM) (240 mm ²) Aluminum: 750 kcmil (MCM) (400 mm ²) Communications Cable: -
Length	19-1/8" (486 mm)
Weight	5.8 lbs. (2.6 kg)

CAT. NO.	UPC NO.	DESCRIPTION
773	01876	High Performance Ratchet Cable Cutter, 15-1/2"
774	01878	High Performance Ratchet Cable Cutter 19-1/8"
R 10809	10809	Movable & Fixed Blades (773 & 774)