



# Accessories T4 - T5 Mechanical

Acc.

Tmax

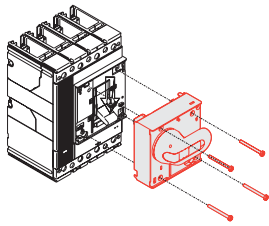

KT5RH

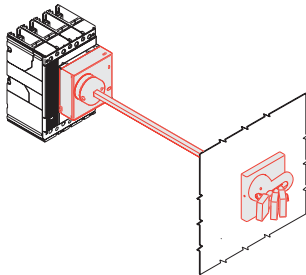

KT5VD-M, OXP10X225  
KT5VD-H



KT5PFVR



KT5WMK



KT5WFVR

## Direct mount rotary operator handle

Direct mount rotary handle (for fixed and plug-in breakers)  
Direct mount rotary handle (for withdrawable breakers)

	Catalog number	List price
Direct mount rotary handle (for fixed and plug-in breakers)	KT5RH	
Direct mount rotary handle (for withdrawable breakers)	KT5RHW	

## Early make contact

Frame	Catalog number	List price
T4-T5	KT5EM	

Allows the UVR or control to be supplied in advance. Mounted inside the direct rotary handle.

## Variable depth rotary handles

Mechanism	Catalog number	List price
Nema 1, 12, 3R Handle (Black)	OHB125J10X ①	
Nema 4, 4X Handle (Black)	OHB125L10 ①	
Shaft - 148 mm / 5.8 in	OXF10X148 ①	
Shaft - 225 mm / 8.9 in	OXF10X225 ①	
Shaft - 500 mm / 19.7 in	OXF10X500 ①	
Nema 1 handle square profile	KT5VD-H	

## Plug-in kits

Breaker	Breaker adapter kit		Plug-in base	
	Catalog number	List price	Catalog number	List price
3-pole	T4 3 Pole with extended front terminal	KT4PMK	KT4PFEF	
	T4 3 Pole with rear horizontal terminal		KT4PFHR	
	T4 3 Pole with rear vertical terminal		KT4PFVR	
3-pole	T5 3 Pole with extended front terminal	KT5PMK	KT5PFEF	
	T5 3 Pole with rear horizontal terminal		KT5PFHR	
	T5 3 Pole with rear vertical terminal		KT5PFVR	
4-pole	T4 4 Pole with extended front terminal	KT4PMK-4	KT4PFEF-4	
	T4 4 Pole with rear horizontal terminal		KT4PFHR-4	
	T4 4 Pole with rear vertical terminal		KT4PFVR-4	
4-pole	T5 4 Pole with extended front terminal	KT5PMK-4	KT5PFEF-4	
	T5 4 Pole with rear horizontal terminal		KT5PFHR-4	
	T5 4 Pole with rear vertical terminal		KT5PFVR-4	

## Draw-out kits

Breaker	Breaker adapter kit		Draw-out base	
	Catalog number	List price	Catalog number	List price
3-pole	T4 3 Pole with extended front terminal	KT4WMK	KT4WFEF	
	T4 3 Pole with rear horizontal terminal		KT4WFHR	
	T4 3 Pole with rear vertical terminal		KT4WFVR	
3-pole	T5 3 Pole with extended front terminal	KT5WMK	KT5WFEF	
	T5 3 Pole with rear horizontal terminal		KT5WFHR	
	T5 3 Pole with rear vertical terminal		KT5WFVR	
4-pole	T4 4 Pole with extended front terminal	KT4WMK-4	KT4WFEF-4	
	T4 4 Pole with rear horizontal terminal		KT4WFHR-4	
	T4 4 Pole with rear vertical terminal		KT4WFVR-4	
4-pole	T5 4 Pole with extended front terminal	KT5WMK-4	KT5WFEF-4	
	T5 4 Pole with rear horizontal terminal		KT5WFHR-4	
	T5 4 Pole with rear vertical terminal		KT5WFVR-4	

Direct mount rotary operator or front locking device or motor operator is required for the draw-out configuration.

## Terminal covers for fixed part of circuit-breakers (kit of 2)

Breaker	3-pole		4-pole	
	Catalog number	List price	Catalog number	List price
T4	KT4TCFP-3		KT4TCFP-4	
T5	KT5TCFP-3		KT5TCFP-4	

## Mechanical interlock plate

	Catalog number	List price
Frame unit horizontal interlock - HB	KT5MI-H	
Frame unit vertical interlock - VB	KT5MI-V	
Plate for A interlock - T4 (F-P-W) + T4 (F-P-W)	KT5MIP-A	
Plate for B interlock - T4 (F-P-W) + T5 400A (F-P-W) or T5 600A (F)	KT5MIP-B	
Plate for C interlock - T4 (F-P-M) + T5 600A (P-W)	KT5MIP-C	
Plate for D interlock - T5 400A (F-P-M) or T5 600A (F) + T5 400A (F-P-M) or T5 600A (F)	KT5MIP-D	
Plate for E interlock - T5 400A (F-P-M) or T5 600A (F) + T5 600A (P-W)	KT5MIP-E	
Plate for F interlock - T5 600A (P-W) + T5 600A (P-W)	KT5MIP-F	