

Silicone Lubricant for High-Voltage Electrical Work


- Seals around junction boxes, flashings, service mast entries, service cable entries and countless other applications
- Easy to use, forms around irregular surfaces and configurations
- Highly resistant to cracking, drying and shrinking
- Cuts and trims easily



CAT. NO.	SIZE	STD. CTN.
SL-5	5 oz.	12

Duct Seal

- Can be painted immediately after application
- Gray color
- No unpleasant odor
- +20°F to 212°F workable temperature range
- -40°F to 250°F service temperature range
- Contains no asbestos

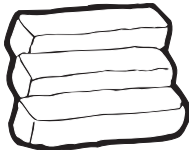

CAT. NO.	DESCRIPTION	STD. CTN.
DX-1	1 Lb. Slug	50
DX-5	(5) 1 Lb. Slugs	10
DX-5S	5 Lb. Slug	10

UL Classified R13335.

NOTE: Not classified as a "Fire Stop." For moisture and air sealing only.

Wire Bristle Brush

- For removing oxides from conductor surfaces
- Easy-grip handle with glove guard to prevent rubber glove puncture
- Long-life brushes can be rotated and are replaceable
- Handle and guard coated with durable non-conductive plastic



CAT. NO.	TYPE	STD. CTN.
WWB1	Complete Brush with Handle	6
WRB1	Wire Element Only, Pair	30

CONTAX® Oxide-Inhibiting Compound

- Seals electrical connections from oxygen and moisture
- Non-water soluble, non-petroleum based polymer grease
- Non-toxic, will not irritate the skin
- Service temperature to 460°F; can be applied in 0°F weather

CAT. NO.	SIZE	STD. CTN.
CTA	½ oz. Package	400
CTB	4 oz. Plastic Bottles	72
CTB8	8 oz. Plastic Bottles	12
CTQ	Quart Cans	6
CTG	Gallon Cans	2

CTO™ Conduit Threading Oil

This oil is a premium petroleum-type cutting oil, chemically compounded to provide an excellent lubricant and coolant for heavy-duty threading, cutting, tapping and drilling.

- Volume: 16 oz. aerosol, 1 quart, 1 gallon
- Chlorinated
- Odor: Slight
- Ingredients: None
- Viscosity: 425–450 SUS @ 100°F
- Flash Point: Above 400°F

CAT. NO.	DESCRIPTION	STD. CTN.
15-111	1 Quart	12
15-112	1 Gallon	4