


Ground Clamps

Similar to aluminum water pipe clamp but lighter in construction.

Budget Price Cast Bronze Clamp

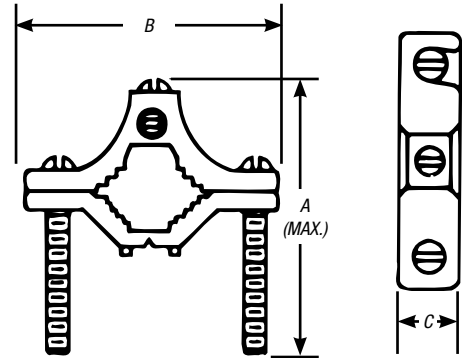


| CAT. NO. | WATER PIPE SIZE | CONDUCTOR RANGE | | DIMENSIONS (IN.) | | |
|----------|-----------------|-----------------|----------|------------------|--------|--------|
| | | MAX. | MIN. | A | B | C |
| JJR | 1/2"–1" | #4 Str. | #10 Sol. | 2 15/32 | 2 5/32 | 1 7/32 |

Add suffix C to Cat. No. to specify plating.

Lay-in feature reduces installation time for difficult bends or continuous loops of ground wire.

Type JDLI — Direct-Burial Ground Clamp

- UL® Listed for direct burial in earth/concrete
- UL® Listed for connection to ground rod, pipe or rebar up to 1"
- Constructed from bronze alloy and high performance stainless steel bolts
- Designed for easy installation of difficult bends or continuous loops

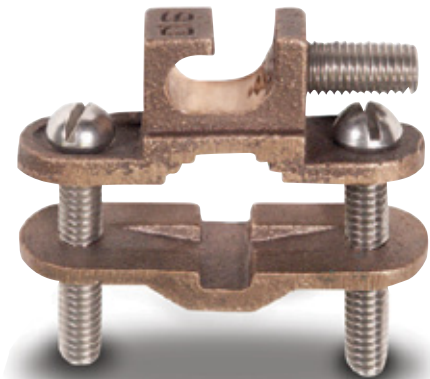

| CAT. NO. | PIPE SIZE | REBAR SIZE | GROUND ROD SIZE | CONDUCTOR RANGE | MECH. CONN./SPICE (UL LISTED) |
|----------|-----------|------------|-----------------|------------------|-------------------------------|
| JDLI | 1/2"–1" | 3/8"–1" | 1/4"–1" | #10 Sol.–#2 Str. | (2) #8 Sol. |