


# STRAIGHT BLADE RECEPTACLES

## Quad Receptacles & Accessories 15 & 20A, 125V



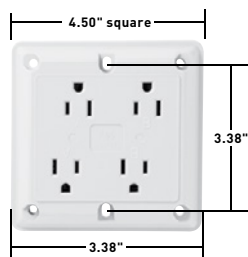


Quad Receptacle

### Application

Pass & Seymour® quad receptacles are designed for dense, multiple-outlet applications such as personal computers and peripherals, office equipment, and home entertainment centers. The bidirectional outlet configuration allows use of up to four oversized plugs, in close proximity. The clean, contemporary design of the quad receptacle allows for surface mounting with minimal protrusion from the wall. No wall plate is required.

### Features

- Rugged nylon face and body withstands impacts and hard use.
- Built-in wire stripping gauge.
- Outward-facing ground terminals make handling up to four straight or angled plugs easy and convenient.
- Heavy-duty, phosphor bronze contacts.
- Shielding walls guard against live-circuit-to-ground shorts.
- Split circuit break-off tabs.
- UL and CSA listed.

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.			 UL498	 UL1449	 CSA
HOSPITAL GRADE ISOLATED GROUND SURGE PROTECTIVE QUADS							
IG420HISP	20	125	Ivory	5-20R	•	•	
IG420HGRYSP	20	125	Gray	5-20R	•	•	
IG420HBLSP	20	125	Blue	5-20R	•	•	
HOSPITAL GRADE QUADS							
420HI	20	125	Ivory	5-20R	•		•
420HW	20	125	White	5-20R	•		•
420H	20	125	Brown	5-20R	•		•
420HGRY	20	125	Gray	5-20R	•		•
420HRED	20	125	Red	5-20R	•		•
SPECIFICATION GRADE SURGE PROTECTIVE QUADS							
420ISP	20	125	Ivory	5-20R	•	•	
420BLSP	20	125	Blue	5-20R	•	•	
SPECIFICATION ISOLATED GRADE QUADS							
IG415	15	125	Orange	5-15R	•		•
IG420	20	125	Orange	5-20R	•		•
SPECIFICATION GRADE QUADS							
415I	15	125	Ivory	5-15R	•		•
415W	15	125	White	5-15R	•		•
415GRY	15	125	Gray	5-15R	•		•
420I	20	125	Ivory	5-20R	•		•
420W	20	125	White	5-20R	•		•
420GRY	20	125	Gray	5-20R	•		•
QUAD ADAPTER PLATES							
4API			Ivory		•	•	
4APW			White		•	•	
4AP			Brown		•	•	
4APGRY			Gray		•	•	
4APRED			Red		•	•	
4APBL			Blue		•	•	
4APORG			Orange		•	•	

### 2 Pole, 3 Wire



NEMA  
5-15R




NEMA  
5-20R

# DEVICES & WALL PLATES

## Color Selection Chart

### Devices & Plastic Wall Plate Colors

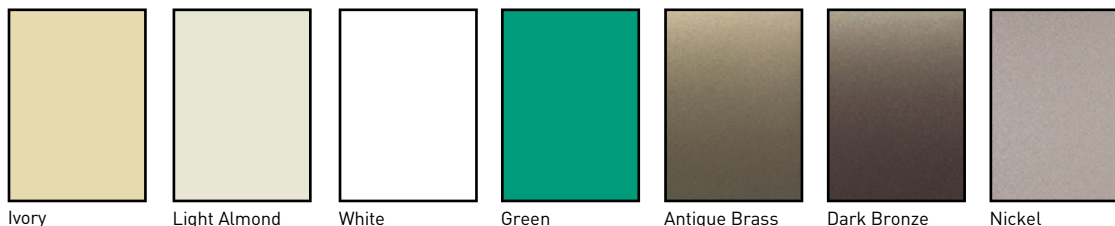

Ivory

Light Almond


White

Green

Antique Brass

Dark Bronze

Nickel

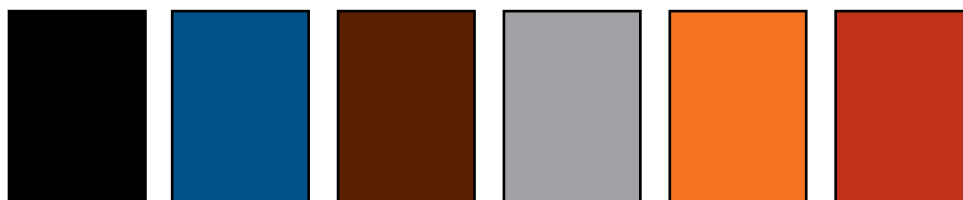

Black

Blue

Brown

Gray


Orange

Red

See specific device and wall plate catalog charts for particular color availabilities.

### Metal Wall Plates

#### Metal Finish

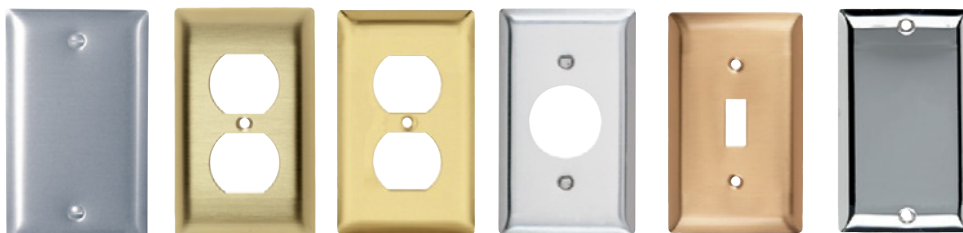

Aluminum

Brass (Brushed)

Polished Brass


Stainless Steel

Brushed Bronze

Chrome

### Custom Metal Wall Plates Paint Finish Colors

#### Paint Color

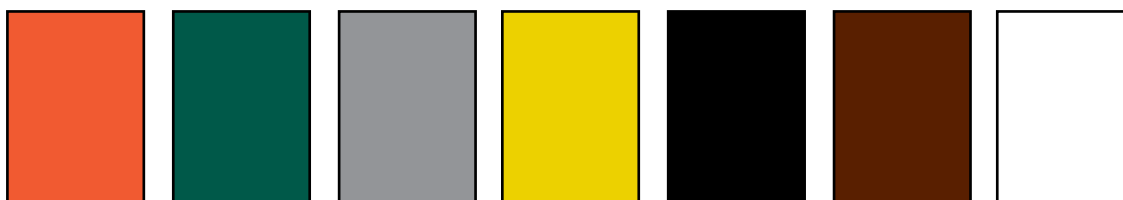

Orange

Green


Gray

Yellow

Glossy Black

Brown

White

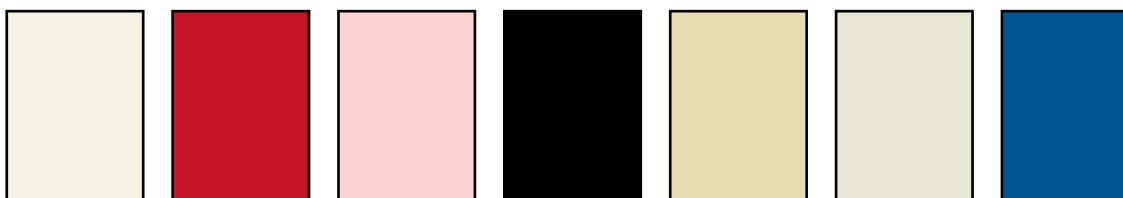

Primer

Red

Pink

Flat Black

Ivory

Light Almond

Blue

To order custom metal wall plates, see Pages P-40 – P-44.

**For additional colors consult factory.**