


### TYPE YP-U

#### CABELOK™ CRIMPIT™

**ACCOMMODATES:** COPPER, AAC (STR, COMPRESSED, COMPACT), ACSR, AND AAAC

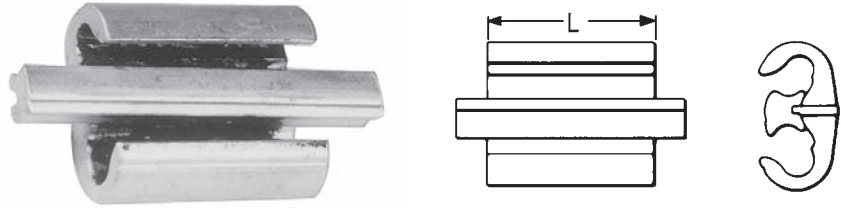

#### MATERIAL: ALUMINUM

Wide range, universal and reversible, Figure "3"-shaped aluminum connector with adjustable overhanging spacer that separates conductors. Spacer holds run or tap in place permitting lineman to either approach the line ready to crimp, or to assemble connector and tap on run and then crimp. Massive aluminum design minimizes conductor corrosion due to galvanic action. Pre-filled with PENETROX™ joint compound and

Stripsealed to limit oxide growth and to increase the life of the connection. Conductor range and tooling information clearly printed on connector and package.

RUS Accepted



H-24

| Catalog Number | Conductor (See Chart Below for Compressed Conductor) |                |              |                    |               |             | L      | Die Index | Tools, Die Set Catalog Number, & (# of Crimps) |                         |
|----------------|--|----------------|--------------|--------------------|---------------|-------------|--------|-----------|--|-------------------------|
|                | Groove A   |                |              | Groove B           |               |             |        |           | MD7, MD6                                       | Y35, Y750, Y45 †, Y46 ‡ |
|                | Solid  | Stranded       | ACSR         | Solid              | Stranded      | ACSR        |        |           |  |                         |
| YP2U3*         | 6, 4, 3, 2   | 6, 4, 3        | 6, 4         | 6, 4, 3, 2         | 6, 4, 3       | 6, 4        | 1-1/2" | O         | W-0 (4)  | U-0(1)                  |
| YP26AU2        | 1, 1/0, 2/0, 3/0                                     | 2, 1, 1/0, 2/0 | 3, 2, 1, 1/0 | 6, 4, 3, 2, 1, 1/0 | 6, 4, 3, 2, 1 | 6, 4, 3, 2  |        |           |  |                         |
| YP25U25**      | 2/0, 3/0   | 1, 1/0, 2/0    | 1, 1/0       | 2/0, 3/0           | 1, 1/0, 2/0   | 1, 1/0      | 1-5/8" | D3        | MD6 (4)  | U-D3 (1)                |
| YP27AU4        | 2/0, 3/0, 4/0  | 1, 0, 2/0, 3/0 | 1/0, 2/0     | 6, 4, 3, 2         | 6, 4, 3       | 6, 4        |        |           |  |                         |
| YP27AU2        |  |                |              | 2, 1, 1/0          | 3, 2, 1       | 4, 3, 2     |        |           |  |                         |
| YP27AU26       | 3/0, 4/0   | 2/0, 3/0       | 2/0          | 2/0, 3/0           | 1/0, 2/0      | 1, 1/0, 2/0 |        |           |  |                         |
| YP28U2         | —  | 4/0            | 3/0, 4/0     | 2, 1, 1/0          | 4, 3, 2, 1    | 4, 3, 2     |        |           |  |                         |
| YP28U26        |  |                |              | 2/0, 3/0           | 1/0, 2/0      | 1, 1/0, 2/0 | 3-1/2" | MD6 (9)   | U - D3 (2)                                     |                         |

| Catalog Number | Compressed Conductor |                    |                   |               | L        | Die Index | Tool, Die Set Catalog No., & (# of Crimps) |                       |
|----------------|----------------------|--------------------|-------------------|---------------|----------|-----------|--|-----------------------|
|                | Groove A             |                    | Groove B          |               |          |           | MD7, MD6                                   | Y36, Y750, Y45†, Y46‡ |
|                | Stranded Aluminum    | ACSR               | Stranded Aluminum | ACSR          |          |           |  |                       |
| YP2U3          | 6, 4, 3, 2           | 6, 4, 3            | 6, 4, 3, 2        | 6, 4, 3       | 1-1/2"   | O         | W-0 (4)                                    | U-0(1)                |
| YP26AU2        | 2, 1, 1/0, 2/0       | 2, 1, 1/0, 2, 0    | 6, 4, 3, 2, 1     | 6, 4, 3, 2, 1 |          |           |  |                       |
| YP25U25        | 1/0, 2/0             | 1/0, 2/0           | 1/0, 2/0          | 1/0, 2/0      | 1-5/8"   | D3        | MD6 (4)                                    | U-D3 (1)              |
| YP27AU4        | 2/0, 3/0             | 1/0, 2/0, 3/0      | 6, 4, 3           | 6, 4, 3       |          |           |  |                       |
| YP27AU2        |                      |                    | 3, 2, 1           | 4, 3, 2, 1    |          |           |  |                       |
| YP27AU26       | 3/0                  | 2/0, 3/0           | 1/0, 2/0, 3/0     | 1/0, 2/0      |          |           |  |                       |
| YP28U2         | 4/0, 250, 266.8      | 4/0, 266.8, (18/1) | 3, 2, 1           | 4, 3, 2, 1    |          |           |  |                       |
| YP28U26        |                      |                    | 1/0, 2/0, 3/0     | 1/0, 2/0      | 3-1/2"   | MD6 ( )   | U - D3 (1)                                 |                       |
| YP28U28        |                      |                    | 4/0               | 3/0, 4/0      | 3/0, 4/0 | 3/0, 4/0  | 2-3/4"                                     | —                     |

\* TAKES UP to #2 ACSR maximum in either groove if other wire is #2 solid or smaller.

\*\* TAKES DOWN to #2 ACSR minimum in either groove if other groove wire is 1/0 stranded or larger.

† U Die with adapter PT-6515.

‡ U Die with adapter PUADP-1.

Not recommended for copper to copper applications. Use a copper connector to increase connection life.

For faster installations use BURNDY® PATRIOT® family of battery tools.