


## Pole Line Hardware

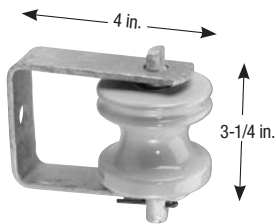


**AN428S**

### Clevis (12 kV)

Cat. No.	Weight (100 pcs)		Std. Pkg.
	lb.	kg	
<b>AN428S</b>	262	119	25

Add suffix "NI" if insulator is not required. Constructed of 3/16 in. x 1-1/2 in. flat mild steel, has 5/8 in. diam. pin and C/W No. IB135 insulator, 11/16 in. round mounting hole. All ferrous parts are hot dip galvanized.

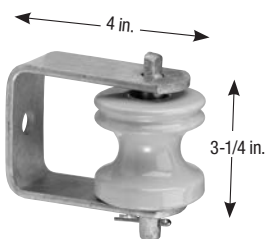


**AN428**

### Clevis (12 kV)

Cat. No.	Weight (100 pcs)		Std. Pkg.
	lb.	kg	
<b>AN428</b>	350	159	5

Add suffix "NI" if insulator is not required. Constructed of 1/4 in. x 2 in. flat mild steel, has 5/8 in. diam. pin and C/W No. IB135 insulator, 11/16 in. round mounting hole. All ferrous parts are hot dip galvanized.

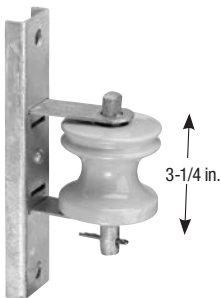


**AN117**

### Flat Mount H.D. Triplex Cable Rack (12 kV)

Cat. No.	Weight (100 pcs)		Std. Pkg.
	lb.	kg	
<b>AN117</b>	290	130	10

Heavy duty wall rack constructed of 1/8 in. steel, C/W 2 mounting holes 1/2 in., C/W No. IB135 insulator. All ferrous parts are hot dip galvanized.

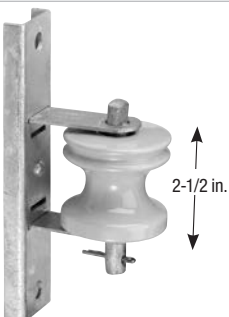

**AN122**

### Flat Mount H.D. Triplex Cable Rack (8 kV)

Cat. No.	Weight (100 pcs)		Std. Pkg.
	lb.	kg	
<b>AN122</b>	160	70	10

Light duty wall rack constructed of 1/8 in. steel, C/W 2 mounting holes 1/2 in., C/W No. IB134 insulator. All ferrous parts are hot dip galvanized.