

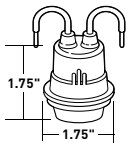
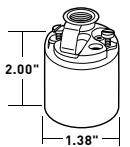
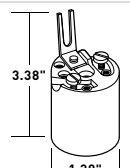
 

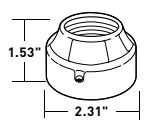
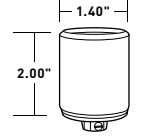
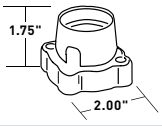

 


ELECTRICAL ACCESSORIES

Incandescent Lampholders

METAL SHELL LAMPHOLDERS								
	CATALOG NUMBER	RATING		DESCRIPTION	COLOR	UL	CSA	cULus
		975ABDCC10	660W	250V	Medium base, metal shell, keyless.		•	•
MEDIUM BASE LAMPHOLDERS								
	8101	660W	250V	Medium base, porcelain, keyless, single circuit, 2 piece ring with leads. 1-3/8" to 1-1/2" hole.	White	•		
 1.75" 1.75"	201	660W	600V	Medium base, rubber, keyless, for temporary lighting, 2 wire leads 6" long.	Black	•		•
 2.00" 1.38"	31528	660W	250V	Medium base, porcelain, screw terminals, keyless, single circuit, fixture pan with 1/8" IPS hickey.	White	•	•	
 3.38" 1.38"	3352F	660W	250V	Medium base, porcelain, keyless, screw terminals, short base.	White	•	•	
	8052CC10	660W	250V	Medium base, porcelain, bracket mount.		•	•	
	9814	250W	250V	Medium base, porcelain, 2-piece pull chain, ring type, screw terminals, gasket furnished.	White			
 1.53" 2.31"	9880	660W	250V	Medium base, porcelain, surface mount type, 2-piece.	White	•	•	
 1.40" 2.00"	10045	660W	250V	Medium base, porcelain, keyless, single circuit with screw terminals, aluminum screw shell with set.	White	•	•	
	10085	660W	250V	Medium base, porcelain, keyless, single circuit with 2-18 AWG leads 6" long.	White	•	•	
 1.75" 2.00"	19062	660W	250V	Medium base, porcelain, pony cleat type, terminal screws.	White	•	•	
	S752WCC10	660W	250V	Medium base, cleat sockets, front wire.	White			•
	61	660W	125V	Medium base, outlet to lampholder, 2 Pole, 2 Wire.	Brown			

All devices listed on this page conform to NEMA WD-1 and WD-6.