



OCCUPANCY & VACANCY SENSORS & TIMERS


120V Wall Box Vacancy Sensors Passive Infrared (PIR)

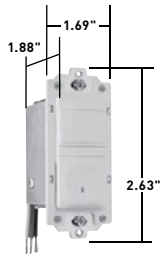

RW600UTC

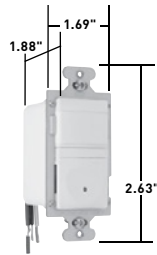

RWU600BLACC4

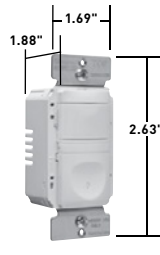


RW600BTC

Features

- California Title 24 compliant.
- Replaces a standard light or fan single pole switch.
- Lighted switch for visibility in darkened rooms.
- Manual-ON operation.
- RW600UTC has adjustable time delay of 30 seconds to 30 minutes - others have fixed 30-minute time delay, no adjustment necessary.
- Low-profile styling with uniform color-matched lens and device.
- Coverage: 180°, max. 600 ft.2 (56m2).
- cULus listed.
- 5-year warranty.
- **RW600B only**
- Load: Incandescent, fluorescent, compact fluorescent (CFL), magnetic low-voltage (MLV) and electronic low-voltage (ELV), 1/6 hp.
- **RW600BTC, RW600UTC only**
- Interchangeable face – Three colors in one box (Ivory, White, Light Almond).


CATALOG NUMBER	DESCRIPTION	VOLTAGE	LOAD	AUTO ON	MANUAL ON	SELECTABLE AUTO/MAN. ON	COLOR
SINGLE POLE VACANCY SENSORS							
RW600BICC4	Neutral required ideal for bedrooms and baths	120VAC 60Hz	0-600W All	No	Yes	No	Ivory
RW600BWCC4				No	Yes	No	White
RW600BBKCC4				No	Yes	No	Black
RW600BLACC4				No	Yes	No	Light Almond
RW600BTC	No neutral required, ideal for bedrooms and baths. Comes with three interchangeable face colors.	120VAC 60Hz	0-600W All	No	Yes	No	Ivory White Light Almond
RW600UTC	No neutral required, ideal for bedrooms and baths. Comes with three interchangeable face colors.	120VAC 60Hz	0-600W All	Yes	Yes	Yes	Ivory Light Almond White

RW600B Wiring

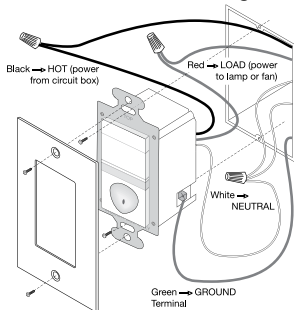


Wiring for RW600B requires a neutral.

RW600B Wiring

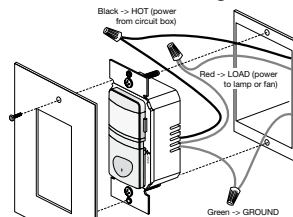

Wiring for RW600B does not require a neutral.

RW600U Wiring

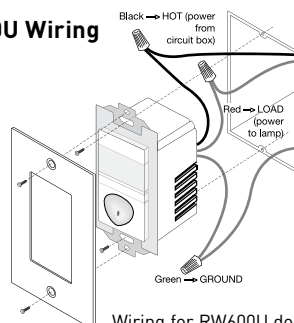

Wiring for RW600U does not require a neutral.

Coverage

