


Utility Boxes and Covers



CI2018

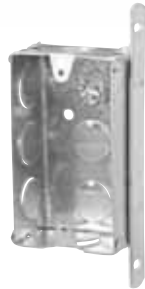


CI2018-SB



BC2020



BC2020-R

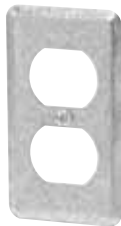


BC20-C-1



BC20-C-3



BC20-C-4

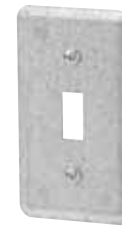

BC20-C-5



Cat. No.	Volume (Cu. in.)	Features		Knockouts		
		Bracket	Raised Ground Screw	1/2 in. ends	1/2 in. bottom	1/2 in. sides
1-1/2 in. Deep — 4 in. x 2-1/4 in.						
CI2018	13.0	-	no	2	2	6
CI2018-SB	13.0	"SB"	no	2	2	3
1-7/8 in. Deep — 4 in. x 2-1/8 in.						
BC2020	14.0	-	yes	2	2	6
BC2020-R	14.0	-	-	2	-	6

Cat. No.	Description
Covers — 20 Series	
BC20-C-1	For duplex receptacle
BC20-C-3	For 1-13/32 in. diameter 15 A single receptacle
BC20-C-4	Blank
BC20-C-5	For toggle switch

Note:
BC2020-R can be installed on CI2018 / BC2020 Series
Covers: Device mounting screws included

Extension Rings

Conduit Knockouts



BC55151-K




CI55171-K




BCOBEX



BC53151-K

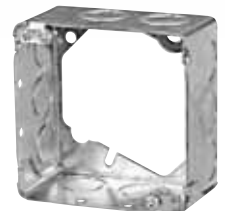

CI53171-ER

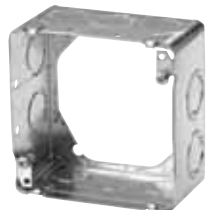

BC53171-K



BC73151-K



BC73171-K



BC1110-R



BC2020-R



Cat. No.	Volume (Cu. in.)	Dimensions	Knockouts		
		H x W x D (in.)	1/2 in. sides	3/4 in. sides	1 in. sides
4 in. Octagonal					
BC55151-K	15.0	4 x 4 x 1-1/2	4	2	-
CI55171-K	21.0	4 x 4 x 2-1/8	4	2	-
4 in. Round					
BCOBEX	5.0	4 x 4 x 1/2	-	-	-
4 in. Square					
BC53151-K	21.0	4 x 4 x 1-1/2	10	6	-
BC53171-K	30.0	4 x 4 x 2-1/8	10	6	-
4-11/16 in. Square					
BC73151-K	30.0	4-11/16 x 4-11/16 x 1-1/2	10	6	-
BC73171-K	42.0	4-11/16 x 4-11/16 x 2-1/8	10	6	-
Utility					
BC1110-R	16.5	4 x 2-3/8 x 1-7/8	6	-	-
BC2020-R	14.0	4 x 2-1/8 x 1-7/8	6	-	-
Concrete					
CI53171-ER	30.0	4 x 4 x 2-1/8	10	6	-