




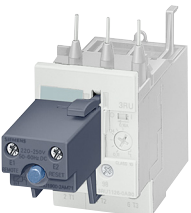
Overview

Overload relays for standard applications

The following optional accessories are available for the 3RU11 thermal overload relays:

- Terminal support for stand-alone installation of overload relay sizes S00 to S3
- Mechanical RESET (for all sizes)
- Cable release for resetting devices which are difficult to access (for all sizes)
- Electrical remote RESET module in three voltage variants (for all sizes)
- Terminal covers

Selection and ordering data

Version	Size	DT	Article No.	Price per PU	PU (UNIT, SET, M)	PS*	PG
Terminal supports for stand-alone installation							
 <p>3RU19.6-3AA01</p>	For separate mounting of overload relays; screw and snap-on mounting onto TH 35 standard mounting rail; size S3 also for TH 75 standard mounting rail	S00	▶	3RU1916-3AA01	1	1 unit	41F
		S0	▶	3RU1926-3AA01	1	1 unit	41F
		S2	▶	3RU1936-3AA01	1	1 unit	41F
		S3	▶	3RU1946-3AA01	1	1 unit	41F
Mechanical RESET							
 <p>3RU1900-1A with pushbutton and extension plunger</p>	Resetting plungers, holders and formers	S00 ... S3	▶	3RU1900-1A	1	1 unit	41F
	Pushbuttons with extended stroke (12 mm), IP65, Ø 22 mm	S00 ... S3	B	3SB3000-0EA11	1	1 unit	41J
	Extension plungers For compensation of the distance between the pushbutton and the unlatching button of the relay	S00 ... S3	A	3SX1335	1	1 unit	41J
Cable releases with holder for RESET							
 <p>3RU1900-1.</p>	For Ø 6.5 mm holes in the control panel; max. control panel thickness 8 mm	S00 ... S3	▶	3RU1900-1B	1	1 unit	41F
	<ul style="list-style-type: none"> • Length 400 mm • Length 600 mm 	S00 ... S3	▶	3RU1900-1C	1	1 unit	41F
Modules for remote RESET, electrical							
 <p>3RU1900-2A.71</p>	Operating range 0.85 ... 1.1 × U_N , power consumption AC 80 VA, DC 70 W, ON period 0.2 ... 4 s, switching frequency 60/h	S00 ... S3	A	3RU1900-2AB71	1	1 unit	41F
	• 24 ... 30 V AC/DC	S00 ... S3	A	3RU1900-2AF71	1	1 unit	41F
	• 110 ... 127 V AC/DC	S00 ... S3	A	3RU1900-2AM71	1	1 unit	41F
	• 220 ... 250 V AC/DC	S00 ... S3	A				
Terminal covers							
	Covers for cable lugs and busbar connections						
	• Length 55 mm	S3	B	3RT1946-4EA1	1	1 unit	41B
	Covers for box terminals						
	• Length 20.6 mm	S2	B	3RT1936-4EA2	1	1 unit	41B
	• Length 20.8 mm	S3	▶	3RT1946-4EA2	1	1 unit	41B