

NEER Zinc Two Screw Connectors

For Nonmetallic Sheathed Cable

C: Two Screw

Application

- Open throat type for nonmetallic sheathed cable.

Features

- Furnished with locknut.
- Male hub threads — NPS.

Standard Material/Finish

- Body: zinc diecast
- Clamp: steel/zinc plated
- Screw: steel/zinc plated

Certifications and Compliances

- UL Standard: 514B
- UL Listed: E25015
- CSA Standard: C22.2 No. 18.3
- CSA Certified: 208044
- NEMA: FB-1

Note:


- All connectors listed for use with a single cable only except for the C-500 which is also listed for use with two 14-2 AWG or two 12-2 AWG NM cables. C-500 also listed for flexible cord with a diameter range of 0.29in./7.4mm. to 0.45in./11.4mm.

Commercial Products

COMMERCIAL PRODUCTS: CORD AND CABLE FITTINGS



C-500

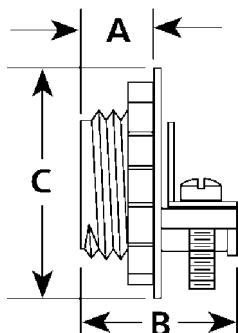

| Trade Size (Inches) | Catalog Number | Dimensions in Inches/Millimeters | | | Nm Cable Range |
|---------------------|----------------|----------------------------------|---------------|---------------|-----------------|
| | | A | B | C | |
| 3/8 (1/2 knockout) | C-500 | 0.36/ 9.1 | 0.81/ 20.6 | 0.91/ 23.1 | 14-2 to 12-2 |
| 3/4 | C-750 | 0.42/ 10.7 | 0.94/ 23.9 | 1.20/ 30.5 | 10-3 to 8-2 |
| 1 | C-1001-R | 0.51/ 13.0 | 1.11/ 28.2 | 1.51/ 38.4 | 10-3 to 4-2 |