

A45 ... A75, AE and AF50 ... AF75 4-pole contactors

Main accessories



CA5-10




CAL5-11




RV5/50



 TP40DA




BX-TP

 


VE5-2

 Terminal marking and positioning



BES... for 4 N.O. main pole connection

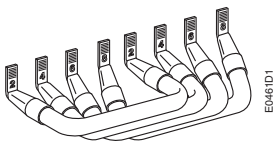

BES75-40

Ordering details (1)

For contactors	Auxiliary contacts	Type	Order code	Pkg qty	Weight (1 pce)
					kg

Front-mounted instantaneous auxiliary contact blocks

A45 ... A75, AE45 ... AE75, AF50 ... AF75	1 -	CA5-10	1SBN010010R1010	10	0.014
	- 1	CA5-01	1SBN010010R1001	10	0.014
A45 ... A75, AE45 ... AE75, AF45 ... AF75	2 2	CA5-22E	1SBN010040R1022	2	0.060

Side-mounted instantaneous auxiliary contact blocks

A45 ... A75, AE45 ... AE75, AF45 ... AF75	1 1	CAL5-11	1SBN010020R1011	2	0.050
---	-----	---------	-----------------	---	-------

Pneumatic timer blocks

A45 ... A75, AE45 ... AE75, AF45 ... AF75	delay on energization	0.1...40 s	1 1	TP40DA	1SBN020300R1000	1	0.070
		10...180 s	1 1	TP180DA	1SBN020300R1001	1	0.070
	delay on de-energization	0.1...40 s	1 1	TP40IA	1SBN020301R1000	1	0.070
		10...180 s	1 1	TP180IA	1SBN020301R1001	1	0.070
Timer accessory	plastic sealable cover		- -	BX-TP	FPTN472657R0001	1	0.006

Interlock unit

A45 ... A75-40-00, AF45 ... AF75-40-00	Mechanical and electrical	- 2	VE5-2	1SBN030210R1000	1	0.146
--	---------------------------	-----	-------	-----------------	---	-------

Surge suppressors

For contactors	Rated control circuit voltage U _c		Type	Order code	Pkg qty	Weight (1 pce)
	V	AC DC				
A45 ... A75, AE45 ... AE75	24...50	● ●	RV5/50	1SBN050010R1000	2	0.015
	50...133	● ●	RV5/133	1SBN050010R1001	2	0.015
	110...250	● ●	RV5/250	1SBN050010R1002	2	0.015
	250...440	● ●	RV5/440	1SBN050010R1003	2	0.015
A45 ... A75	24...50	● -	RC5-2/50	1SBN050200R1000	2	0.015
	50...133	● -	RC5-2/133	1SBN050200R1001	2	0.015
	110...250	● -	RC5-2/250	1SBN050200R1002	2	0.015
	250...440	● -	RC5-2/440	1SBN050200R1003	2	0.015
AE45 ... AE75	12...32	- ●	RT5/32	1SBN050020R1000	2	0.015
	25...65	- ●	RT5/65	1SBN050020R1001	2	0.015
	50...90	- ●	RT5/90	1SBN050020R1002	2	0.015
	77...150	- ●	RT5/150	1SBN050020R1003	2	0.015
	150...264	- ●	RT5/264	1SBN050020R1004	2	0.015

Connection sets for 4-pole changeover contactors

A45 ... A75-40-00, AE45 ... AE75-40-00, AF45 ... AF75-40-00	BES75-40	1SBN083302R1000	1	0.400
---	----------	-----------------	---	-------

(1) See "Main accessory fitting details" table.