

Panelboards

Type P2 Panelboard Kits and Accessories

Selection

Standard Enclosures

Box Height Inches	Catalog Number				
	Type 1 Standard Trim			Type 3R	Type 3R/12
	Box	Surface	Flush		
26	B26	S26B	F26B	NR26	WP26
32	B32	S32B	F32B	NR32	WP32
38	B38	S38B	F38B	NR38	WP38
44	B44	S44B	F44B	NR44	WP44
50	B50	S50B	F50B	NR50	WP50
56	B56	S56B	F56B	NR56	WP56
62	B62	S62B	F62B	NR62	WP62
68	B68	S68B	F68B	NR68	WP68
74	B74	S74B	F74B	NR74	WP74

Options For Type 1 Trims

Items must be ordered as manual line item on Spartanburg

Hinged trim – Replace "B" suffix with "H"

Door-in-door – Replace "B" suffix with "D"

Screw to Box - Replace "B" suffix with "C"

Metal card holder - Add "M" suffix on all trims

Option For 24" Wide Enclosures with Equal Gutter on Both Sides (Excludes NEMA 3R)

24" wide with equal gutter on both sides - Add "24" as prefix

Breaker Kits and Accessories

Kit Number	Description	Contents
BBKB32	BL/BQD 6-pole 3" branch breaker kit	Kit contains top barrier, (3) A/C connectors, (1) B connector, hardware
BBKED32	ED 6-pole 3" branch breaker kit	Kit contains breaker support, inter-phase barriers, (3) A/C connectors, (1) B connector, hardware
BBKNB32	xGB 6-pole 3" branch breaker kit	Kit contains top barrier, (3) A/C connectors, (1) B connector, hardware
BBKQ1	QJ branch breaker kit for 2 and 3-pole single mount	Kit to contain all connectors and cover plates necessary to mount both 2 and 3-pole breakers
DFK1	BL, BQD, ED deadfront kit for 1" pole breakers	Center strips 3", 6", 9", 15", 21" plus mounting hardware
DFFP3	Deadfront filler 3"	3" empty space filler and hardware
DFFP6	Deadfront filler 6"	6" empty space filler and hardware
BNK2	Branch neutral (P2)	Three tier lug with mounting hardware to increase neutral capacity
P2BK1	P2 250A max. Bonding Kit	Bonding strap and hardware
P2BK2	P2 400A max. Bonding Kit	Bonding strap and hardware
P2BK3	P2 600A max. Bonding Kit	Bonding strap and hardware

Type P1, P2, and P3 Panelboards

Miscellaneous Parts and Accessories


Catalog Number	Description	Catalog Number	Description
EGK	Al Ground Bus 44 Connections	NBK6	Number Strips 86-168
P2BK1	P2 250A Bonding Kit	NBK7	Number Strips 169-210
P2BK2	P2 400A Bonding Kit	NBK8	Number Strips 211-252
P2BK3	P2 600A Bonding Kit	ECGK	Cu Ground Bus 44 Connections
IMK1	Interior Adjusting Kit	IGK	Insulated Al Ground Bus
11-1824-01	Directory Card Holder	ICGK	Insulated Cu Ground Bus
12-1110-01	Directory Card	EWK1	End Wall Kit with Knockouts (20" W x 5.75" DP)
11-1056-01	NEMA Instruction Book	EWK2	End Wall Kit with Knockouts (24" W x 7.75" DP)
NBK3	Number Strips 1-42	DFFP1	1" Filler Plate – (suitable for replacing QF3 in P1 thru P5 Panelboards and Switchboards)
NBK4	Number Strips 43-84	EBF1	NEB/HEB Filler Plate
NBK5	Number Strips 85-126		

Panelboards


Type P2 Panelboards

Dimensions

Type 1 Box
Box is symmetrical

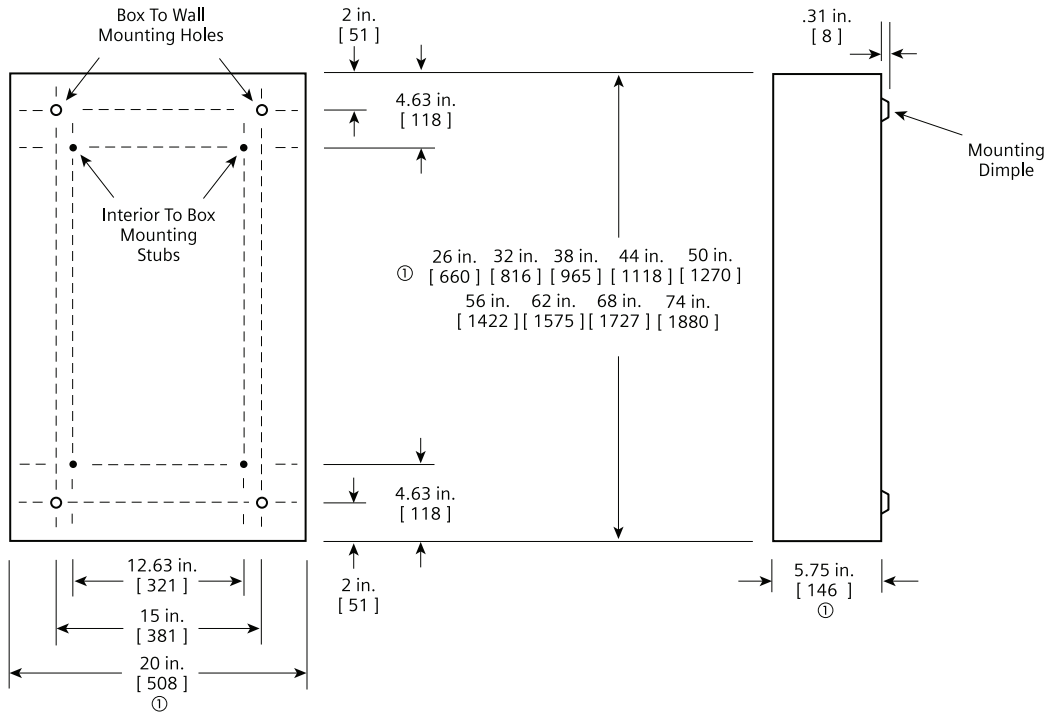

Type 3R and 3R/12 Box

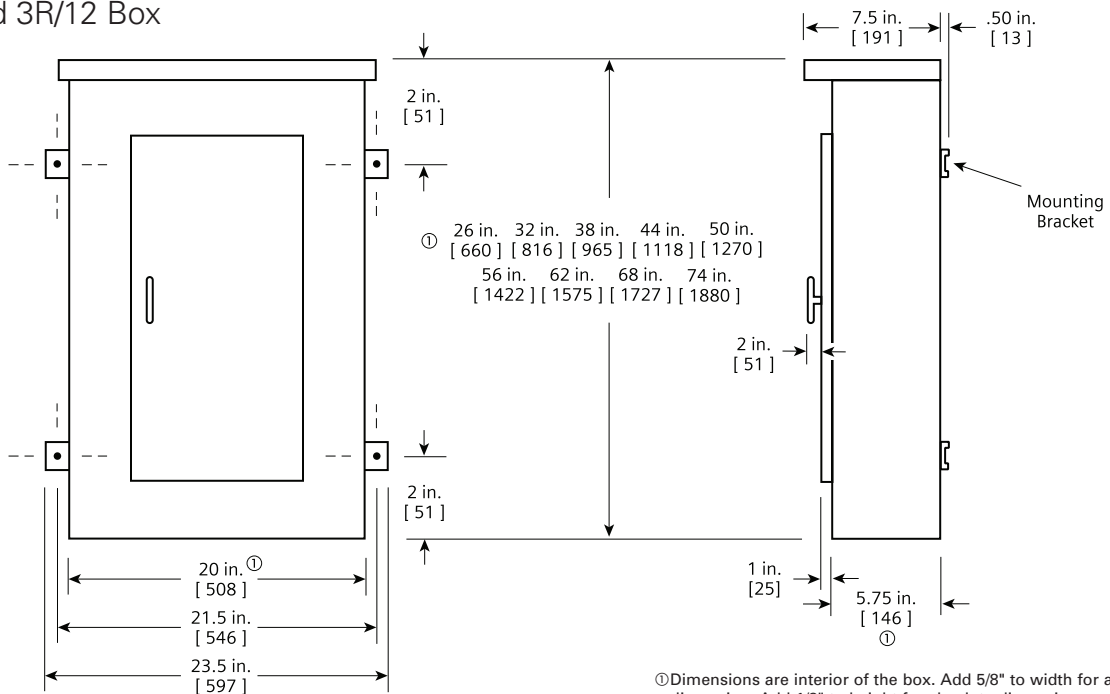

① Dimensions are interior of the box. Add 5/8" to width for absolute dimension. Add 1/8" to height for absolute dimension.
Dimensions shown in inches and millimeters [].