


HOSPITAL GRADE DEVICES

IP20
Suitability


Straight Blade Plugs & Connectors 2 Pole, 3 Wire Grounding 15 & 20A, 125 & 250V

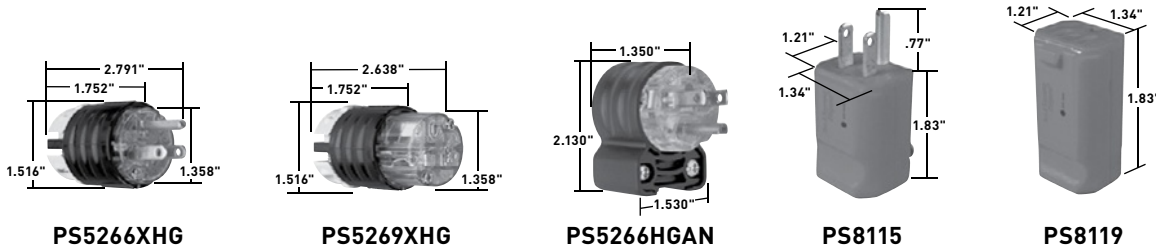

Features

- Unit arrives completely ready-to-wire, cuts installation time significantly.
- Nylon housing provides impact and chemical resistance.
- Rugged two-piece cord provides more uniform cord retention.
- Internal dust shield keeps terminals free of contaminants.
- Tri-drive assembly screws are standard on Hospital Grade plugs and connectors (angle plugs not included).
- All 3-wire terminals located on the same plane, allows for quick wire termination from any angle.
- Heavy-duty brass alloy blades and contacts resist heat rise, provide excellent conductivity.
- Cord-grip screws recessed to protect installer against screwdriver head slippage.

CATALOG NUMBER	RATING		DESCRIPTION	CORD DIAMETER	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.				UL498	FSUL WC596	C22.2 NO.42
EXTRA-HARD USE (EHU)								
PS5266XHGX	15	125	Plug, Black & Clear	.230"-.720"	5-15P	•	•	•
PS5266HGXAN	15	125	Angle Plug, Black & Clear	.320"-.655"	5-15P	•	•	•
PS5269XHGX	15	125	Connector, Black & Clear	.230"-.720"	5-15R	•	•	•
PS5366XHGX	20	125	Plug, Black & Clear	.230"-.720"	5-20P	•	•	•
PS5366HGXAN	20	125	Angle Plug, Black & Clear	.320"-.655"	5-20P	•	•	•
PS5369XHGX	20	125	Connector, Black & Clear	.230"-.720"	5-20R	•	•	•
PS5666XHGX	15	250	Plug, Black & Clear	.230"-.720"	6-15P	•	•	•
PS5666HGXAN	15	250	Angle Plug, Black & Clear	.320"-.655"	6-15P	•	•	•
PS5669XHGX	15	250	Connector, Black & Clear	.230"-.720"	6-15R	•	•	•
PS5466XHGX	20	250	Plug, Black & Clear	.230"-.720"	6-20P	•	•	•
PS5466HGXAN	20	250	Angle Plug, Black & Clear	.320"-.655"	6-20P	•	•	•
PS5469XHGX	20	250	Connector, Black & Clear	.230"-.720"	6-20R	•	•	•
MAXGRIP® M³								
PS8115	15	125	Plug, Gray	.230"-.720"	5-15P	•	•	•
PS8119	15	125	Connector, Gray	.230"-.720"	5-15R	•	•	•

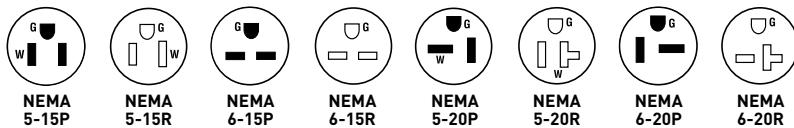

CATALOG NUMBER	DESCRIPTION
ACCESSORIES	
EHU15AN	15 & 20A EHU Straight Blade, Right Angle Adapter
FC22GL	EHU-Strain Relief Grip*
FC30GL	EHU-Strain Relief Grip*
FC40GL	EHU-Strain Relief Grip*
FC52GL	EHU-Strain Relief Grip*

*For further information consult the Flexcor® Section J.